

**Search Results**

- Evaluate
  - FAQ's
- Design a Solution
  - Part Drawings
  - PDFH\*00X165H\*F
  - Specification Sheets
  - PDF2-Sided Heat..
- How to Buy
  - Bill of Material
  - Favorite Products List
  - Locate Distributor


Home > Products Overview > Search Results >

Current refinements (click  to remove) Search Tips


 Text Search: 'H100X165H1T-2'

Your search criteria matched only one product, shown below

**H100X165H1T2**

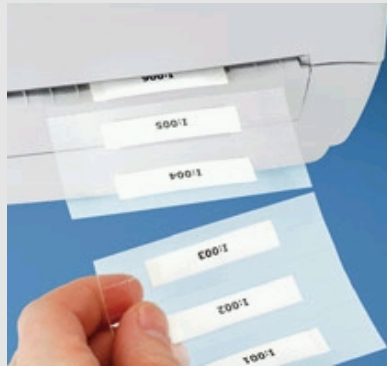

- Labels offer crisp, clear legends with superior legibility
- Meets UL Standard 224 for flammability and AMS -DTL-23053/5C (Class 1 and Class 3)
- Will meet MIL-M-81531, MIL-STD202F, and MIL-STD-883E when printed with RMH4BL or RHH4BL-S ribbons
- Shrink ratio 3:1
- Pre-cut flattened polyolefin is thermal transfer printable and supplied roll mounted on plastic carrier
- Panduit labeling software packages include all label formats for quick and easy label production

Part Number	H100X165H1T2
RoHS Compliancy Status	Compliant
Part Description	2-sided Military Grade printable heat shrink label, white, 1" (25.4mm) diameter polyolefin, 500/roll.
Material	3:1 Flattened Polyolefin
Color	White
Height (In.)	1.65
Height (mm)	41.9
Width (In.)	1.00
Width (mm)	25.4
Max. Wire O.D. (In.)	1.00
Max. Wire O.D. (mm)	25.4
Min. Cable O.D. (In.)	0.33
Min. Cable O.D. (mm)	8.4
Nominal Cable O.D. (In.)	0.33 - 1.00
Nominal Cable O.D. (mm)	8.4 - 25.4
Overall Size W x H (In.)	1.00 x 1.65
Pricing Description	Heat Shrink Label, 2Sided, 1.00" (25.4mm) Diameter, White
Min. Order UOM	RL
Min. Order Qty.	1
BOM Qty. (# of Pkgs.)	<input type="text" value="0"/>
Add to Favorite Product List	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.