

Search Results

- Evaluate
 - FAQ's
- Design a Solution
 - Part Drawings
 - PDFH___X064H*F ..
 - Specification Sheets
 - PDF2-Sided Heat..
- How to Buy
 - Bill of Material
 - Favorite Products List
 - Locate Distributor


Home > Products Overview > Search Results >

Current refinements (click  to remove) Search Tips


 Text Search: 'H200X064H1T-2'

Your search criteria matched only one product, shown below

H200X064H1T2

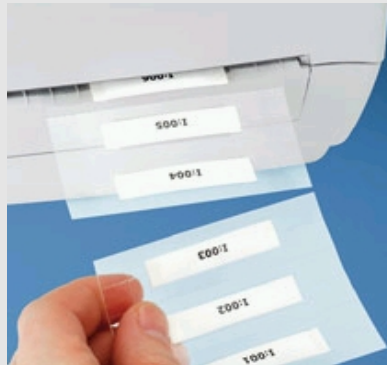

- Labels offer crisp, clear legends with superior legibility
- Meets UL Standard 224 for flammability and AMS -DTL-23053/5C (Class 1 and Class 3)
- Will meet MIL-M-81531, MIL-STD202F, and MIL-STD-883E when printed with RMH4BL or RHH4BL -S ribbons
- Shrink ratio 3:1
- Pre-cut flattened polyolefin is thermal transfer printable and supplied roll mounted on plastic carrier
- Panduit labeling software packages include all label formats for quick and easy label production

| | |
|------------------------------|--|
| Part Number | H200X064H1T2 |
| RoHS Compliancy Status | Compliant |
| Part Description | 2-sided Military Grade printable heat shrink label, white, 3/8" (9.5mm) diameter polyolefin, 500/roll. |
| Material | 3:1 Flattened Polyolefin |
| Color | White |
| Height (In.) | 0.64 |
| Height (mm) | 16.3 |
| Width (In.) | 2.00 |
| Width (mm) | 50.8 |
| Max. Wire O.D. (In.) | 0.38 |
| Max. Wire O.D. (mm) | 9.7 |
| Min. Cable O.D. (In.) | 0.13 |
| Min. Cable O.D. (mm) | 3.3 |
| Nominal Cable O.D. (In.) | 0.13 - 0.38 |
| Nominal Cable O.D. (mm) | 3.3 - 9.7 |
| Pricing Description | Heat Shrink Label, 2Sided, 0.38" (9.65mm) Dia., White |
| Min. Order UOM | RL |
| Min. Order Qty. | 1 |
| BOM Qty. (# of Pkgs.) | <input type="text" value="0"/> |
| Add to Favorite Product List |  |

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.