


Item no.: 773-166
 Product description: sorry no description

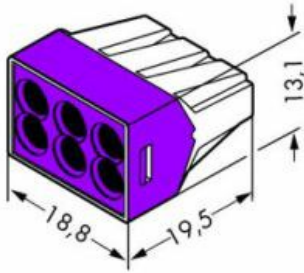

Packing unit 50 pieces

Product group	7 (Push Wire Conn.)
pole count	6
Cross section [mm ²]	0.75 - 2.5 mm ²
Cross section [AWG]	18 - 12 AWG
Wiring method	e
Connection method	PUSH WIRE®
Cross section [mm ²]	1.5 - 2.5 mm ²
Cross section [AWG]	16 - 12 AWG
Wiring method	st
Connection method	PUSH WIRE®
Measured voltage EN	400 V
Measured shock voltage	4 kV
Pollution degree	2
Current intensity EN	24 A
Weight	4.25 g
Color	violet
No. of connection Points	6
No. of potentials	1
Height	13.1 mm
Height	0.516 in
Width	18.8 mm
Width	0.74 in
Depth	19.5 mm
Depth	0.768 in
Strip length from	12 mm
Strip length to	12 mm
Strip length	0.47 in