

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130098-0044](#)
Status: **Active**
Overview: [Strain-Relief Cord Grips](#)
Description: MAX-LOC® Strain Relief Cord-Sealing Grip, 1/2" NPT, 90° Angle Male, Cable Diameter 3.18-4.75mm (.125-.187")

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

Agency Certification

CSA	LR32159
UL	E76954

General


Product Family	Cable Grips
Series	130098
Eye Type	N/A
NEMA Rating	NEMA 3R
O-Ring	No
Overview	Strain-Relief Cord Grips
Product Literature Order No	987650-8064
Product Name	MAX-LOC®
Type	Strain Relief Grip
UPC	78678872155
Use With	1/2" NPT MAX-LOC® Lock Nut 130099-0143 , MAX-LOC® O-Ring, 1/2" NPT 130180-0314 , 1/2" NPT MAX-LOC® Gasket 130099-0149
Woodhead	Yes

Physical

Approximate Break Strength	N/A
Bale Length	N/A
Body Style	90° Angle
Cable Diameter	3.18-4.75mm (.125-.187")
Color - Grommet	Yellow
Gender	Male
Material - Body	Nylon
Material - Grip	N/A
Mesh Length	N/A
Number of Holes	1
Thread Size	1/2" NPT

Material Info

Old Part Number	5521
-----------------	------

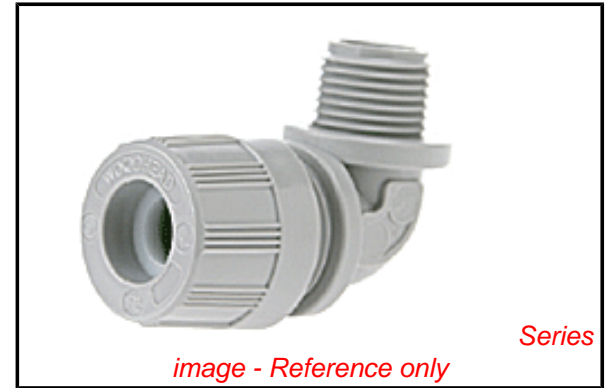

EU RoHS

**ELV and RoHS
Compliant**
**REACH SVHC
Not Reviewed**
**Low-Halogen Status
Not Reviewed**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[130098Series](#)