





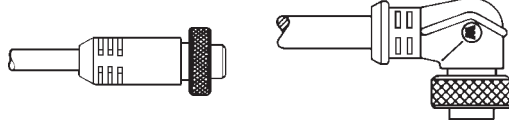

PLUGS

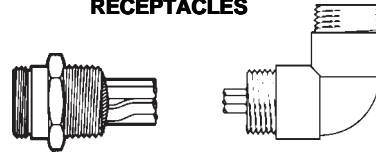


RECEPTACLES




BRAD HARRISON MOLDED MINI-CHANGE ELECTRICAL CONNECTORS (2-5 POLE) WITH CABLE


No. Poles	Face View of Male	Wiring	Rating 600V 105°C	Cable Length	Plugs with #16 AWG STO Cable						Receptacles with 12" Pigtails							
					Male		Female				Male				Female			
					Straight	Price	Straight	Price	90°	Price	Straight	Price	90°	Price	Straight	Price	90°	Price
2		1. White 2. Black	13A	3'	40707	\$12.12	40710	\$12.12	40710-90	\$12.12	40705	\$ 8.69	40706	\$11.40	40701	\$11.34	40702	\$14.39
				6'	40708	13.84	40711	13.84	40711-90	13.84								
				12'	40709	17.29	40712	17.29	40712-90	17.29								
3		1. Green 2. Black 3. White	10A	3'	40904	12.89	40901	12.89	40901-90	12.89	40909	8.95	40908	11.68	40910	8.95	40911	11.68
				6'	40905	15.12	40902	15.12	40902-90	15.12								
				12'	40906	19.79	40903	19.79	40903-90	19.79								
4		1. Black 2. White 3. Red 4. Green	8A	3'	41110	16.34	41107	16.34	41107-90	16.34	41103	10.30	41101	13.13	41104	10.30	41105	10.30
				6'	41111	22.22	41108	22.22	41108-90	22.22								
				12'	41112	25.66	41109	25.66	41109-90	25.66								
5		1. White 2. Red 3. Green 4. Orange 5. Black	8A	3'	41315	19.03	41306	19.03	41306-90	19.03	41310	10.99	41311	13.62	41313	10.99	41314	16.52
				6'	41316	23.63	41307	23.63	41307-90	23.63								
				12'	41317	32.81	41308	32.81	41308-90	32.81								

MOLDED MINI-CHANGE CONNECTORS Designed to meet Automotive Standards (ANSI/B93.55M-1981)

No. Poles	Face View of Male	Wiring	Rating 600V 105°C	Cable Length	Plugs with #16 AWG STO Cable				Receptacles with 12" pigtail leads			
					Female				Male			
					Straight	Price	90°	Price	Straight	Price	90°	Price
3		1. Green 2. Red 3. Red	10A	3'	40958	\$12.28	40958-90	\$12.28	40957	\$8.95	40961	\$11.68
				6'	40959	14.48	40959-90	14.48				
				12'	40960	18.85	40960-90	18.85				


MICRO-CHANGE MOLDED CONNECTORS -- INTERNATIONAL PLUGS


No. Poles	Face View of Female	Wiring	Description	Cable Length (Meters)	Female			
					Straight	Price	90°	Price
3		1. Brown 2. Blue 3. Not Used 4. Green/Yellow	Standard Cordset (w/ Braid) 22 AWG 105 ° C	2	81286	\$18.74	81291	\$18.75
			E Series Cordset (w/o Braid) 22 AWG 90 ° C	2	81286-E	12.51	81291-E	13.76

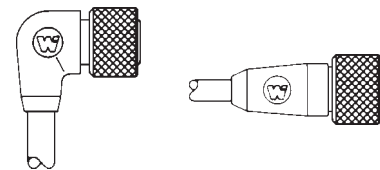

MICRO-CHANGE L.E.D. PLUG


Micro-Change L.E.D. 90° plug allows monitoring of sensor status from a distance. Indicators identify power (green) and sensor (amber) status at a glance, even in well-lit areas. Quick, easy, and space-saving addition to any 10 - 30 VDC, 12 mm sensor, especially those without their own lights, or for sensors mounted in obscure or hard-to-reach places.

No. Poles	Face View of Female	Wiring	Description	Cable Length (Meters)	Sourcing (PNP) Sinking (NPN)	
					Sourcing (PNP)	Sinking (NPN)
3		1. Brown 2. Not Used 3. Blue 4. Black	A Series Cordset (w/o Braid) 22 AWG 90 ° C	2	80326-PA	80326-NA
					\$15.15	\$15.14

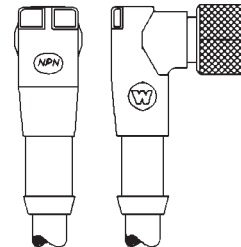

Prices listed in this catalog are for estimating purposes. Prices were correct first column net at the time the pages were composed. Prices are subject to change without notice. Quantity prices are available.


BRAD HARRISON MOLDED MICRO-CHANGE ELECTRICAL CONNECTORS WITH CABLE

No. Poles	Face View of Male	Wiring Code	PLUGS								ADAPTORS		
			Cable Lgth	22AWG Straight				22AWG 90°				Micro-Change Male to Mini-Change Female	Micro-Change Female to Mini-Change Male
				Female	Price	Male	Price	Female	Price	Male	Price		
3		1. Green (Gnd.)	6'	703000D02F060	\$15.49	703002D02F060	\$15.49	703001D02F060	\$16.57	703003D02F060	\$16.57	70204 \$14.60	70205 \$14.60
		2. Red w/Black TR.	12'	703000D02F120	20.52	703002D02F120	20.52	703001D02F120	21.58	703003D02F120	21.58		
		3. Red w/White TR.	20'	703000D02F200	27.20	703002D02F200	27.20	703001D02F200	28.27	703003D02F200	28.27		


RECEPTACLES

1/4" - 18 NPT		1/2" - 14 NPT	
Male	Female	Male	Female
7R3A06A19A120	7R3A04A19A120	7R3006A19A120	7R2004A19A120
\$8.31	\$9.21	\$19.47	\$9.67

 
Straight Plug




90° Plugs

 


1/2" - 14N.P.T. Receptacles

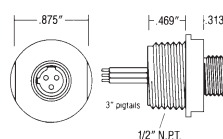


1/4" - 18N.P.T. Receptacle

 

 Male Micro-Change to Female Mini-Change Adapter




 
Micro-Change Female to Mini-Change Male Adapter




ALSO AVAILABLE IN 2, 4 & 5 POLE CONFIGURATIONS

 
BRAD HARRISON MOLDED DC MICRO-CHANGE CONNECTORS WITH CABLE

No. Poles	Face View of Female	Wiring Code	Description	Cable Length (Meters)	PLUGS			
					Straight 22 AWG	Price	90° 22 AWG	Price
3		1. Brown	A Series Cordset	2M	803000A09M020	\$11.30	803001A09M020	\$11.30
		2. Not Used (w/o braid)		4M	803000A09M040	13.49	803001A09M040	13.49
		3. Blue	22AWG 90°C	5M	803000A09M050	14.60	803001A09M050	14.60
		4. Black						
4		1. Brown	A Series Cordset	2M	804000A09M020	12.64	804001A09M020	12.64
		2. White (w/o braid)		4M	804000A09M040	15.70	804001A09M040	15.70
		3. Blue	22AWG 90°C	5M	804000A09M050	17.23	804001A09M050	17.23
		4. Black						

 Straight Plug Cordsets (Female Socket Contacts)






90° Plugs

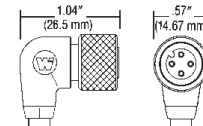


DROP-LITE

Impact resistant molded Nylon handle. Heavy plated steel guard opens easily for relamping. Supplied with switch. 15A outlet in handle for convenience in using portable tools. #16-3 conductor 300V PVC cord set with molded plug.

CAT. NO.	DESCRIPTION	PRICE
402	Drop-lite with 25 ft. cord set	\$33.71
405	Drop-lite with 50 ft. cord set	\$50.01

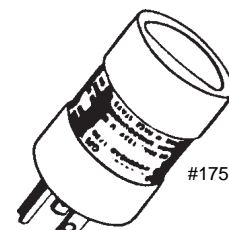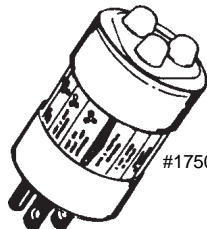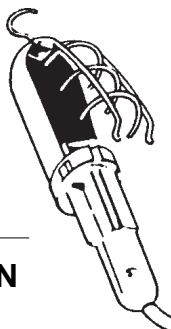

PENDANT PUSH BUTTON STATION

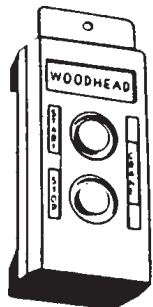

Soft molded rubber enclosure; weatherproof design seals out moisture, etc. Switches are momentary contact type; No buttons required; switch activated by pressure on enclosure face. These single-speed switches are rated 20 Amp, 125, 250 or 480 VAC. 1 H.P., 125 VAC, 2 H.P., 250 VAC

TYPE	W.	D.	L.	CAT.NO.	PRICE
2-Button	3 in.	2 1/2	5-3/4	4022	\$148.92
3-Button	3 in.	2 1/2	7-1/2	4023	215.40
4-Button	3 in.	2 1/2	9 in.	4024	279.08
6-Button	3 in.	2 1/2	12-3/8	4026	418.28

E-Z Grip Control for AC and DC Motors. Molded Safety Yellow nylon enclosure and coverplate with rubber pushbutton diaphragm. Single-speed, double throw, momentary contact.

Catalog Number	Description
4052 \$58.70	Two-button, single-speed pendant station. 7 in. overall length X 1.75 in. 10 Amp, 125 or 250 VAC. 1 H.P. 125 or 250 VAC.



NO. 4052

RECEPTACLE TESTERS

A trio of safety checkers for the tool box or electrician's kit. No. 1750 provides a convenient means for testing 3-wire 115VAC single phased polarized receptacles for proper connection of ground wire, correct polarity, or fault in any of the three wires. No. 1753 GFI Receptacle Tester is used in conjunction with No. 1750 to determine if receptacle is protected by properly operating GFI. No. 1756 is a combination Duplex Circuit Tester and Tool Ground Continuity Tester.

Receptacle Circuit Tester	CAT. NO. 1750	\$22.06
G Receptacle Tester	CAT. NO. 1753	28.40
Tool Ground Continuity Tester	CAT. NO. 1756	44.70


Replacement switches, covers, etc. are available for Push Button Stations. A salesperson at any of the toll-free numbers listed on the back of this catalog will be glad to supply prices, availability, literature, etc.

Designed to meet the requirements of critical applications, **Watertite Plugs** and connectors are constructed of NEO₂TE₂X rubber to provide a sure seal against oil, moisture, and dirt - without the boot required by other manufacturer's devices.



Super Safeway Plugs and connectors are also constructed with NEO₂TE₂X rubber for safety, yet can withstand the impact and abrasion of tough industrial service.

Rugged nylon **Safeway Plugs** and connectors resist the punishment of everyday applications.

 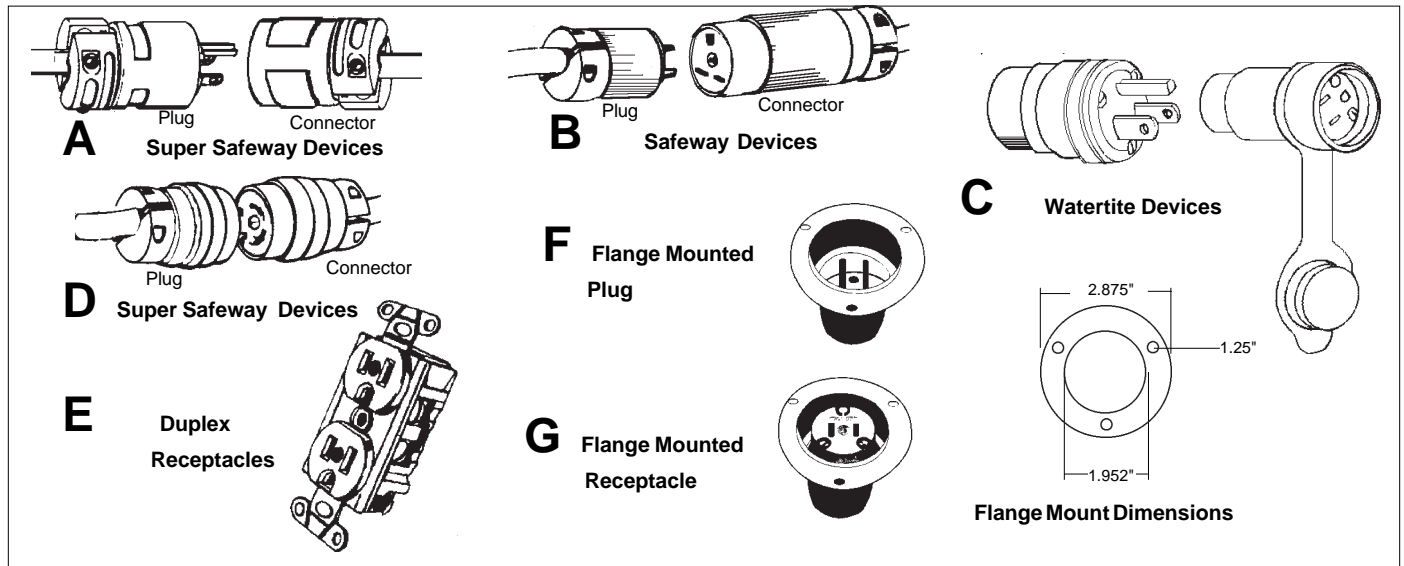

 

 
 
 
 
 

 
Our **Duplex Receptacles**, available in Specification-grade and Hospital grade, are designed for easy wiring, long life, and safety







2-POLE, 3-WIRE GROUNDING

PART NO.	PRICE	DESCRIPTION	STYLE	CORD SIZE	NEMA CONFIGURATION	AMPS	VOLTS
14W47	\$13.09	Plug, Non-Locking	C	0.312-0.625in.		15 AMP	125V
15W47	19.19	Connector with closure seal					
1447	7.44	Plug, Non-Locking	A	0.335-0.640in.			
1547	13.73	Connector, Non-Locking					
5266	8.30	Plug, Black, Non-locking	B				
85266YL	9.16	Hospital Grade Plug, Yellow, Non-Locking					
85266ORG	9.16	Hospital Grade Plug, Orange, Non-Locking					
5269	14.68	Connector, Black, Non-Locking					
85269YL	16.14	Hospital Grade Connector, Yellow Non-Locking					
5262DW	12.12	Heavi-Spec Duplex Receptacle, Brown	E				
5262DWI	12.65	Heavi-Spec Duplex Receptacle, Ivory					
5262DWIG	16.95	Spec-Grade Isolated Ground Duplex Receptacle, Orange					
85262DW	14.99	Hospital Grade, Heavi-Spec Duplex Receptacle, Brown					
85262DWI	15.16	Hospital Grade, Heavi-Spec Duplex Receptacle, Ivory					
85262DWIG	21.68	Hospital Grade Isolated Ground Duplex Receptacle, Orange					
5252DW	7.13	Gen-Spec Duplex Receptacle, Brown					
5252DWI	7.54	Gen-Spec Duplex Receptacle, Ivory					
5252DWW	8.93	Gen-Spec Duplex Receptacle, White					
5252GF	34.98	GFCI Receptacle, Brown					
5252GF-I	34.98	GFCI Receptacle, Ivory					
85252GF-W	75.87	GFCI Receptacle, Hospital Grade, White					
24W47	12.96	Plug, Turnex Locking	C	0.312-0.625in.		15 AMP	125V
25W47	19.73	Connector with closure seal, Turnex Locking					
2447	8.43	Plug, Turnex Locking	D	0.335-0.640in.			
2547	14.23	Connector, Turnex Locking					
4720	8.60	Plug, Black, Turnex Locking	B	0.335-0.640in.			
4729	15.00	Connector, Black, Turnex Locking					
2447MB	14.23	Flanged Receptacle (Same as 4720 flange mount)	F	0.312-			
2547MB	14.23	Flanged Receptacle (Same as 4729 flange mount)	G	0.625in.			

2-POLE, 3-WIRE GROUNDING Continued

PART NO.	PRICE	DESCRIPTION	STYLE	CORD SIZE	NEMA CONFIGURATION	AMPS	VOLTS
14W49	\$13.97	Plug, Non-Locking	C	0.312-0.625in.	NEMA 6-15 	15 AMP	250V
15W49	15.01	Connector, with closure seal, Non-Locking	B	0.335-0.640in.			
5666	9.02	Plug, Black, Non-Locking		0.335-0.640in.			
5669	15.61	Connector, Black, Non-Locking	E	0.335-0.640in.			
5662DW	15.07	Heavi-Spec Duplex Receptacle, Brown					
5662DWI	15.65	Heavi-Spec Duplex Receptacle, Ivory	A				
1449	7.88	Plug					
1549	14.57	Connector					
1449MB	13.48	Flanged Inlet (Same as 5666 with flange mount)	F		NEMA 7-15 	15 AMP	277V
1549MB	14.31	Flanged Receptacle (Same as 5669 flange mount)	G				
14W34	13.14	Plug, Non-Locking	C	0.312-0.625in.	NEMA L7-15 	15 AMP	277V
15W34	19.87	Connector, with closure seal, Non-Locking					
24W34	14.96	Plug, Turnex Locking	C	0.312-0.625in.	NEMA 5-20 	20 AMP	125V
25W34	23.40	Connector, with closure seal, Turnex Locking					
14W33	14.39	Plug, Non-Locking	C	0.312-0.625in.	NEMA L5-20 	20 AMP	125V
15W33	20.82	Connector, Non-Locking					
1433	9.91	Plug, Non-Locking	A	0.335-0.640in.	NEMA 6-20 	20 AMP	250V
1533	15.01	Connector, Non-Locking					
5366	9.57	Plug, Black, Non-Locking	B	0.335-0.640in.	NEMA L16-20 	20 AMP	480V 3 Phase
5369	15.73	Connector, Non-locking					
5362DW	14.55	Heavi-Spec Duplex Receptacle, Brown	E		NEMA L14-30 	30 AMP	125/250V
5362DWI	15.31	Heavi-Spec Duplex Receptacle, Ivory					
26W47	19.73	Plug, Turnex Locking	C	0.500-0.687in.	NEMA L15-30 	30 AMP	250V 3 Phase
27W47	28.94	Connector, Turnex Locking					
2647	11.48	Plug, Turnex Locking	D	0.405-0.815in.	NEMA L16-30 	30 AMP	480V 3 Phase
2747	17.90	Connector, Turnex Locking					
2647MB	14.23	Flanged Inlet (Same as 2647 flanged mount)	F				
5466	9.25	Plug, Black, Non-Locking	B	0.335-0.640in.	NEMA L16-20 	20 AMP	480V 3 Phase
5469	15.61	Connector, Black, Non-Locking					
5462DW	17.74	Heavi-Spec Duplex Receptacle, Brown	E				

   3-POLE, 4-WIRE GROUNDING

26W76	26.75	Plug, Turnex Locking	C	0.325-0.840in.	NEMA L16-20 	20AMP	480V 3 Phase
27W76	35.30	Connector, turnex Locking, with closure seal					
28W74	32.76	Plug, Turnex Locking	C	0.562-1.000in.	NEMA L14-30 	30AMP	125/250V
29W74	56.23	Connector, Turnex Locking, with closure seal					
28W75	32.76	Plug, Turnex Locking	C	0.625-0.812 in.	NEMA L15-30 	30AMP	250V 3 Phase
29W75	56.23	Connector, Turnex Locking, with closure seal					
28W76	32.77	Plug, Turnex Locking	C	0.562-1.000in.	NEMA L16-30 	30 AMP	480V 3 Phase
29W76	55.94	Connector, Turnex Locking, with closure seal					