

PANEL MOUNT SELECTION GUIDE

PUSHBUTTONS

ROCKERS

IM SERIES

- Snap-action, audible tactile feedback
- Ø12mm panel cutout
- Sealed to IP67
- NC+NO
- Multiple colors available



IP SERIES

- Solid and illuminated
- Tactile feedback
- Variety of terminal options
- Round or square actuator
- Sealed to IP67
- Momentary or latching function



IB SERIES

- Momentary (NO) with tactile feedback
- Snap-in mount
- Tactile feedback
- Sealed to IP54
- Solder lug, quick connect or PC terminals



KR SERIES

- Solid or illuminated
- Sealed up to IP68
- Laser etched symbols
- Large color selection
- Unique rocker design



IS SERIES

- Momentary (NO) with tactile feedback
- Threaded bushing
- Tactile feedback
- Sealed to IP67
- Solder lug, quick connect or PC terminals



 
IC SERIES

- Momentary (NO) with tactile feedback
- Metal bushing
- Sealed to IP67
- Round or square actuator
- Variety of actuator colors available



IL SERIES

- Solid or illuminated
- Ø12mm panel cutout
- Sealed to IP67
- Reduced bezel option available
- Available with solder lug, PC pins or wire leads



KL SERIES

- Solid or illuminated
- Single sided locking feature
- Sealed up to IP68
- Laser etched symbols
- Large color selection
- Unique rocker design



IZ SERIES

- Solid or illuminated
- Ø16mm panel cutout
- Rear mount
- Sealed to IP67
- Available in metal and plastic body



IA SERIES

- Soft feel, membrane actuator
- Tactile feedback
- Sealed to IP67
- Resistant to dust, sand, water, frost
- Variety of actuator colors



IR SERIES

- Solid or illuminated
- Ø16mm panel cutout
- Round or square bezel shape
- Sealed to IP67
- Available with solder lug, PC pins or wire leads



KG SERIES

- Solid or illuminated
- Raised protection bezel
- Sealed to IP65
- Standard symbols available
- Variety of color choices



IQ SERIES

- Solid or illuminated
- 16mm cutout
- Snap in mount
- Sealed to IP54
- Momentary or latching
- Round or square bezel shape



IHS SERIES

- Hall effect
- Sealed to IP67
- Momentary (NO)
- Rated to 5 million cycles
- Ø12mm panel cutout



IHL SERIES

- Hall effect
- Linear 0.5 to 4.5V output
- Sealed to IP67
- Rated to 5 million cycles
- 3 different force ratings available
- Ø12mm panel cutout



2600 SERIES

- Solid or illuminated
- 16A 125VAC
- Single or double pole
- 3 rocker shapes
- Peak currents available



13000 SERIES

- 1/4" threaded bushing
- Single or double pole
- Silver or gold plated contacts
- Quick break momentary
- Several cap colors available



13000X778

- High performance
- Threaded bushing
- Double pole, double throw
- Fully sealed to IP67



13000 PUSH/PULL

- Unique ergonomic Push-pull function
- 24.8mm red anodized aluminum actuator
- O-ring, epoxy sealed
- 4 A 24VDC



FM SERIES

- Solid or illuminated
- 16A 125VAC
- Single or double pole
- Protective boot available



FP SERIES

- 24, 26 & 30mm bushing
- Momentary or latching
- Pad printed or laser etched marking available
- Fully backlit legends
- Snap in or threaded mounting



FD SERIES

- 24 & 26mm bushing
- Momentary or latching
- Fully backlit legends
- Snap in or threaded bushing
- Threaded bushing sealed up to IP69K



RP SERIES

- Momentary (NO) with tactile feedback
- Sealed to IP67
- Resistant to frost
- 6" and 12" wire leads



MT SERIES

- Single pole, double throw
- Rocker/Toggle function
- Rated up to 6A 125VAC
- Several actuator option
- Sealed to IP67



10400 SERIES

- Momentary with solder lug terminals
- Single or double pole
- Silver or gold plated contacts
- Optional color caps



8000 SERIES

- Momentary or alternate action
- Single or double pole
- Long bushing
- Numerous plunger, bushing & accessory options



1200 SERIES

- Up to 8A 125VAC
- Momentary NC+NO action
- Single pole
- Plastic or metal plunger
- UL, CSA, VDE



AS SERIES

- Snap-in, single pole
- 2 or 3 positions
- Sealed and double insulated
- Solder lug or PC terminals
- Several actuator colors



9400 & 9600

- Momentary, NC, NO or NC/NO
- Two case lengths
- Sealing options
- Several plunger options



800 & 18000

- Snap action momentary
- 18000 – miniature, to 1A
- Single or double pole
- Solder lug or PC terminal
- Epoxy sealed



300, 400 & 9000

- Threaded bushing selections
- Compact, cylinder shape
- Single pole, single throw NC+NO
- Solder lug or PC terminals



7000 SERIES

- Single or double pole
- Rocker or Paddle style
- Wide variety of actuators
- Actuator and bezel color options



4700 & 4800

- 6A 125VAC
- Alternate action
- Single or double pole
- Full actuator return
- Multiple actuator colors



1400N

- Momentary pushbutton
- Butt action contacts, double break
- Solder lug, straight PC and quick connect
- Snap-in mounting



LPI SERIES

- Large, 35mm actuator
- Tactile feedback
- Low behind panel depth
- Stylish design
- 5,000,000 cycles for 0.5A version



S & SR

- Single or double pole
- Rocker or Paddle style
- Silver or gold plated contacts
- Different actuator styles and colors





PANEL MOUNT SELECTION GUIDE

TOGGLES

12000X778

- High performance toggle
- Mil STD 3950 & 83731
- 15/32" threaded bushing
- Sealed to IP67
- Double shelled case & pinned lever



3500 SERIES

- Industrial grade and fully sealed
- 20A 125VAC
- Single or double pole
- 15/32" bushing
- Sealed to IP67
- Variety of lever styles



5000 SERIES

- Miniature toggle with 6 bushing options
- 17 different actuator styles
- 1, 2, 3 and 4 pole
- 8 functions including maintained and momentary



55000 SERIES

- VDE approved
- Miniature toggle with 6 bushing options
- 17 different actuator styles
- 8 functions including maintained and momentary



CT SERIES

- High volume, cost effective
- 100,000 lifecycles
- Three terminal options
- Rated up to 10A at 250VAC
- Front panel sealed up to IP67



600H & 600NH

- 16A 125VAC
- 1, 2 and 3 pole
- 2 and 3 maintained or momentary positions
- Metal or insulated lever
- Locking lever options



 
11000 SERIES

- Robust, threaded bushing
- 2 position toggle
- 1, 2, 3 and 4 pole
- Several front panel sealing options
- CECC approved



12000 SERIES

- Larger 15/32" threaded bushing
- 1, 2, 3 and 4 pole
- DPDT, 3PDT, 4PDT
- Several locking lever options
- Peak current versions available



3600NF

- 6A 250VAC
- Single or double pole
- Fully sealed
- Locking lever options
- UL Listed



1600 & 1700

- Single or double pole
- 4A 125VAC
- Single pole with metal or insulated lever
- 2 & 3 maintained positions



6000 SERIES

- 10A 125VAC
- 1, 2, 3 and 4 pole
- Solder, screw or quick-connect terminals
- Sealing and locking lever options



10600 SERIES

- Single or double pole
- 2 & 3 positions
- Large, threaded bushing
- Matte black available



4400 & 4600

- 6A 125VAC
- 1, 2 and 3 pole
- High current/voltage rating in a small case
- Metal or insulated lever



ZL SERIES

- Single pole
- Ø 4,83 mm threaded bushing
- Silver or gold plated contacts
- Epoxy sealed
- Additional actuator lengths available



1000 SERIES

- 6A 125VAC
- Single pole, 2 & 3 positions
- Optional insulated levers
- Metal lever & bushing



MT SERIES

- Single pole, double throw
- Toggle / Rocker function
- Several actuator option
- Rated up to 6A 125VAC
- Sealed to IP67



MSG TOGGLE GUARDS

- 10A 125VAC
- Single pole, 2 & 3 maintained positions
- Insulated lever & bushing
- Variety of actuator styles & colors



METAL TOGGLE GUARDS

- 10A 125VAC
- Single pole, 2 & 3 maintained positions
- Insulated lever & bushing
- Variety of actuator styles & colors



ANTI VANDAL

AV SERIES - 16mm

- Momentary (NO) with tactile feedback
- Snap-in mount
- Tactile feedback
- Sealed to IP54
- Solder lug, quick connect or PC terminals



AV SERIES - 19mm

- Solid or illuminated
- Sealed up to IP68
- Laser etched symbols
- Large color selection
- Unique rocker design



AV SERIES - 22mm

- Solid or illuminated
- Ø12mm panel cutout
- Sealed to IP67
- Reduced bezel option
- Available with solder lug, PC pins or wire leads



AV SERIES - 24mm

- Solid or illuminated
- Single sided locking feature
- Sealed up to IP68
- Laser etched symbols
- Large color selection
- Unique rocker design



AV SERIES - 30mm

- Solid or illuminated
- Ø16mm panel cutout
- Round or square bezel shape
- Sealed to IP67
- Available with solder lug, PC pins or wire leads



AV SERIES - 250V

- Solid or illuminated
- Raised protection bezel
- Sealed to IP65
- Standard symbols available
- Variety of color choices



PIEZO

PBA SERIES

- High performance
- Available in Ø16, 19 or 22mm
- Sealed up to IP68 & IP69K
- Metal surface with ring or dot illumination
- ATEX certi



CAPACITIVE

CP and CG


- Momentary (NO) with tactile feedback
- Sealed to IP67
- Resistant to frost
- 6" and 12" wire leads



SNAP-ACTION

MA, MB, MD

- Threaded bushing selections
- Compact, cylinder shape
- Single pole, single throw NC+NO
- Solder lug or PC terminals

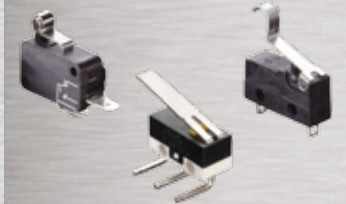

PUSHWHEELS



DP, SH, PICO

- Threaded bushing selections
- Compact, cylinder shape
- Single pole, single throw NC+NO
- Solder lug or PC terminals