



- Home
- About us ▶
- Products ▶
- Industries ▶
- Literature ▶
- News ▶
- Contact us ▶
- Search
- Supplier log-in

Search Catalog

By Keyword

- All Categories
- Broadband Split / Snap-on Ferrite Cores for Round Cables

[All Categories](#) > [EMC / EMI Board Level and Cable Core Products](#) > [Ferrite Cores for Cables - Wiring Harnesses - Connectors](#) > [Round and Cylindrical Cores](#) > [Broadband Split / Snap-on Ferrite Cores for Round Cables](#) > **Item # 28A 2025-0A0**

[Request Information](#)

Item # 28A 2025-0A0


[Printable Page](#)

[Email This Page](#)

[Save To Favorites](#)



[larger image](#)

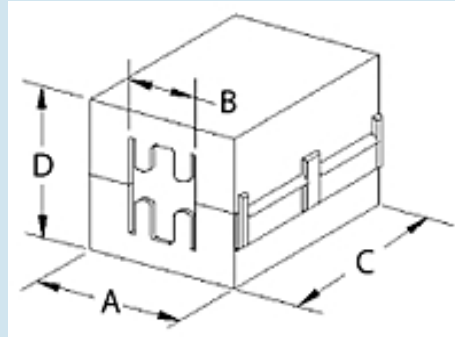

[larger image](#)

MORE IMAGES

[Impedance Curves](#)

DOWNLOADS

[Part Number Nomenclature \(PDF, 305KB\)](#)

Specifications	Features	Applications
Figure Number	2	
Case A	17.58 mm	
Case B	7.26 mm	
Case C	32.03 mm	
Case D	17.80 mm	
Max. Cable Diameter	0.250 in 6.35 mm	
Typical Z Ohms at 25 MHz	130	
Nominal Z Ohms at 100 MHz	320	
Typical Z Ohms at 300 MHz	510	
Material Type	Broad Band Material	
Product Type Code	Split round cores (Snap-Ons)	
Part Size Code	2025	
Additional Description	Plastic Case	
Case Color	White	

[Request Information](#)