


R/RSC-Series

Single Pole Lighted Rocker & Paddle Switches

PRODUCT WEBPAGE

request sample, configure part

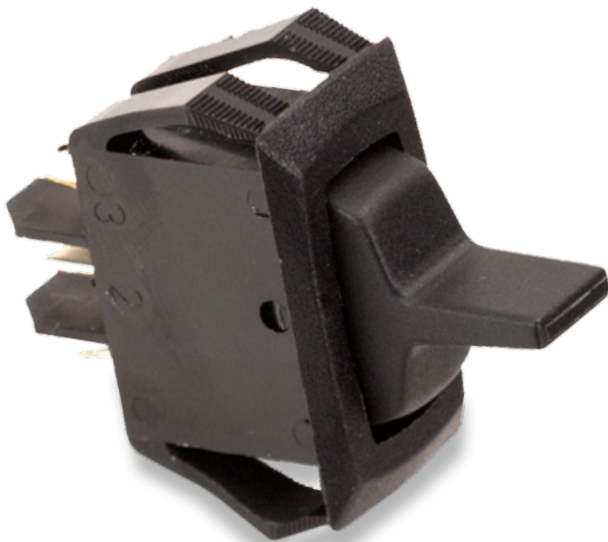

Since its introduction, the Corvette switch has become the barometer for versatility and performance in the switch market. Self cleaning contacts, international approvals, along with a wide variety of circuits, ratings, and actuator options make the Corvette the switch of choice for many markets.

1
Pole

10-20
Amps

125-250
VAC

6-24
VDC

Typical Applications

- Office Lighting
- HVAC
- Commercial Food
- Medical Equipment
- Appliance
- On-Highway
- Lawn & Garden

Tech Specs

Dielectric Strength

UL/CSA: 1000V - live to dead metal parts
VDE: 4000V - live to dead metal parts;
750V - across open contacts

Electrical Life

100,000 cycles

Operating Temperature

32°F to 185°F (0°C to 85°C)

Ordering Scheme

Sample
Part Number

RA901 - V B - B - 9 - V

Selection

1

2

3

4

5

6

1. SERIES

10A 250 VAC; 16A 125 VAC; 3/4 HP 125-250 VAC; 10(4) A 250 VACu
T85

OFF-NONE-ON	Solder Lugs	.250 Tabs	Wire Leads
ON-NONE-ON	RA900	RA901	RA905
ON-OFF-ON ³	RB900	RB901	RB905
OFF-NONE-(ON) ²	RC910	RC911	RC915
	RD220	RD221	RD225

15A 250 VAC; 20A 125 VAC; 3/4 HP 125-250 VAC

OFF-NONE-ON	Solder Lugs	.250 Tabs
ON-NONE-ON	RSCA200	RSCA201
	RSCB200	RSCB201

2. ACTUATOR STYLE

M	Momentary Rocker	R	Rocker
P	Paddle	V	Visi-rocker (2 color)

3. ACTUATOR COLOR

1	Black (gloss)	B	Black (matte)
2	White (gloss)	W	White (matte)

4. BEZEL COLOR

STANDARD		OVAL	
B	Black (matte)	1	Black (gloss)
W	White (matte)	2	White (gloss)

5. ROCKER LEGEND

NO LEGEND	molded in	hot stamp
Off-On vertical	0	0
Off-On horizontal	1	A
O-I horizontal	2	B
O-I vertical	8	D
dual OFF-ON/O-I	9	E
	n/a	H

6. VISI-ROCKER END / LEGEND COLOR

N	N/A	V	Visi-red
B	Black	W	White

Notes: PC Terminals also available, consult factory for details.

1 For additional ratings, consult factory.

2 Rating is 8A 250 VAC, 12A 125 VAC, 1/2 HP 125-250 VAC, and must specify M actuator style.

3 Not rated at 3/4 HP 125-250 VAC

() indicates momentary function.

[Configure Complete Part Number >](#)

[Browse Standard Parts >](#)

Dimensional Specs

inches [millimeters]

