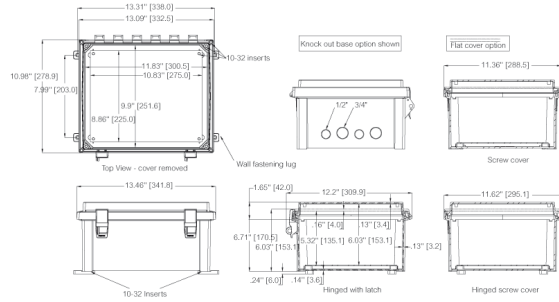


**Product #:** 8561543**Order Symbol:** ARK12106CHSSLT

Description: Hinged transparent cover enclosure with lockable stainless-steel latch, with knock out base.

Remarks: PC Enclosure with Knock-Out Base, Hinged Transparent Cover with Stainless Steel Latches

Dimensions	Height	Width	Depth
Inch	12	10	6
mm	304.8	254	152.4

Materials

Material:	Polycarbonate
Base color:	RAL 7035 -light grey
Cover color:	Transparent
Gasket material:	Polyurethane

Temperatures

Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175
Temperature °C (short term):	-40 ... 140
Temperature °C (continuous):	-40 ... 80

Ratings

Ingress Protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK09;
Electrical insulation:	Fully insulated
Halogen free (DIN/VDE 0472, Part 815):	Yes
UV resistance:	UL 508
Flammability Rating:	UL94-5VA (f1)/ Cover: UL94-V0 (f1)
Glow Wire Test (IEC 60695):	960 °C
UL/cUL Type:	NEMA 4, 4X, 6, 6P, 12, 12K and 13