



Wiring Device-Kellems

Submittal

Table of Contents

SKU	Asset Type	Page
HBL2510AR	Specification Sheet	2

Twist-Lock® Devices
20A, 3 Phase Y 120/208V AC, 4 Pole, 5 Wire
Grounding
Safety-Shroud® Receptacle



Features

- Alignment arrows with lock and unlock symbols provide a visual indication that devices are properly connected
- Catalog number and color coded voltage rating are visible even when in use
- Engineered thermoplastic housing is impact and corrosion resistant, making it suitable for heavy-duty industrial environments

Ordering Information

Description	Device Color	UPC	Catalog Number
RPT angle housing, one gang.	Gray	783585234960	HBL2510AR

Listings

Listed to UL 498
Fed.Spec. W-C-596
Certified to CSA C22.2 No.42

Specifications

Housing / Flange	Gray RPT
Terminal Retainer	Clear polycarbonate
Body Contact Carrier	Natural (white) nylon
Body Holding Screws	Steel, zinc plated
Contacts	Brass
Mounting Plate	Steel, zinc plated

Performance


Electrical	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum

Mechanical	
Terminal Accommodation	#16 AWG - #8 AWG solid or stranded copper wire only.
Terminal Identification	Terminals identified in accordance with UL 498

Environmental	
Flammability	V2 or better per UL94/CSA 22.2 No.0.17
Moisture Resistance	IP20 Suitability
Operating Temperatures	Maximum Continuous 75°C; Minimum -40°C (w/o impact)



20A 3ØV
120/208V AC
NEMA L21-20R
UL/CSA
2 HP

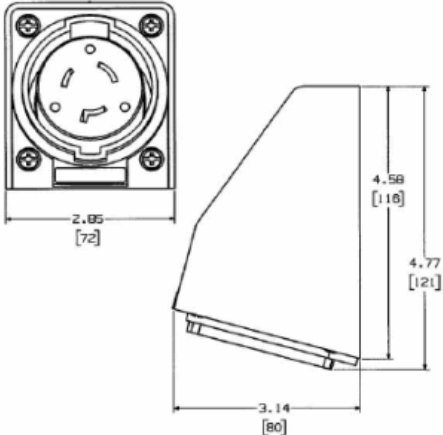

Accessories

Plug	HBL2511S
------	----------

Resources

Customer Use Drawing
eCatalog

