

Single Pole Devices and Temporary Power

400A, 600V AC/250V DC

Stud Type Male Receptacles



Ordering Information

Description	Device Color	UPC	Catalog Number
400 A,Panel Mount, thermoplastic elastomer,mates with 300 and 400A plugs	Green	783585093543	HBLMRSCGN




Standards

UL and cUL Listed
UL Enclosure Types 3R, 4X, 12
National Electric Code (NEC), ANSI/NFPA 70

Specifications

Base Compound	Thermoplastic Elastomer
Contact Material	Brass
Retaining Screw Material	Nylon
Mounting Hole	4x Ø .20"
Termination	1/2-13 UNC-2A Threaded Stud

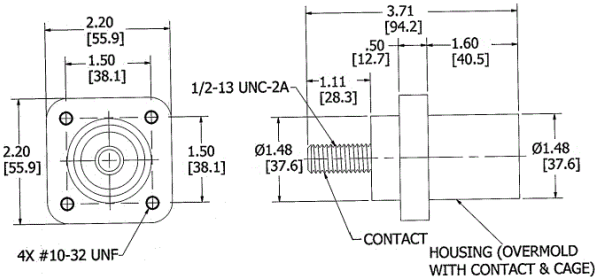

Performance

Electrical	
Amperage Rating	400A Maximum
Voltage Ratings	600V AC Maximum; 250V DC Maximum
Mechanical	
Product Identification	Ratings are a permanent part of device
Terminal Accommodation	#4 to 4/0 AWG
Environmental	
Flammability	HB per UL94 or CSA 22.2. 0.17

Online Resources

- Customer Use Drawing
- eCatalog
- Installation Instructions

