


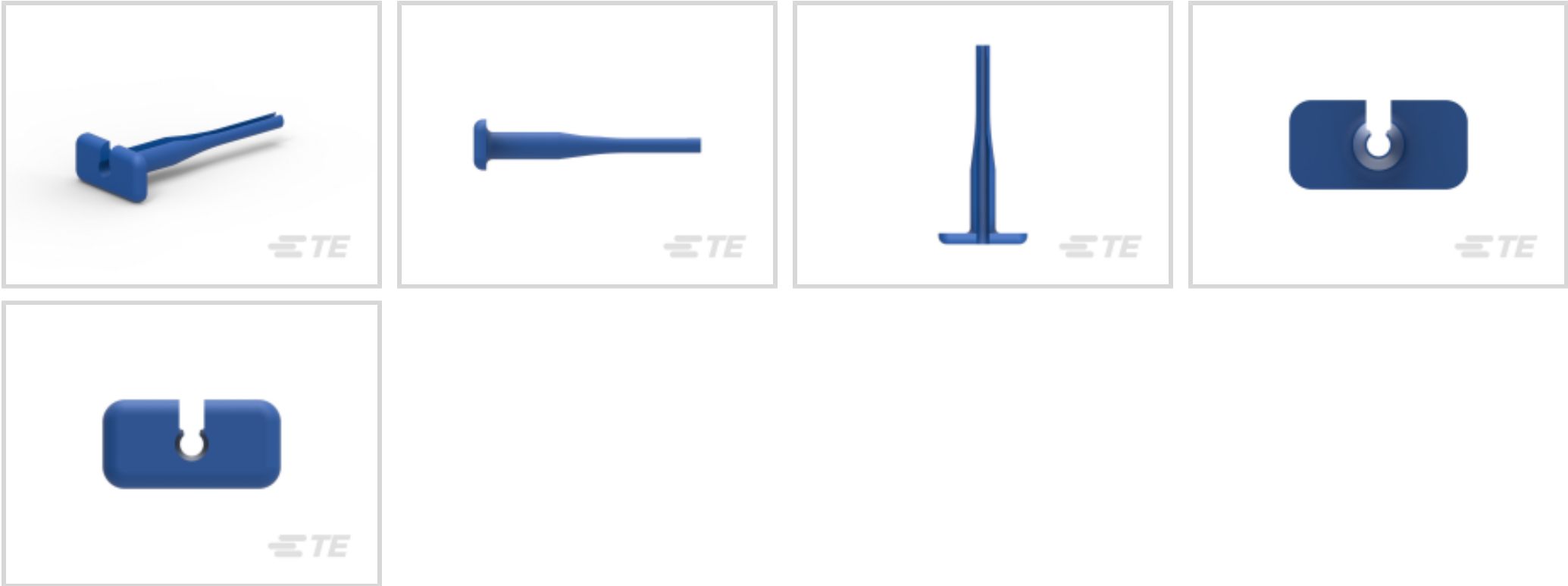

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

 
 
 
 
 
 
 
 
 
 
 
 
 
 
EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2023 (235) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



 TE Part # 2301337-1 HDP24-24-91PE-P064, REC, 9P, E,8/12/16,P	 TE Part # CAT-D799-CH8172 DEUTSCH DRC Housings	 TE Part # AEC16-40SDE-E019 PLG, 40P, BLK, E, XCAP, D	 TE Part # AEC16-40SAE-K001 PLG, 40P, BLK, E, BRN CAP, A
 TE Part # CAT-H3910-CH8172 DEUTSCH HD10 Housings	 TE Part # AEC16-40SBE PLG, 40P, BLK, E, B	 TE Part # HDP24-24-21PE-9974 REC, 21P, BLK, E, 12/16, P	 TE Part # AEC14-40PABE-E019 REC, 40P, BLK, E, XCAP, AB
 TE Part # AEC16-40SCE-E019 PLG, 40P, BLK, E, XCAP, C	 TE Part # AEC16-40SCE PLG, 40P, BLK, E, C	 TE Part # AEC14-40PCE-E019 REC, 40P, BLK, E, XCAP, C	 TE Part # AEC14-40PDE-E019 REC, 40P, BLK, E, XCAP, D
 TE Part # CAT-H396-CH8172 DEUTSCH HDP20 Housings	 TE Part # AEC16-40SAE PLG, 40P, BLK, E, A	 TE Part # CAT-H3930-CH8172 DEUTSCH HD30 Housings	 TE Part # 2301339-1 HDP26-24-91SE-P064, PLG, 9P, E, NOJMP, S
 TE Part # AEC16-40SDE PLG, 40P, BLK, E, D	 TE Part # AEC16-40SUE-E019 PLG, 40P, BLK, E, XCAP, U	 TE Part # JS-16-00 JIFFY SPLICE, Size 16	

Also in the Series | **DEUTSCH HD**




Automotive Housings(670)



Automotive Seals & Cavity Plugs(10)



Connector Strain Relief(6)

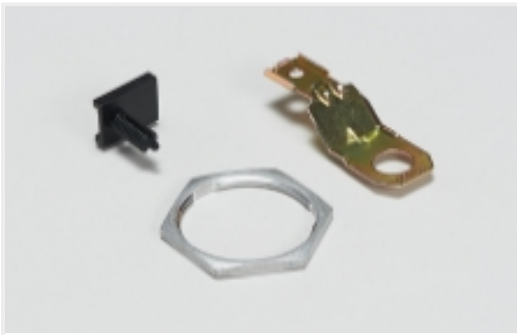

Other Automotive Connector Accessories(17)

Customers Also Bought

TE Part #114010-ZZ
EXT TOOL, SIZE 12, 12 AWG, N, YEL

TE Part #0411-310-1605
EXT TOOL, SIZE 16, 16-18 AWG, T, LT BLU

TE Part #0462-201-16141
SOC, SOLID, SIZE 16, 16-20AWG, NI

TE Part #0411-337-1205
EXT TOOL, SIZE 12, 12-14 AWG, E, ORG

TE Part #HD34-24-31PT-B019
REC, 31P, AL, T, CUSTOM MOUNT, 16, P

TE Part #0411-240-2005
EXT TOOL, SIZE 20, 16-22 AWG, N, RED

TE Part #0411-353-0805
EXT TOOL, SIZE 8, 8-10 AWG, N, GRN

TE Part #0411-291-1405
EXT TOOL, SIZE 16, 14-16 AWG, N, GRN

TE Part #114008-ZZ
EXT TOOL, SIZE 8, 8-10 AWG, N, GRN

TE Part #2310361-1
1062-16-0122

Documents

Product Drawings
EXT TOOL, SIZE 16, 16-20 AWG, E, DRK BLU
English

CAD Files
3D PDF
3D
Customer View Model
ENG_CVM_CVM_0411-336-1605_C.2d_dxf.zip



English

Customer View Model

[ENG_CVM_CVM_0411-336-1605_C.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_0411-336-1605_C.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English