

Product data sheet

Specifications



Socket, SE Relays, 10A, 17 pins, screw connectors, mixed contact, for 782 relays

70-782E14-1

 To be discontinued on: Sep 30, 2025

 To be discontinued

Product availability: Non-Stock - Not normally stocked in distribution facility

Main

Product Range	Harmony Electromechanical Relays
Product Type	Socket
Product Compatibility	relay 792XDX relay 782XDXH diode 70-BSMD signalling device 70-BSMLG suppressor module 70-BSMM jumper wire 16-782CBJ-1
Number of Terminals	14
Switch Function	4PDT
Contact Composition	4 C/O

Complementary

Rated Current	10 A
[Ue] rated operational voltage	300 V
Contact Terminal Arrangement	Separate
Connections Terminals	Panel lift terminals, clamping connection capacity:2 x 1.5...1 x 2.5 mm², AWG 16...AWG 14 flexible with cable end Panel lift terminals, clamping connection capacity:2 x 1.5...1 x 2.5 mm², AWG 16...AWG 14 solid with cable end
Tightening Torque	0.8 N.m, AWG 16...AWG 14, copper Screw 0.8 N.m
Fixing Mode	By screw, M3 panel Clip-on 35 mm symmetrical DIN rail
Shape of Screw Head	Combination roundhead
Product Weight	2.0 oz (56 g)
Width	1.06 in (26.9 mm)
Depth	3.1 in (79 mm)

Environment

Ambient Air Temperature for Storage	-40...221 °F (-40...105 °C)
Ambient Air Temperature for Operation	-40...158 °F (-40...70 °C)
IP Degree of Protection	IP20
Flame Retardance	UL94-V0

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Product Certifications	UL
	CSA
	CE

Ordering and shipping details

Category	US10CP221127
Discount Schedule	0CP2
GTIN	3606480278129
Returnability	No
Country of origin	CN

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3.11 in (7.9 cm)
Package 1 Width	1.06 in (2.69 cm)
Package 1 Length	3.11 in (7.9 cm)
Package 1 Weight	2.0 oz (56 g)
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Height	2.85 in (7.25 cm)
Package 2 Width	3.54 in (9 cm)
Package 2 Length	5.41 in (13.75 cm)
Package 2 Weight	19.8 oz (560 g)
Unit Type of Package 3	CAR
Number of Units in Package 3	200
Package 3 Height	7.09 in (18 cm)
Package 3 Width	11.81 in (30 cm)
Package 3 Length	18.50 in (47 cm)
Package 3 Weight	24.7 lb(US) (11.2 kg)

Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint	
Carbon footprint (kg CO2 eq, Total Life cycle)	1

Use Better


Materials and Substances	
Packaging made with recycled cardboard	Yes
Packaging without single use plastic	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
REACH Regulation	REACH Declaration
California proposition 65	WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Use Again

Repack and remanufacture	
Circularity Profile	No need of specific recycling operations
WEEE	 The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.

Dimensions Drawings

Dimensions

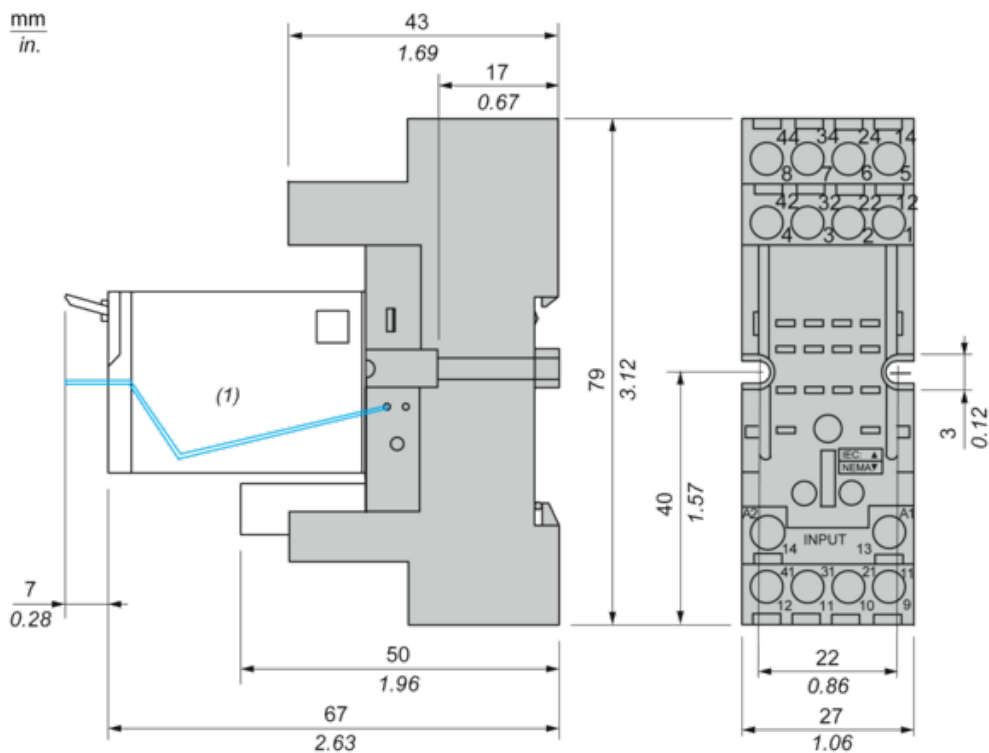

(1) : Metal hold-down clip

Technical Illustration

Dimensions

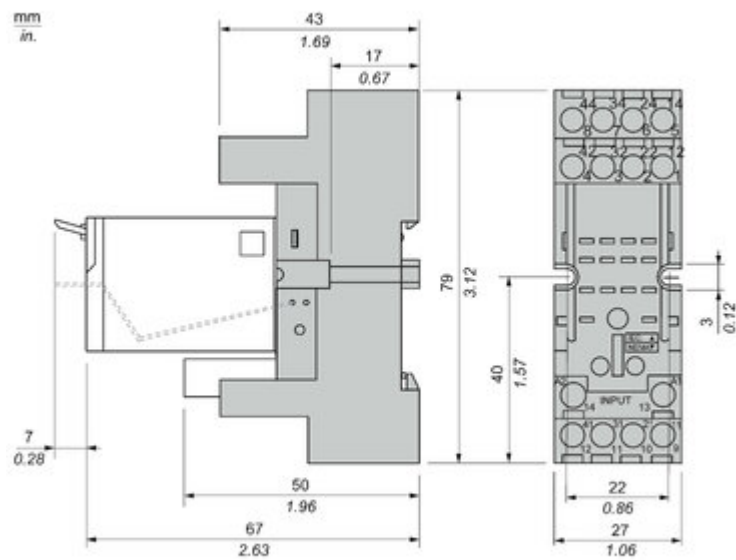


Image of product in real life situation

