





MDC (M12) Series Cordsets

4 Conductor MDC Series Cordsets, 18/22AWG



Right Angle Female Cordsets | 300 Volt, 4 amps | IP69 Rating

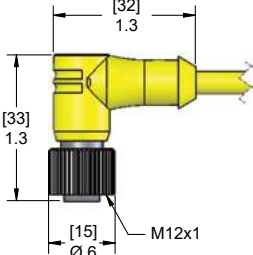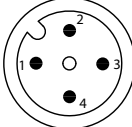

Connector Body Style	Part Number	Cables	Features	Color Code	Faceview
	MDC-4FPX-**-R (Yellow) MDC-4FPX-**-R-B (Black)	PVC AWM 4 X 18 AWG 300V, 4A -40°C to +105°C 7.4mm OD	Industry Standard PVC	1. Brown 2. White 3. Blue 4. Black 5. Not Used	 M12x1
	MDCP-4FPX-**-R	Yellow PUR AWM 4 X 18 AWG 300V, 4A -40°C to +80°C 7.4mm OD	Oil and Cutting Fluid Resistant Cut Resistant PUR		
	MDCW-4FPX-**-R	Yellow TPE AWM 4 X 18 AWG 300V, 4A -40°C to +80°C 7.4mm OD	Weld Slag Resistant TPE		
	MDC-4FP-**-R (Yellow) MDC-4FP-**-R-B (Black)	PVC AWM 4 X 22 AWG 300V, 4A -40°C to +105°C 5mm OD	Industry Standard PVC		
	MDCM-4FP-**-R	Yellow PVC AWM With Foil Shield 4 X 22 AWG 300V, 4A -40°C to +105°C 5mm OD	Industry Standard PVC Foil Shield		
	MDCP-4FP-**-R	Yellow PUR AWM 4 X 22 AWG 300V, 4A -40°C to +80°C 5mm OD	Oil and Cutting Fluid Resistant Cut Resistant PUR		
	MDCW-4FP-**-R	Yellow TPE AWM 4 X 22 AWG 300V, 4A -40°C to +80°C 5mm OD	Weld Slag Resistant TPE		
	MDCWF-4FP-**-R	Black TPE AWM 4 X 22 AWG 300V, 4A -40°C to +80°C 5mm OD	Hi-Flex Weld Slag Resistant TPE		

** Lengths in meters. Standard cable lengths are 1, 2, 4, 5, 6, 10 & 15 meters. Consult the factory for other lengths.

2~5 Pole females will have all 5 contact holes in the connector.

Standard coupling nut is nickel plated brass, for stainless steel coupling nut add a "-SS" suffix. (e.g. MDC-4FPX-1M-R becomes MDC-4FPX-1M-R-SS)

H

Micro-DC (M12) Series Cordsets