





MDC (M12) Series Cordsets

12 Conductor MDC Series Cordsets, 24AWG

 


Double Ended Cordsets | Straight | 30 Volt, 2 amps | IP69 Rating

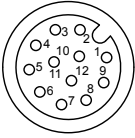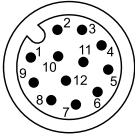

Male Faceview	Part Number	Cables	Features	Color Code	Female Faceview
 M12 x 1	MDCM-12MFP-**-B	Black PVC AWM With Foil Shield 12 X 24 AWG 30V, 2A -40°C to +105°C 6.7mm OD	Industry Standard PVC Foil Shield	1. White 2. Brown 3. Green 4. Yellow 5. Gray 6. Pink 7. Blue 8. Red 9. Orange 10. Tan 11. Black 12. Violet	 M12 x 1
	MDCPM-12MFP-**-B	Black PUR AWM With Foil Shield 12 X 24 AWG 30V, 2A -40°C to +80°C 6.7mm OD	Oil and Cutting Fluid Resistant Cut Resistant PUR Foil Shield		

** Lengths in meters. Standard cable lengths are 1, 2, 4, 5, 6, 10 & 15 meters. Consult factory for other lengths.
Gray cables are available on some versions, please consult the factory.
Standard coupling nut is nickel plated brass, for stainless steel coupling nut add a “SS” suffix. (e.g. MDCM-12MFP-1M-B becomes MDCM-12MFP-1M-B-SS)



Male - Female Extension

H
Micro-DC (M12) Series Cordsets