


77–MG120

Fan Guard, Metal

Features

- For 120mm x 120mm Fans

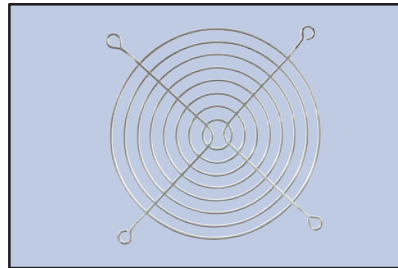

77–FF40 thru 77–FF120

Fan Filter, 3–Piece

Contains:

- 1 UL94–V0 Plastic Base (that attaches to the fan)
- 1 Nylon Fiber Synthetic Resin Filter
- 1 1 UL94–V0 Plastic Cover

Features

- 35PPI Rating

Fan Applications:

- 40mm x 40mm uses 77–FF40
- 60mm x 60mm uses 77–FF60
- 80mm x 80mm uses 77–FF80
- 92mm x 92mm uses 77–FF92
- 120mm x 120mm uses 77–FF120



77–FC12 thru 77–FC72

Fan Cord

Features

- Black Molded PVC Hood with Copper Terminal Connector
- Power Cable, Bar Copper 17*0.15 BC/2C, Black PVC Jacket
- (UL) SPT–1 60°C VW–1 22AWGX2C

Cord Lengths:

- 77–FC12 – 12 inches
- 77–FC24 – 24 inches
- 77–FC36 – 36 inches
- 77–FC48 – 48 inches
- 77–FC72 – 72 inches



77–FC12P thru 77–FC72P

Fan Cord with Plug

Features

- Contains 2–Prong AC Plug
- Black Molded PVC Hood with Copper Terminal Connector
- Power Cable, Bar Copper 17*0.15 BC/2C, Black PVC Jacket
- (UL) SPT–1 60°C VW–1 22AWGX2C

Cord Lengths:

- 77–FC12P – 12 inches
- 77–FC24P – 24 inches
- 77–FC36P – 36 inches
- 77–FC48P – 48 inches
- 77–FC72P – 72 inches

