

EQUIPMENT SHELVES Single-Sided Design




19" Format

Specifications			
Stock No.	RU	Depth	Load Capacity
ES0219-0107	1 RU	7"	12 lbs
ES0219-0110	1 RU	10.5"	15 lbs
ES0219-0210	2 RU	10.5"	18 lbs
ES0219-0112	1 RU	12"	20 lbs
ES0219-0212	2 RU	12"	22 lbs
ES0219-0115	1 RU	15"	35 lbs
ES0219-0215	2 RU	15"	38 lbs
ES0219-0218	2 RU	18"	40 lbs
ES0219-0315	3 RU	15"	41 lbs

RU = Rack Units

Vented

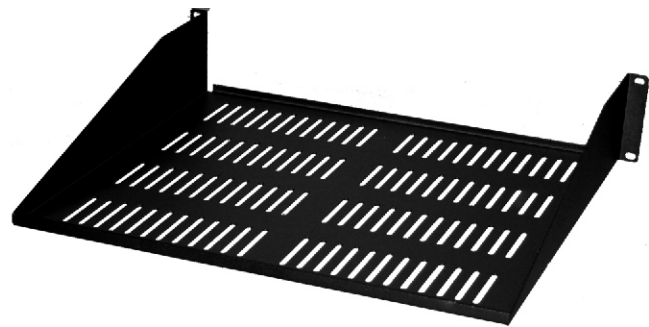

Cold Rolled Steel 16 AWG
Black Powder Coat Finish

Specifications			
Stock No.	RU	Depth	Load Capacity
ES0319-0107	1 RU	7"	20 lbs
ES0319-0110	1 RU	10.5"	25 lbs
ES0319-0210	2 RU	10.5"	28 lbs
ES0319-0112	1 RU	12"	30 lbs
ES0319-0212	2 RU	12"	32 lbs
ES0319-0115	1 RU	15"	40 lbs
ES0319-0215	2 RU	15"	42 lbs
ES0319-0315	3 RU	15"	45 lbs

RU = Rack Units

Non-Vented



Cold Rolled Steel 16 AWG
Black Powder Coat Finish