

PATCHCORDS/MOLDED CABLES

Audio and Video Patchcord and Molded Cables Series 1/4", Mil-Type, TT or Bantam, Video Series

Features and Benefits - Audio

- 110 ohm impedance-matched digital patchcords meet AES/EBU interface standards for digital patching
- Available with a variety of plug terminations, plug finishes, cord lengths and cable colors, the patchcords offer design flexibility
- Premium quality cable insures high reliability and greater flexibility

Specifications

Standard plug terminations are single 3-conductor 1/4" and TT® Nickel-plated plugs (standard), brass and gold-plated (optional)
Cable jacket material is PVC.
Black is standard with other colors available


Features and Benefits - Video

- Designed and built to highest quality standards for efficient video signal transmission
- Cable type is RG59 (75Ω)
- Rugged nickel-plated handles with knurled area for positive finger grip
- Available in standard size or mid-size styles

Specifications

Materials

Housing: Nickel-plated, copper alloy
Contact Pin: Gold-plated, copper alloy
Boot: Thermoplastic, in black and colors

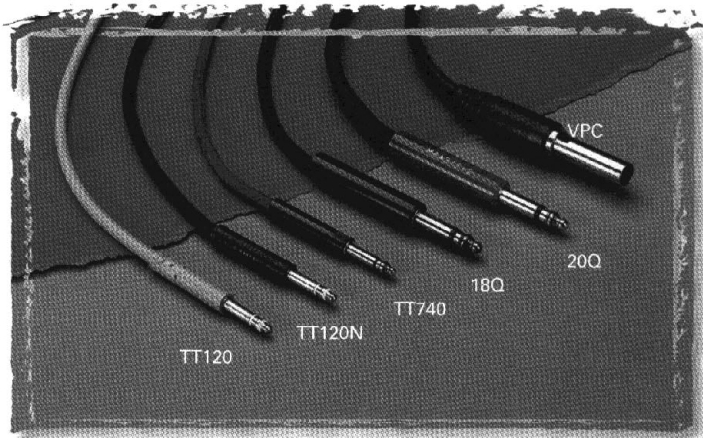


A wide variety of audio patchcords and molded cable assemblies are available. Some of the more popular versions are the 18Q and 20Q Series for professional 1/4" patching, the TT120, TT120N, and the TT740 Series for TT or bantam patching, and the DTT and DMT Series for AES/EBU digital patching. The VPC and VPCM Series offer exceptional performance for video signal patching.



Ordering Information

Part Number	Type	Description
Video Patchcords		
VPC12*PP	Standard	1 foot
VPC24*PP*	Standard	2 foot
VPC36*PP*	Standard	3 foot
VPC48*PP*	Standard	4 foot
VPC72*PP*	Standard	6 foot
VSPP	Standard	Crimpable plug
VPCM12*PP*	Midsized	1 foot
VPCM24*PP*	Midsized	2 foot
VPCM36*PP*	Midsized	3 foot
VPCM48*PP*	Midsized	4 foot
VPCM72*PP*	Midsized	6 foot
VMPP	Midsized	Crimpable plug

*When ordering, add the following numbers for color cable and boot option: 0- Black; 2- Red; 5- Green; 6- Blue. Note: First * designates cable color and second * designates boot color.

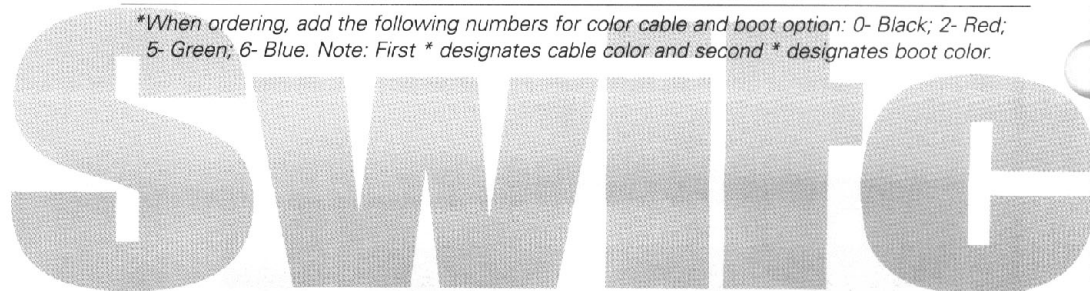

PATCHCORDS/MOLDED CABLES

Audio and Video Patchcord, and Molded Cables Series 1/4", Mil-Type, TT or Bantam, Video Series

39

Ordering Information

Part Number	Type	Plug Finger	Description
Audio Patchcords			
18QD18	1/4" Mil-Type	Brass	2 foot, black nylon jacket
18QF18	1/4" Mil-Type	Brass	3 foot, black nylon jacket
18QH18	1/4" Mil-Type	Brass	4 foot, black nylon jacket
20QD20N*	1/4" Mil-Type	Nickel	2 foot, nylon jacket
20QF20N*	1/4" Mil-Type	Nickel	3 foot, nylon jacket
20QH20N*	1/4" Mil-Type	Nickel	4 foot, nylon jacket Uses 2 cond. shielded cable
TT122	TT or Bantam	Brass	1 foot, molded gray jacket
TT124	TT or Bantam	Brass	2 foot, molded gray jacket
TT126	TT or Bantam	Brass	3 foot, molded gray jacket
TT127	TT or Bantam	Brass	4 foot, molded gray jacket
TT128	TT or Bantam	Brass	5 foot, molded gray jacket
TT122N*	TT or Bantam	Nickel	1 foot, molded
TT124N*	TT or Bantam	Nickel	2 foot, molded
TT126N*	TT or Bantam	Nickel	3 foot, molded
TT127N*	TT or Bantam	Nickel	4 foot, molded
TT128N*	TT or Bantam	Nickel	5 foot, molded
TT742N*	TT or Bantam	Nickel	1 foot, nylon jacket
TT744N*	TT or Bantam	Nickel	2 foot, nylon jacket
TT746N*	TT or Bantam	Nickel	3 foot, nylon jacket
TT747N*	TT or Bantam	Nickel	4 foot, nylon jacket Uses 2 cond. shielded cable
Digital AES/EBU Patchcords			
DTT122	TT or Bantam	Nickel	1 foot, 110 Ohm, black, molded
DTT124	TT or Bantam	Nickel	2 foot, 110 Ohm, black, molded
DTT126	TT or Bantam	Nickel	3 foot, 110 Ohm, black, molded
DTT128	TT or Bantam	Nickel	5 foot, 110 Ohm, black, molded
DTT133	TT or Bantam	Nickel	10 foot, 110 Ohm, black, molded
DMT122	1/4" Mil-Type	Nickel	1 foot, 110 Ohm, black
DMT124	1/4" Mil-Type	Nickel	2 foot, 110 Ohm, black
DMT126	1/4" Mil-Type	Nickel	3 foot, 110 Ohm, black
DMT128	1/4" Mil-Type	Nickel	5 foot, 110 Ohm, black Uses 2 cond. shielded, 110 Ohm cable

Ordering Information

Part No.	Description
Molded MIDI Cables	
MD3	3 foot, 5 pin DIN, molded black
MD6	6 foot, 5 pin DIN, molded black
MD10	10 foot, 5 pin DIN, molded black
MD15	15 foot, 5 pin DIN, molded black Uses 4 cond., 24 awg, PVC outer jacket, braided shielded cable
1/4" Cables	
05AD05	2 foot, mono, male to male
05AK05	6 foot, mono, male to male
05AN05	10 foot, mono, male to male
05AU05	25 foot, mono, male to male
05AN15	10 foot, mono, male to RA male
05AN80	10 foot, mono, male to female
05AU80	25 foot, mono, male to female
10BF10	3 foot, stereo, male to male
10BK10	6 foot, stereo, male to male
10BN10	10 foot, stereo, male to male
15AK15	6 foot, mono, RA male to RA male
RCA	
25AF25	3 foot, male to male
25AK25	6 foot, male to male
25AN25	10 foot, male to male
25AK82	6 foot, male to female
30AK30	6 foot, RA male to RA male
30AN30	10 foot, RA male to RA male
30AR30	15 foot, RA male to RA male
1/4" to RCA	
05AK25	6 foot, 1/4" male to RCA male
05AN25	10 foot, 1/4" male to RCA male Uses either single or 2 cond, 22awg, PVC outer jacket, braided shielded cable

* When ordering, add the following for cable color: 0 - Black; 2 - Red; 5 - Green; 6 - Blue

Switchcraft
www.switchcraft.com

5555 North Elston Avenue / Chicago, IL 60630
Phone: 773-792-2700 / Fax: 773-792-2129