
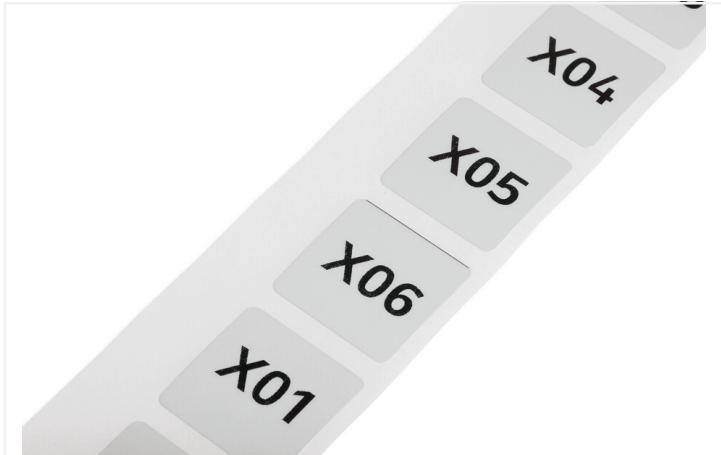


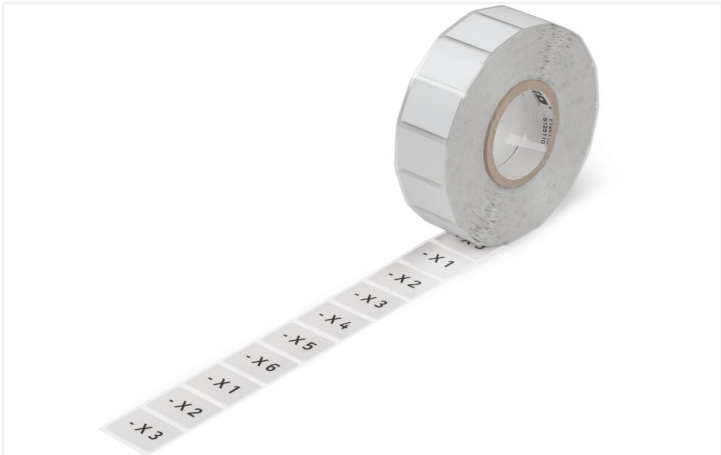

Color:  silver-colored Similar to illustration

Technical data	
Suitable	without button frame
Marking method	Thermal transfer
Marking	plain
Delivery form	Roll
Delivery form configuration	500 markers/reel; 1 line
Printing device	Smart Printer (thermal transfer printer)

Physical data	
Height	28 mm
Width	28 mm
Depth	0.09 mm
Marking surface	28 x 28 mm

Mechanical data	
Mounting type	Sticking
Smear resistance	in conjunction with 258-5005 Ink Ribbon

Material data	
Color	silver-colored
Material	Polyester
UV resistance	EN 60068-2-5:2010 Procedure B
Adhesive information	Acrylic; permanent
Halogen-free	Yes
Weight	220 g
Fire load	0 MJ



Environmental requirements	
Ambient temperature (storage)	≥+22 °C
Ambient temperature (operation)	-30 ... +130 °C
Relative humidity	40 ... 50 %

Commercial data	
Product Group	2 (Terminal Block Accessories)
eCl@ss 10.0	27-40-06-29
eCl@ss 9.0	27-40-06-29
ETIM 8.0	EC001288
ETIM 7.0	EC001288
PU (SPU)	1 pcs
Packaging type	Box
Country of origin	DE
GTIN	4050821656876
Customs tariff number	39199080888

Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads

Environmental Product Compliance

Compliance Search	
Environmental Product Compliance 210-854	

Documentation

Operating Instructions			
210-852 Information on handling print material	1 28.08.2020	pdf 1004.72 KB	

1 Compatible Products

1.1 Optional Accessories

1.1.1 Marking

1.1.1.1 Marking device



Item No.: 258-5000
Thermal transfer printer; Smart Printer; for complete control cabinet marking; 300 dpi; With marking material