


MAX04NG

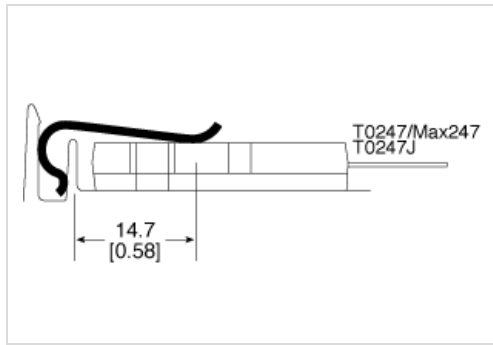

Standard force clip

Width: 20.00

Force: 60 N [13.5 lbs]

Thickness: 0.50

RoHS: compliant

PCN Link: <http://www.aavid.com/sites/default/files/pcn/PCN121411.pdf>

Need assistance?

Call us: 1-855-32-AAVID
Email: estore@aavid.com

[» Help Page](#)

[>Request a Sample](#)
[>Request a Quote](#)
[>Ask an Engineer](#)

The Fine Print

[Product Return Policy](#)
[Terms & Conditions](#)
[Privacy Policy](#)

Customer Assistance

- [Contact Us](#)
- [Get Design Assistance](#)
- [Find a Distributor](#)
- [Find a Sales Rep](#)
- [Request a Quote](#)
- [Placing an Order](#)
- [Terms and Conditions](#)
- [Returns](#)

Popular Products

- [Fans](#)
- [Extrusions](#)
- [Board Level](#)
- [Liquid Cooling](#)
- [Heat Pipe Technology](#)
- [Heat Sink Accessories](#)
- [Interface Materials](#)

Our Company

- [News and Events](#)
- [Management Team](#)
- [Worldwide Locations](#)
- [Directions to Headquarters](#)
- [Disclaimer](#)
- [Customer Survey](#)
- [Privacy Policy](#)

Connect with Aavid

Sign up for Aavid News & Alerts

Email Address [GO!](#)

Like / Follow / Connect



© Copyright 2015 Aavid Thermalloy, LLC.