



Platform Trucks Wood Deck

FEATURING KILN-DRIED TONGUE & GROOVE HARDWOOD DECKS

How to Order Your Wood Platform Truck



SERIES 1 with Polyolefin Casters

SERIES 2 with Mold-On Casters



STEP 1

PICK A DECK SIZE

All decks are 4/4 (7/8" thick) hardwood with tongue and groove construction.

Standard deck sizes:

24" x 48" • 27" x 54" • 30" x 60" • 36" x 72"

STEP 2

PICK A DECK STYLE (1-2)

Series 1 – All Wood

- Standard with removable crossbar pipe handle at swivel end

Series 2 – Wood Deck with Steel Frame

- 2" x 2" x 1/8" all-welded steel angle frame keeps cart square (on 36" x 72" deck, 2" x 2" x 3/16")
- Heavy-duty steel frame for additional deck support
- Standard with removable crossbar pipe handle at swivel end
- The wood deck is reinforced with longitudinal stiffeners for maximum capacity. (See caster options for capacity)

STEP 3

 
PICK SUPERSTRUCTURE (A-D)

Superstructure





Open pipe handle

COLOR
Red



Crossbar pipe handle

  


Crossbar handles are removable

STEP 4


PICK RUNNING GEARS (4-7)

Rigid caster

Swivel caster

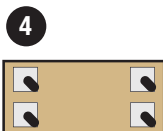


Four Swivel

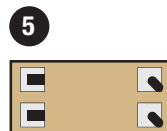

Two Rigid
Two Swivel



Tilt

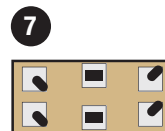

Tilt Quad

STEP 5

PICK CASTER TYPE (P, M, Y, N, R, S)

Heavy-duty casters are bolted on for easy replacement. Caster options allow 1,180 to 3,000 lb. capacities.



Polyolefin
5 x 2 • 6 x 2



Mold-On Rubber
5 x 2 • 6 x 2 • 8 x 2



Polyurethane
6 x 2 • 8 x 2



Pneumatic
8 x 3 • 10 x 3 1/2



Non-Marking
Rubber
6 x 2 • 8 x 2



Steel
8 x 2

Caster & Wheel choices allow you to resolve problems of noise control, floor protection, impact or abrasion resistance, or load capacity. See page 91 for more caster and wheel information.

STEP 6

PICK CASTER SIZE – 5", 6", 8", 10"

Call your Akro-Mils distributor with your model number today to order

model #	step 1	step 2	step 3	step 4	step 5	step 6
Platform Truck	Size	Series	Super-structure	Running Gear Type	Caster Wheel	Caster Wheel Diameter
RPT	2448 2754 3060 3672	1 2	A B C D	4 5 6 7	P M Y N R S	5 6 8 10
RPT	3060	2	A	5	Y	6



Ships fully assembled & ready to use!

= RPT30602A5Y6





Platform Trucks : Steel, Super-Heavy-Duty

ADDITIONAL HEAVY-DUTY TRUCK OPTIONS

800.253.2467
akro-mils.com

PLATFORM TRUCKS

Platform Trucks – Steel Deck



FEATURES

- 1 Durable powder-coated finish
- 2 Smooth 13-gauge steel deck and frame
- 3 Steel reinforcements run lengthwise under the deck
- 4 Heavy-duty industrial casters (standard 2 swivel, 2 rigid) bolt-on for easy replacement
- 5 Removable crossbar handle

PRODUCT HIGHLIGHTS

- **HEAVY-DUTY** – 13-gauge steel deck with longitudinal steel underdeck reinforcements
- **CAPACITY** – Caster options allow 800 to 2,000 lb. capacities
- **NO ASSEMBLY** – Trucks are shipped assembled and ready to use
- **VARIETY** – Special order platform trucks are available. Select from 8 standard deck sizes and a wide variety of handle and caster options
- **DECK SIZES** – 24" x 36", 24" x 48", 24" x 60", 27" x 54", 30" x 48", 30" x 60", 36" x 60", 36" x 72"



COLOR
Gray



Platform Trucks - Steel

Model No.	Caster Type*	Caster Size (In.)	Weight Capacity (lbs.)	Deck Height (In.)
R2108FPB	Full Pneumatic	8 x 2	1200	11-1/2
R2125MRB	Mold-On Rubber	5 x 2	1200	8
R2168MRB	Mold-On Rubber	8 x 2	2000	11

* See page 91 for full description of casters and wheels.

Platform Trucks – Super-Heavy-Duty



FEATURES

- 1 Powder-coated steel frame
- 2 Super-heavy-duty kiln-dried hardwood deck
- 3 Steel C-channel and removable side rails allow for deck repair/replacement
- 4 High deck for minimal bending
- 5 Load wheels on solid 1" steel axle
- 6 Removable crossbar handle

PRODUCT HIGHLIGHTS

- **HEAVY-DUTY** – Caster options allow 1,200 to 4,000 lb. capacities
- **NO ASSEMBLY** – Trucks are shipped completely assembled and ready to use
- **VARIETY** – Deck sizes: 24" x 48", 30" x 48", 30" x 60", 36" x 72"



COLOR
Gray



Platform Trucks - Super-Heavy-Duty

Model No.	Caster Type*	Caster/Wheel Size (In.)	Weight Capacity (lbs.)	Deck Height (In.)
R2178MRB	Mold-On Rubber	8 x 2	2000	12-1/4
R219885MRB	Mold-On Rubber	8 x 2 / 8 x 2-1/2	2500	12-1/2
R221812MRB	Mold-On Rubber	8 x 2 / 12 x 2-1/2	3000	16
R2258516MRB	Mold-On Rubber	8 x 2-1/2 / 16 x 3	4000	19-1/2

* See page 91 for full description of casters and wheels.

ACCESSORIES



Floor Locks



Wheel Locks



Corner Bumpers



Continuous Bumpers



VERSA/Deck™

VERSATILE STRUCTURAL FOAM PLATFORM TRUCK



UP TO
2000
LBS.

VERSA/Deck™

MADE
IN THE
USA




FEATURES

- 1 More than 70 different handle/caster configurations
- 2 Non-skid structural foam deck is easy-to-clean and won't rot, chip or rust
- 3 Jam Bolts, standard on all models, hold handles in place
- 4 **NEW FEATURE!** 4 molded-in tie-down slots secure items during transport
- 5 Steel reinforcements provide durability and a weight capacity of up to 2,000 lbs.
- 6 Handles and rails feature a durable, powder-coated finish



PRODUCT HIGHLIGHTS

- **DURABLE** – HDPE molded structural foam with steel reinforcement
- **CAPACITY** – Up to 2,000 lb. weight capacity
- **VARIETY** – Customizable for your exact needs with multiple handle, deck and caster options. Brake and floor lock options are available as well. Decks sizes: 24" x 48", 30" x 60"

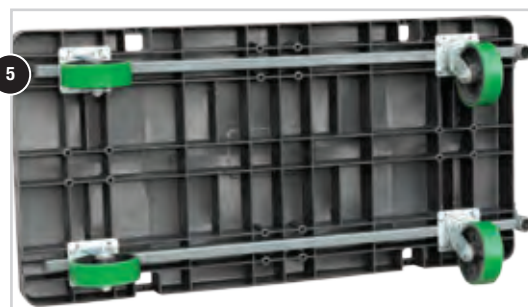

Handle Styles:

 
Open Swayback



Crossbar Swayback



Open Straight



Wire Mesh Sides



High/Low



Posts



COLOR
Black/Gray



CASTER & WHEEL CHOICES

allow you to resolve problems of noise control, floor protection, impact or abrasion resistance, or load capacity. See page 91 for more information.



Mold-On Rubber



Pneumatic



Polyolefin



Polyurethane



Thermoplastic



Easy-Roll

NEW!



Handle Style "A"
1 Crossbar Swayback
or
1 Open Swayback

Models ending in "11"
have open handles,
those ending in "12"
have crossbar handles

Style "A" – 1 Crossbar Swayback or 1 Open Swayback			
Model No.	Deck Size	Caster Type	Caster Size (In.)
R90110A1411	24 x 48	Pneumatic	10
R90110A1412	24 x 48	Pneumatic	10
R90162A1411	24 x 48	Polyolefin	6
R90162A1412	24 x 48	Polyolefin	6
R90163A1411	24 x 48	Polyurethane	6
R90163A1412	24 x 48	Polyurethane	6
R90181A1411	24 x 48	Pneumatic	8
R90181A1412	24 x 48	Pneumatic	8
R90182A1411	24 x 48	Mold-On Rubber	8
R90182A1412	24 x 48	Mold-On Rubber	8
R90184A1411	24 x 48	Polyolefin	8
R90184A1412	24 x 48	Polyolefin	8
R90185A1411	24 x 48	Thermoplastic	8
R90185A1412	24 x 48	Thermoplastic	8
R90165A1411	24 x 48	Easy-Roll	6
R90165A1412	24 x 48	Easy-Roll	6
R90210A1011	30 x 60	Pneumatic	10
R90210A1012	30 x 60	Pneumatic	10
R90262A1011	30 x 60	Polyolefin	6
R90262A1012	30 x 60	Polyolefin	6
R90263A1011	30 x 60	Polyurethane	6
R90263A1012	30 x 60	Polyurethane	6
R90281A1011	30 x 60	Pneumatic	8
R90281A1012	30 x 60	Pneumatic	8
R90282A1011	30 x 60	Mold-On Rubber	8
R90282A1012	30 x 60	Mold-On Rubber	8
R90284A1011	30 x 60	Polyolefin	8
R90284A1012	30 x 60	Polyolefin	8
R90285A1011	30 x 60	Thermoplastic	8
R90285A1012	30 x 60	Thermoplastic	8
R90265A1011	30 x 60	Easy-Roll	6
R90265A1012	30 x 60	Easy-Roll	6

Note: Models ending in "11" have open handles, those ending in "12" have crossbar handles.



Handle Style "D"
3 Open Straight



Handle Style "S"
2 Open Swayback & 4
Wire Mesh Side Panels

Style "D" – 3 Open Straight Length of Deck			
Model No.	Deck Size	Caster Type	Caster Size (In.)
R90162D3815	24 x 48	Polyolefin	6
R90163D3815	24 x 48	Polyurethane	6
R90181D3815	24 x 48	Pneumatic	8
R90182D3815	24 x 48	Mold-On Rubber	8
R90262D3015	30 x 60	Polyolefin	6
R90263D3015	30 x 60	Polyurethane	6
R90281D3015	30 x 60	Pneumatic	8
R90282D3015	30 x 60	Mold-On Rubber	8

Style "S" – 2 Open Swayback & 4 Wire Mesh Side Panels			
Model No.	Deck Size	Caster Type	Caster Size (In.)
R90110S2411	24 x 48	Pneumatic	10
R90181S2411	24 x 48	Pneumatic	8
R90182S2411	24 x 48	Mold-On Rubber	8
R90184S2411	24 x 48	Polyolefin	8
R90165S2411	24 x 48	Easy-Roll	6
R90210S2011	30 x 60	Pneumatic	10
R90281S2011	30 x 60	Pneumatic	8
R90282S2011	30 x 60	Mold-On Rubber	8
R90284S2011	30 x 60	Polyolefin	8
R90265S2011	30 x 60	Easy-Roll	6



Handle Style "P"
1 High Side Rail &
1 Low Side Rail

Style "P" – 1 High Side Rail & 1 Low Side Rail			
Model No.	Deck Size	Caster Type	Caster Size (In.)
R90162P24111811	24 x 48	Polyolefin	6
R90163P24111811	24 x 48	Polyurethane	6
R90181P24111811	24 x 48	Pneumatic	8
R90182P24111811	24 x 48	Mold-On Rubber	8
R90262P20111011	30 x 60	Polyolefin	6
R90263P20111011	30 x 60	Polyurethane	6
R90281P20111011	30 x 60	Pneumatic	8
R90282P20111011	30 x 60	Mold-On Rubber	8



Handle Style "F"
4 Corner Posts - 39" tall

Style "F" – 4 Corner Posts			
Model No.	Deck Size	Caster Type	Caster Size (In.)
R90110F44813	24 x 48	Pneumatic	10
R90163F44813	24 x 48	Polyurethane	6
R90181F44813	24 x 48	Pneumatic	8
R90182F44813	24 x 48	Mold-On Rubber	8
R90184F44813	24 x 48	Polyolefin	8
R90210F40013	30 x 60	Pneumatic	10
R90263F40013	30 x 60	Polyurethane	6
R90281F40013	30 x 60	Pneumatic	8
R90282F40013	30 x 60	Mold-On Rubber	8
R90284F40013	30 x 60	Polyolefin	8



Handle Style "B"
2 Crossbar Swayback

Style "B" – 2 Crossbar Swayback			
Model No.	Deck Size	Caster Type	Caster Size (In.)
R90110B2412	24 x 48	Pneumatic	10
R90181B2412	24 x 48	Pneumatic	8
R90182B2412	24 x 48	Mold-On Rubber	8
R90184B2412	24 x 48	Polyolefin	8
R90165B2412	24 x 48	Easy-Roll	6
R90210B2012	30 x 60	Pneumatic	10
R90281B2012	30 x 60	Pneumatic	8
R90282B2012	30 x 60	Mold-On Rubber	8
R90284B2012	30 x 60	Polyolefin	8
R90265B2012	30 x 60	Easy-Roll	6

Brake and floor lock options available – consult Akro-Mils for your application needs.



ULTRA/Deck™

HEAVY-DUTY STRUCTURAL FOAM PLATFORM TRUCK

ULTRA/Deck™



UP TO
3000
LBS.


U90181A1412

MADE
IN THE
USA



FEATURES

- 1 Sturdy, easy-to-clean, non-skid structural foam deck resists most chemicals and damage from long-term weather exposure
- 2 The ULTRA/Deck is heavy-duty! Steel reinforcements and extra structural foam ribs under the deck add strength and stability for your toughest loads
- 3 Cart handles and rails feature a durable, powder-coated finish, and are removable for convenient shipping and storage

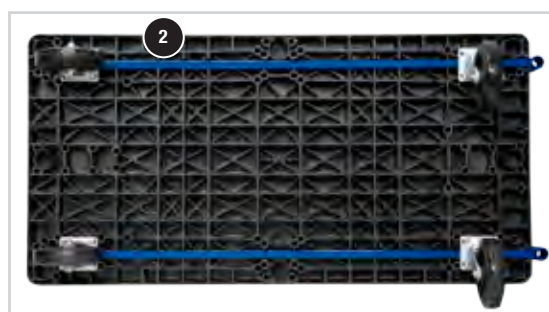

PRODUCT HIGHLIGHTS

- **RUGGED** – HDPE molded structural foam withstands the toughest loads in most environments
- **CAPACITY** – Caster options allow up to 3,000 lb. weight capacity
- **VARIETY** – Multiple handle, deck and caster options to select the exact configuration you need

Handle Styles:

Handle – Outside Deck

 


Open
Swayback



Crossbar
Swayback

Handle Rails – Indeck



Crossbar
Straight

COLOR
Black/Blue



CASTER & WHEEL CHOICES

allow you to resolve problems of noise control, floor protection, impact or abrasion resistance, or load capacity. See page 91 for more information.



Mold-On Rubber



Pneumatic



Polyolefin



Polyurethane



Thermoplastic



Easy-Roll

NEW!

800.253.2467
akro-mils.com


Handle Style "A"

1 Crossbar Swayback
or
1 Open Swayback

Models ending in "11"
have open handles,
those ending in "12"
have crossbar handles

Style "A" – 1 Crossbar Swayback or 1 Open Swayback			
Model No.	Deck Size	Caster Type	Caster Size (In.)
U90110A1411	24 x 48	Pneumatic	10
U90110A1412	24 x 48	Pneumatic	10
U90162A1411	24 x 48	Polyolefin	6
U90162A1412	24 x 48	Polyolefin	6
U90163A1411	24 x 48	Polyurethane	6
U90163A1412	24 x 48	Polyurethane	6
U90181A1411	24 x 48	Pneumatic	8
U90181A1412	24 x 48	Pneumatic	8
U90182A1411	24 x 48	Mold-On Rubber	8
U90182A1412	24 x 48	Mold-On Rubber	8
U90184A1411	24 x 48	Polyolefin	8
U90184A1412	24 x 48	Polyolefin	8
U90185A1411	24 x 48	Thermoplastic	8
U90185A1412	24 x 48	Thermoplastic	8
U90165A1411	24 x 48	Easy Roll	6
U90165A1412	24 x 48	Easy Roll	6
U90210A1011	30 x 60	Pneumatic	10
U90210A1012	30 x 60	Pneumatic	10
U90262A1011	30 x 60	Polyolefin	6
U90262A1012	30 x 60	Polyolefin	6
U90263A1011	30 x 60	Polyurethane	6
U90263A1012	30 x 60	Polyurethane	6
U90281A1011	30 x 60	Pneumatic	8
U90281A1012	30 x 60	Pneumatic	8
U90282A1011	30 x 60	Mold-On Rubber	8
U90282A1012	30 x 60	Mold-On Rubber	8
U90284A1011	30 x 60	Polyolefin	8
U90284A1012	30 x 60	Polyolefin	8
U90285A1011	30 x 60	Thermoplastic	8
U90285A1012	30 x 60	Thermoplastic	8
U90265A1011	30 x 60	Easy Roll	6
U90265A1012	30 x 60	Easy Roll	6

Note: Models ending in "11" have open handles, those ending in "12" have crossbar handles.



Handle Style "B"

2 Crossbar Swayback

Style "B" – 2 Crossbar Swayback			
Model No.	Deck Size	Caster Type	Caster Size (In.)
U90110B2412	24 x 48	Pneumatic	10
U90181B2412	24 x 48	Pneumatic	8
U90182B2412	24 x 48	Mold-On Rubber	8
U90184B2412	24 x 48	Polyolefin	8
U90210B2012	30 x 60	Pneumatic	10
U90281B2012	30 x 60	Pneumatic	8
U90282B2012	30 x 60	Mold-On Rubber	8
U90284B2012	30 x 60	Polyolefin	8



Handle Style "D"

3 Crossbar Straight Index

Style "D" – 3 Crossbar Straight, Index			
Model No.	Deck Size	Caster Type	Caster Size (In.)
U90162D3817	24 x 48	Polyolefin	6
U90163D3817	24 x 48	Polyurethane	6
U90181D3817	24 x 48	Pneumatic	8
U90182D3817	24 x 48	Mold-On Rubber	8
U90262D3017	30 x 60	Polyolefin	6
U90263D3017	30 x 60	Polyurethane	6
U90281D3017	30 x 60	Pneumatic	8
U90282D3017	30 x 60	Mold-On Rubber	8



Handle Style "G"

2 Crossbar Straight Index;
1 Open Swayback

Style "G" – 2 Crossbar Straight, Index; 1 Open Swayback			
Model No.	Deck Size	Caster Type	Caster Size (In.)
U90110G14112817	24 x 48	Pneumatic	10
U90181G14112817	24 x 48	Pneumatic	8
U90182G14112817	24 x 48	Mold-On Rubber	8
U90184G14112817	24 x 48	Polyolefin	8
U90210G10112017	30 x 60	Pneumatic	10
U90281G10112017	30 x 60	Pneumatic	8
U90282G10112017	30 x 60	Mold-On Rubber	8
U90284G10112017	30 x 60	Polyolefin	8



Handle Style "H"

1 Crossbar Straight Index;
2 Crossbar Swayback

Style "H" – 1 Crossbar Straight, Index; 2 Crossbar Swayback			
Model No.	Deck Size	Caster Type	Caster Size (In.)
U90162H24121817	24 x 48	Polyolefin	6
U90163H24121817	24 x 48	Polyurethane	6
U90181H24121817	24 x 48	Pneumatic	8
U90182H24121817	24 x 48	Mold-On Rubber	8
U90262H20121017	30 x 60	Polyolefin	6
U90263H20121017	30 x 60	Polyurethane	6
U90281H20121017	30 x 60	Pneumatic	8
U90282H20121017	30 x 60	Mold-On Rubber	8



Handle Style "L"

2 Crossbar Straight Index;
2 Open Swayback

Style "L" – 2 Crossbar Straight, Index; 2 Open Swayback			
Model No.	Deck Size	Caster Type	Caster Size (In.)
U90110L24112817	24 x 48	Pneumatic	10
U90163L24112817	24 x 48	Polyurethane	6
U90181L24112817	24 x 48	Pneumatic	8
U90182L24112817	24 x 48	Mold-On Rubber	8
U90184L24112817	24 x 48	Polyolefin	8
U90210L20112017	30 x 60	Pneumatic	10
U90263L20112017	30 x 60	Polyurethane	6
U90281L20112017	30 x 60	Pneumatic	8
U90282L20112017	30 x 60	Mold-On Rubber	8
U90284L20112017	30 x 60	Polyolefin	8

Other handle and caster combinations available – consult Akro-Mils for your application needs.




Platform Trucks Work Height – Heavy-Duty

TUBULAR FRAME SUPPORTS HEAVIER LOADS



FEATURES

- 1 1½" 16-gauge tubular all-welded frame
- 2 Durable powder-coated finish
- 3 Deck options: kiln-dried tongue and groove hardwood, steel, structural foam
- 4 Fixed or adjustable height deck
- 5 Optional expanded metal or solid steel shelf

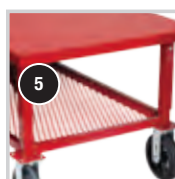

PRODUCT HIGHLIGHTS

- **ERGONOMIC** – Height reduces strain of lifting and bending
- **DURABLE** – Hardwood, steel or structural foam decks available
- **CAPACITY** – Up to 2,000 lb. weight capacity
- **VARIETY** – Fixed and adjustable heights available. Optional expanded metal shelf or solid steel lower shelf. Deck sizes: 24" x 48", 30" x 60"



RWHV24481A5M8A



RWH30601A5M8



RWH30601A5M8

COLOR
Red



ACCESSORIES



Corner Bumpers



Expanded Metal Shelf



Solid Metal Shelf



Floor Locks



Wheel Locks

Platform Trucks - Fixed Work Height - Tubular Steel Frame		Dimensions (In.)			Caster		
Model No.	Deck Type	L	W	H	Type*	Size (In.)	Weight Capacity (lbs.)
RWH24481A5M8	Wood	24	48	26-3/8	Mold-On Rubber	8	1800
RWHV24481A5M8	Structural Foam	24	48	26-7/8	Mold-On Rubber	8	1800
RWHV24481A5Y6	Structural Foam	24	48	24-7/8	Polyurethane	6	2000
RWH324481A5M8	Steel	24	48	25-1/4	Mold-On Rubber	8	1800
RWH324481A5Y6	Steel	24	48	23-1/4	Polyurethane	6	1800
RWH30601A5M8	Wood	30	60	26-3/8	Mold-On Rubber	8	1800
RWHV30601A5M8	Structural Foam	30	60	26-7/8	Mold-On Rubber	8	1800
RWHV30601A5Y6	Structural Foam	30	60	24-7/8	Polyurethane	6	2000
RWH330601A5M8	Steel	30	60	25-1/4	Mold-On Rubber	8	1800
RWH330601A5Y6	Steel	30	60	23-1/4	Polyurethane	6	1800

* See page 91 for full description of casters and wheels.

Platform Trucks - Adjustable Work Height - Tubular Steel Frame		Dimensions (In.)			Caster		
Model No.	Deck Type	L	W	H	Type*	Size (In.)	Weight Capacity (lbs.)
RWH24481A5M8A	Wood	24	48	26-3/4 to 32-3/4	Mold-On Rubber	8	1800
RWHV24481A5M8A	Structural Foam	24	48	27-1/2 to 33-1/2	Mold-On Rubber	8	1800
RWHV24481A5Y6A	Structural Foam	24	48	25-1/2 to 31-1/2	Polyurethane	6	2000
RWH324481A5M8A	Steel	24	48	25-5/8 to 32	Mold-On Rubber	8	1800
RWH324481A5Y6A	Steel	24	48	23-5/8 to 32	Polyurethane	6	1800
RWH30601A5M8A	Wood	30	60	26-3/4 to 32-3/4	Mold-On Rubber	8	1800
RWHV30601A5M8A	Structural Foam	30	60	27-1/2 to 33-1/2	Mold-On Rubber	8	1800
RWHV30601A5Y6A	Structural Foam	30	60	25-1/2 to 31-1/2	Polyurethane	6	2000
RWH330601A5M8A	Steel	30	60	25-5/8 to 32	Mold-On Rubber	8	1800
RWH330601A5Y6A	Steel	30	60	23-5/8 to 32	Polyurethane	6	1800

* See page 91 for full description of casters and wheels.

Platform Trucks Work Height – Standard-Duty : Skids

MORE STORAGE & TRANSPORT OPTIONS

800.253.2467
akro-mils.com

UP TO
1500
LBS.

Platform Trucks Work Height STANDARD DUTY



FEATURES

- 1 1½" x 1½" x 1/8" all-welded angle iron frame
- 2 Durable powder-coated finish
- 3 Deck options: kiln-dried tongue and groove hardwood, steel, structural foam
- 4 Fixed or adjustable height deck
- 5 Optional expanded metal or solid steel shelf

PRODUCT HIGHLIGHTS

- **ERGONOMIC** – Height reduces strain of lifting and bending
- **VARIETY** – Fixed and adjustable heights available. Optional expanded metal shelf. Deck sizes: 24" x 48", 30" x 60"

COLOR
Red



MADE
IN THE
USA

ACCESSORIES



Corner
Bumpers



Floor
Locks



Expanded
Metal
Shelf



Wheel
Locks



Solid
Metal
Shelf

Platform Trucks - Fixed Work Height - Angle Iron Frame		Dimensions (In.)			Caster		
Model No.	Deck Type	L	W	H	Type*	Size* (Inches)	Weight Capacity (lbs.)
RWH2448EA5M6	Wood	24	48	24-1/2	Mold-On Rubber	6	1500
RWHV2448EA5M6	Structural Foam	24	48	24-7/8	Mold-On Rubber	6	1500
RWHS2448EA5M6	All-Steel	24	48	22	Mold-On Rubber	6	1500
RWH3060EA5M6	Wood	30	60	24-1/2	Mold-On Rubber	6	1500
RWHV3060EA5M6	Structural Foam	30	60	24-7/8	Mold-On Rubber	6	1500
RWHS3060EA5M6	All-Steel	30	60	22	Mold-On Rubber	6	1500

* See page 91 for full description of casters and wheels.

Platform Trucks - Adjustable Work Height - Angle Iron Frame		Dimensions (In.)			Caster		
Model No.	Deck Type	L	W	H	Type*	Size* (Inches)	Weight Capacity (lbs.)
RWH2448EA5M6A	Wood	24	48	24-1/2 to 30-1/2	Mold-On Rubber	6	1500
RWHV2448EA5M6A	Structural Foam	24	48	24-7/8 to 30-7/8	Mold-On Rubber	6	1500
RWHS2448EA5M6A	All-Steel	24	48	22 to 28	Mold-On Rubber	6	1500
RWH3060EA5M6A	Wood	30	60	24-1/2 to 30-1/2	Mold-On Rubber	6	1500
RWHV3060EA5M6A	Structural Foam	30	60	24-7/8 to 30-7/8	Mold-On Rubber	6	1500
RWHS3060EA5M6A	All-Steel	30	60	22 to 28	Mold-On Rubber	6	1500

* See page 91 for full description of casters and wheels.

Semi-Live Skids TONGUE AND GROOVE HARDWOOD DECK

UP TO
2200
LBS.



- **EFFICIENT** – Can be used with a forklift or lift jack
- **VARIETY** – Deck sizes: 24" x 48", 30" x 60" (2 wheels standard)

MADE
IN THE
USA



Semi-Live Skids - 2 Wheels		Caster		
Model No.	Description	Type*	Size (In.)	Weight Capacity (lbs.)
RA778MR	Tongue & Groove Hardwood Deck	Mold-On Rubber	8	2200
RA756MR	Tongue & Groove Hardwood Deck	Mold-On Rubber	6	1800

Lift Jacks			Caster	
Model No.	Description	Handle Style	Type*	Size (In.)
RM718MR‡	Male Lift Jack	(T) or (Loop)	Mold-On Rubber	8
RF718MR‡	Female Lift Jack	(T) or (Loop)	Mold-On Rubber	8

* See page 91 for full description of casters and wheels. ‡ - Specify Handle Style (T) or (Loop) when ordering.



Platform Trucks Series 5

ECONOMICALLY PRICED TRUCK SHIPS FLAT TO SAVE MONEY



NEW!

UP TO
2400
LBS.

MADE
IN THE
USA



COLOR
Gray



FEATURES

- 1 4/4 kiln-dried unfinished hardwood deck
- 2 Powder-coated 13-gauge fixed steel handle offered in open or crossbar styles

PRODUCT HIGHLIGHTS

- **DURABLE** – Kiln-dried tongue and groove unfinished hardwood deck
- **CAPACITY** – 4 caster options for up to 2,400-lb. capacity
- **UNASSEMBLED** – Cart ships unassembled, saving freight costs and warehouse space
- **DECK SIZES** – 24" x 48", 27" x 54", 30" x 60"



Series 5 Platform Trucks		Caster		
Model No.	Description	Type	Size (In.)	Weight Capacity (Lbs.)*
RPT24485J5G6GY	24 x 48, Open Handle	Polyurethane	6	2400
RPT24485K5G6GY	24 x 48, Crossbar Handle	Polyurethane	6	2400
RPT24485J5P6GY	24 x 48, Open Handle	Polyolefin	6	2100
RPT24485K5P6GY	24 x 48, Crossbar Handle	Polyolefin	6	2100
RPT24485J5N8GY	24 x 48, Open Handle	Pneumatic	8	1000
RPT24485K5N8GY	24 x 48, Crossbar Handle	Pneumatic	8	1000
RPT24485J5M8GY	24 x 48, Open Handle	Mold-On	8	1500
RPT24485K5M8GY	24 x 48, Crossbar Handle	Mold-On	8	1500
RPT27545J5G6GY	27 x 54, Open Handle	Polyurethane	6	2400
RPT27545K5G6GY	27 x 54, Crossbar Handle	Polyurethane	6	2400
RPT27545J5P6GY	27 x 54, Open Handle	Polyolefin	6	2100
RPT27545K5P6GY	27 x 54, Crossbar Handle	Polyolefin	6	2100

*Based on evenly distributed load on 4 casters. Other caster sets are available. Minimum quantities apply.

Series 5 Platform Trucks		Caster		
Model No.	Description	Type	Size (In.)	Weight Capacity (Lbs.)*
RPT27545J5N8GY	27 x 54, Open Handle	Pneumatic	8	1000
RPT27545K5N8GY	27 x 54, Crossbar Handle	Pneumatic	8	1000
RPT27545J5M8GY	27 x 54, Open Handle	Mold-On	8	1500
RPT27545K5M8GY	27 x 54, Crossbar Handle	Mold-On	8	1500
RPT30605J5G6GY	30 x 60, Open Handle	Polyurethane	6	2400
RPT30605K5G6GY	30 x 60, Crossbar Handle	Polyurethane	6	2400
RPT30605J5P6GY	30 x 60, Open Handle	Polyolefin	6	2100
RPT30605K5P6GY	30 x 60, Crossbar Handle	Polyolefin	6	2100
RPT30605J5N8GY	30 x 60, Open Handle	Pneumatic	8	1000
RPT30605K5N8GY	30 x 60, Crossbar Handle	Pneumatic	8	1000
RPT30605J5M8GY	30 x 60, Open Handle	Mold-On	8	1500
RPT30605K5M8GY	30 x 60, Crossbar Handle	Mold-On	8	1500

*Based on evenly distributed load on 4 casters. Other caster sets are available. Minimum quantities apply.

CASTER & WHEEL CHOICES

allow you to resolve problems of noise control, floor protection, impact or abrasion resistance, or load capacity. See page 91 for more information.



Mold-On Rubber



Pneumatic



Polyolefin




Polyurethane

ProCart™

VERSATILE STRUCTURAL FOAM UTILITY CART

800.253.2467
akro-mils.com**FEATURES**

- 1 Hinged side gates on both shelves flip up or down to easily convert the ProCart to a flat-top or box-top cart
- 2 Deep, molded-in compartments keep items within reach (Only large cart has cup holder)
- 3 Comfortable, full-width handle gives complete handling control
- 4 Smooth, rounded corners and edges
- 5 Toe-touch, locking rear swivel wheels
- 6 Durable, non-marking, polyurethane on polyolefin 5" wheels: 1.75" x 3" caster bolt pattern
- 7 I-beam post makes loading and unloading oversized boxes on the lower shelf easy
- 8 Optional rail systems (sold separately) allow AkroBins®, Super Modular Cabinets or 19-Series Steel Cabinets to hang on cart

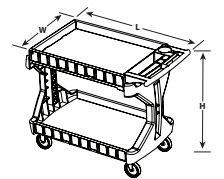**COLOR**
Gray**ProCart™**

ProCart		Dimensions (In.)			
Model No.	Description	L	W	H	Ctn. Qty.
30936	Large Cart	45-5/8	24	34-3/4	1
30930	Small Cart	41-1/2	19	34-3/4	1

ProCart Rail Kits

Model No.	Description
30900	Small Cart 9-Rail System
30906	Large Cart 9-Rail System
30902	Large Cart 2-Rail System for Super Modular Cabinets

Easy assembly – requires Phillips screwdriver and rubber mallet.

PRODUCT HIGHLIGHTS

- **VERSATILE** – All-purpose utility cart for the assembly line, warehouse or wherever you need portable storage
- **DURABLE** – High-density structural foam construction is dent-resistant, rust-proof and never needs painting
- **CAPACITY** – 400 lb. maximum cart load. 200 lb. capacity per top and bottom shelf
- **ASSEMBLY** – Light assembly required
- **VARIETY** – 2 sizes

AkroBins Ordering Information

To create a customized ProCart with AkroBins, use the chart below to determine the quantity of bins that will fit your ProCart. Carts, rail kits and bins must be ordered separately. When ordering, please specify color. See pages 4-5 for more information.

Use this chart when ordering one size AkroBins and 19-Series Cabinets for your ProCart

Bin Model No. Bin Dim. L x W x H	30210 5-3/8 x 4-1/8 x 3	30220 7-3/8 x 4-1/8 x 3	30224 10-7/8 x 4-3/16 x 4	30230 10-7/8 x 5-1/2 x 5	30234 14-3/4 x 5-1/2 x 5	30235 10-3/8 x 11 x 5	30239 10-3/4 x 8-1/4 x 7	30240 14-3/4 x 8-1/4 x 7	30250 14-3/4 x 16-1/2 x 7	30255 10-3/4 x 16-1/2 x 5	30320 8-5/8 x 33 x 5	19-Series Cabinet*
30936 Large Cart	80	80	48	36	36	18	16	16	8	12	6	4
30930 Small Cart	70	70	42	30	—	12	12	—	—	—	—	2

*Requires 98400 Suspension Straps for hanging.

RELATED PRODUCTS
Increase the benefits of
your ProCart with

4-5 AkroBins



26 Akro-Grids

46 19-Series
Steel Cabinets55 Super
Modular Cabinets



TiltView® Stack Cart

THE CONVENIENCE OF TILT-OUT BINS WITH A MOBILE CART

NEW!



UP TO
250
LBS.



FEATURES

- 1 Handles located at each cart end for transport convenience
- 2 Fully assembled cart includes 3-Bin, 4-Bin and 5-Bin TiltView cabinets
- 3 Quiet, 3" non-marking thermo-plastic rubber swivel casters with total lock brakes
- 4 Padded corner bumpers to protect walls and doorways from damage

PRODUCT HIGHLIGHTS

- **DURABLE** – Carts made of 16-gauge powder-coated steel
- **CAPACITY** – 250-lb. weight capacity (100 lbs. each side; 50 lbs. top)




TiltView Stack Cart			Dimensions (In.)			Total Bin Cups
Model No.	Description	Cart Color	L	W	H	
TVSTACKCART	Cart with (2) 3 bin, (4) 4-bin and (2) 5-bin TiltView Cabinets	Beige	25-1/2	18-1/2	39-1/2	32

COLOR
Beige



TiltView Bins		Dimensions (In.)			Dividers
Model No.	Description	L	W	H	
06703	3-Bin TiltView	7-7/8	23-5/8	9-7/16	40703 (3/Pk)
06704	4-Bin TiltView	6-3/4	23-5/8	8-3/16	40704 (4/Pk)
06705	5-Bin TiltView	5-3/8	23-5/8	6-1/2	—

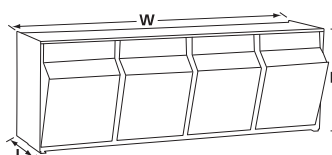

Louvered Carts

MOBILE WORKSTATION ACCOMMODATES
AKRODRAWERS® & AKROBINS®

800.253.2467
akro-mils.com



MA3618P



MA4824P

COLORS

Textured Charcoal Gray, Textured Putty



FEATURES

- 1 Welded steel frame
- 2 Tubular push handle featured on end of carts for easy handling
- 3 Louvered panels on cart end accommodate various sizes of AkroBins
- 4 Steel-reinforced butcher block work surface
- 5 Raised barriers near shelf edges keep AkroDrawers from sliding out when cart is in motion
- 6 2 rigid casters, 2 swivel casters with total lock brakes

MA3618C



PRODUCT HIGHLIGHTS


- **VERSATILE** – Industrial-grade mobile workstation
- **DURABLE** – Made from 16-gauge steel with a durable powder-coated finish
- **CAPACITY** – Non-marking blue elastic rubber casters allow a weight capacity of 800 lbs.
- **NO ASSEMBLY** – Ships fully assembled and ready to use
- **VARIETY** – 2 worktop sizes: 48" L x 24" W, and 36" L x 18" W. Colors: Textured Charcoal Gray, Textured Putty

Small Louvered Cart 37" L x 18" W x 36" H			Capacity/Qty.		
Model No.	Description	Cart Color	Wt. Capacity (lbs.)	Qty. of Drawers	Drawer Color
MA3618C MA3618P	Small Louvered Cart with no AkroDrawers	Textured Charcoal Gray Textured Putty	800	—	—
MA3618C1 MA3618P1	Small Louvered Cart with 31118 AkroDrawers	Textured Charcoal Gray Textured Putty	800	6	R,B,Y,GRY,CRY B,CRY
MA3618CAST MA3618PAST	Small Louvered Cart with 31168 & 31188 AkroDrawers	Textured Charcoal Gray Textured Putty	800	12 / 4	R,B,Y,GRY,CRY B,CRY

Specify drawer color when ordering: Red, Blue, Yellow, Gray or Crystal Clear available with Gray Cart. Blue or Crystal Clear available with Putty Cart. Only one color per unit.

Large Louvered Cart 49" L x 24" W x 37½" H			Capacity/Qty.		
Model No.	Description	Cart Color	Wt. Capacity (lbs.)	Qty. of Drawers	Drawer Color
MA4824C MA4824P	Large Louvered Cart with no AkroDrawers	Textured Charcoal Gray Textured Putty	800	—	—
MA4824C1 MA4824P1	Large Louvered Cart with 31142 & 31162 AkroDrawers	Textured Charcoal Gray Textured Putty	800	22 / 16	R,B,Y,GRY,CRY B,CRY
MA4824C2 MA4824P2	Large Louvered Cart with 31142 & 31182 AkroDrawers	Textured Charcoal Gray Textured Putty	800	22 / 10	R,B,Y,GRY,CRY B,CRY
MA4824C3 MA4824P3	Large Louvered Cart with 31112 AkroDrawers	Textured Charcoal Gray Textured Putty	800	16	R,B,Y,GRY,CRY B,CRY

Specify drawer color when ordering: Red, Blue, Yellow, Gray or Crystal Clear available with Gray Cart. Blue or Crystal Clear available with Putty Cart. Only one color per unit.

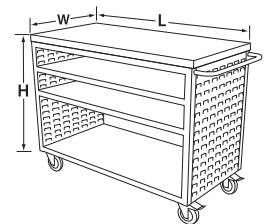

AkroDrawers®

AkroDrawers	Outside Dimensions (In.)		
Model No.	L	W	H
31142	11-5/8	3-3/4	4-5/8
31148	17-5/8	3-3/4	4-5/8
31162	11-5/8	5-9/16	4-5/8
31182	11-5/8	8-3/8	4-5/8
31164	23-7/8	5-9/16	4-5/8
31168	17-5/8	5-9/16	4-5/8
31188	17-5/8	8-3/8	4-5/8
31112	11-5/8	11-1/8	4-5/8
31118	17-5/8	11-1/8	4-5/8



Shelf Carts

HEAVY-DUTY CARTS ARE DESIGNED FOR DAILY WORK



UP TO
2200
LBS.

MADE
IN THE
USA



Shelf Options



Lips Down -
standard



Lips Up - add
"LU" to end of
Model No.



FEATURES

- 1 Heavy-duty, 13-gauge welded steel frame and shelves
- 2 Models feature 1½" lips down shelves
- 3 Variety of bolt-on casters available
- 4 Swayback, vertical and horizontal tubular push handles available

PRODUCT HIGHLIGHTS

- **DURABLE** – Made from 13-gauge steel with a durable powder-coated finish
- **CAPACITY** – Built to withstand loads up to 2,200 lbs. with recommended casters
- **NO ASSEMBLY** – Ships fully assembled and ready to use
- **VARIETY** – Cart sizes: 24" x 36", 24" x 48", 30" x 48", 30" x 60". Choose from several caster options as well as rubber matting, a writing shelf and drawers

COLOR
Gray



Shelf Carts

Model No. Lips Down*	Height (In.)	No. of Shelves	Shelf Clearance (In.)	Caster	Handle Style	Weight Capacity (lbs.)
R1S8FP2	33-1/2	2	20-3/4	8" Full Pneumatic	Swayback	1200
R1S10FP2	35-1/4	2	20-3/4	10" Full Pneumatic	Swayback	1200
R1S5HR	30	2	20-3/4	5" x 2" Polyolefin	Vertical	1800
R1S5HR2LD	25	2	15-1/2	5" x 2" Polyolefin	Swayback	1800
R1S8MR	33	2	20-3/4	8" x 2" Mold-On Rubber	Vertical	2200
R1S8MR2	33	2	20-3/4	8" x 2" Mold-On Rubber	Swayback	2200
R2ST5HR	30	2	20-3/4	5" x 2" Polyolefin	Horiz. Tubular	1800
R3ST5HR	30	3	9-5/8	5" x 2" Polyolefin	Horiz. Tubular	1800
R4ST5HR	63-1/4	4	17	5" x 2" Polyolefin	Horiz. Tubular	1800
R4ST8MR	66-1/4	4	17	8" x 2" Mold-On Rubber	Horiz. Tubular	2200
R5ST5HR	63-1/4	5	12-1/2	5" x 2" Polyolefin	Horiz. Tubular	1800
R5ST8MR	66-1/4	5	12-1/2	8" x 2" Mold-On Rubber	Horiz. Tubular	2200

Specify shelf size and lips up or lips down when ordering. *Standard shelves are lips down, to order lips up, add "LU" to the end of the Model Number.

ACCESSORIES



Drawer



Writing
Shelf



Rubber
Matting



Wheel
Locks

Handle Options



Swayback



Horizontal
Tubular



Vertical



R5SYT5HR2436B

MADE
IN THE
USA

SystemBins™

System Bin Multi-Shelf Carts	Dimensions (In.)			No. of Shelves	Caster	Handle (In.)	Bin/Qty.	Color	Weight Capacity (lbs.)
Model No.	L	W	H						
R5SYT5HR2436	36	24-1/2	40	5	5" x 2" Polyolefin	Horiz. Tubular	30312 / 10*	R, Y, B	1800
R5SYT8MR2436	36	24-1/2	43	5	8" x 2" Mold-On Rubber	Horiz. Tubular	30312 / 10*	R, Y, B	2200
R5SYT5HR3636	36	36-1/2	40	5	5" x 2" Polyolefin	Horiz. Tubular	30318 / 10**	R, Y, B	1800
R5SYT8MR3636	36	36-1/2	43	5	8" x 2" Mold-On Rubber	Horiz. Tubular	30318 / 10**	R, Y, B	2200

Bin color code: R=Red, B=Blue, Y=Yellow. Specify bin color when ordering. *Qty. of 30312 System Bins included. **Qty. of 30318 System Bins included.

Box Trucks : Tray Service Carts : Super-Size AkroBin® Carts

HEAVY-DUTY MOBILE CARTS FOR HEAVY, BULKY ITEMS

800.253.2467
akro-mils.com



Box Trucks



- DURABLE** – Made from 13-gauge all-welded steel with 2" hemmed edges or #13 expanded metal in 1½" x 1½" x ⅛" angle frame
- CAPACITY** – 1,800 lb. weight capacity. Steel Box dimensions: 30½" overall height, 24" interior depth; Expanded Metal Box dimensions: 31½" overall height, 25" interior depth
- CASTERS** – All box trucks have 2 swivel, 2 rigid, 5" x 2" polyolefin casters (additional caster types available)
- SECURE** – Lids can be secured with padlock or combination lock
- VARIETY** – Solid steel or expanded metal sides available. Box sizes: 24" x 36", 24" x 48", 30" x 36", 30" x 48". Available with optional lid



COLOR
Gray



CASTERS & WHEELS

Caster & Wheel choices allow you to resolve problems of noise control, floor protection, impact or abrasion resistance, or load capacity. See page 91 for more caster information.

Box Trucks			
Model No.	Description	Caster Type	Weight Capacity (lbs.)
R1B5HR	Solid Steel Box Truck	5" Polyolefin	1800
R1B5HRL	Solid Steel Box Truck with Lid	5" Polyolefin	1800
R1B5HRX	Expanded Metal Box Truck	5" Polyolefin	1800
R1B5HRXL	Expanded Metal Box Truck with Lid	5" Polyolefin	1800

Tray Service Cart



- EFFICIENT** – Excellent for library, manufacturing and food service operations
- DURABLE** – 13-gauge all-welded steel construction features 12" deep tray and 12½" clear shelf spacing with 1½" lip
- CASTERS** – 2 swivel, 2 fixed
- HANDLE** – Tubular push handle for easy handling
- VARIETY** – Standard sizes include 18" x 30", 24" x 36", 24" x 48"; optional size: 18" x 36"

UP TO
2200
LBS.



COLOR
Gray



Tray Service Cart	Dimensions (In.)			Casters	Weight Capacity (lbs.)
Model No.	L	W	H		
R2T5HR1830	18	30	32-1/2	5" Polyolefin	1800
R2T5HR2436	24	36	32-1/2	5" Polyolefin	1800
R2T5HR2448	24	48	32-1/2	5" Polyolefin	1800
R2T8MR2448	24	48	35-1/2	8" Mold-On Rubber	2200

Super-Size AkroBin® Carts

UP TO
1500
LBS.



COLOR
Gray



- MOBILE** – Mobilize your Super-Size AkroBins
- EFFICIENT** – Easy organization of bulky parts
- DURABLE** – Made from 11-gauge steel
- CAPACITY** – Heavy-duty frames with weight capacities from 900 to 1,500 lbs.
- VARIETY** – 4, 6, 9, 12 and 16-bin configurations (Super-Size AkroBins sold separately). Carts have 5" x 2" polyolefin casters. Optional security bar locks bins in place

Super-Size AkroBin Steel Carts		Dimensions (In.)			No. of Handles	Accessories	Capacity/Qty.	
Model No.	Bin Compatibility	L	W	H		Security Bar	Capacity (lbs.)	Ctn. Qty.
R214CS1841	Six 30283 Bins	41	18	48	2	RSSAKBINHDDWN6	900	1
R214CS1859	Nine 30283 Bins	59	18	48	2	RSSAKBINHDDWN9	1350	1
R214CS1878	Twelve 30283 Bins	78	18	48	2	RSSAKBINHDDWN12	1500	1
R214CS2841	Six 30290 Bins	41	27-1/2	48	2	RSSAKBINHDDWN6	900	1
R214CS2859	Nine 30290 Bins	59	27-1/2	48	2	RSSAKBINHDDWN9	1350	1
R214CS2878	Twelve 30290 Bins	78	27-1/2	48	2	RSSAKBINHDDWN12	1500	1
R216CS2236	Sixteen 30284 Bins or six 30286 Bins or six 30287 Bins or four 30288 Bins	35-1/2	22-1/8	35	1	–	900	1
R216CS2836	Six 30292 Bins or four 30293 Bins	35-1/2	28-1/8	35	1	–	900	1
R216CS2239	Four 30289 Bins	35-1/2	22-1/8	39	1	–	900	1

Optional security bar available for all sizes. Bins sold separately.

Portable Tables & Carts : Mobile Work Tables

VERSATILE MOBILE SYSTEMS & WORK CENTERS

Portable Tables & Carts



- **VERSATILE** – Carts are ideal for stock picking, assembly operations or other heavy-duty tasks
- **DURABLE** – All-welded, 16-gauge steel construction. Gray powder-coated finish. Angle posts for added strength. Ships fully assembled!
- **CASTERS** – Non-marking thermo-plastic 5" x 1 1/4" soft rubber casters for quiet and smooth maneuverability
- **DRAWER** – High-quality storage drawer is padlock-ready
- **VARIETY** – 2 sizes. Optional drawer, writing shelf, rubber shelf matting or wheel locks are available (sold separately)

Portable Tables							
Model No.	Cart Size (In.)	Height (In.)	No. of Shelves	Shelf Clearance (In.)	Caster	Handle Style	Weight Capacity (lbs.)
RMD2ST5SR	24 x 36	36	2	27	2 Swivel / 2 Rigid	Tubular	800
RMD3ST5SR	24 x 36	36	3	12-1/2	2 Swivel / 2 Rigid	Tubular	800



RMD2ST5SR



COLOR
Gray



Mobile Work Tables – Heavy-Duty



- **MULTI-SHELF** – Includes 21" D x 36" W bottom shelf; 13 1/2" D x 37" W tilted shelf for easy access to bins
- **DURABLE** – Industrial-grade mobile workstation with a welded-steel frame and steel-reinforced premium oak top. Gray powder-coated finish. Ships fully assembled!
- **ADJUSTABLE** – 24" L x 48" W work area with 9 adjustable height settings from 36" to 48"
- **WOOD TOP** – Kiln-dried hardwood work surface extends 2" to accommodate vise or clamps; wood top is premium oak boards with rounded edges 2 1/4" in overall thickness; individual planks are 1 1/8" (5/4); optional butcher block top available
- **CASTERS** – 5" x 2" bolted-on polyurethane casters; 2 rigid, 2 swivel with total lock brakes

Mobile Work Tables - Heavy-Duty		Dimensions (In.)			Caster		
Model No.	Deck Type	L	W	H	Type	Size (In.)	Weight Capacity (lbs.)
RHWB2448P5PY0G	Oak Hardwood	24	48	36 to 48	Polyurethane	5 x 2	800

COLOR
Gray



RHWB2448P5PY0



Mobile Work Tables – Medium-Duty



- **DURABLE** – Industrial-grade mobile workstation with a welded-steel frame and steel-reinforced tongue and groove hardwood top. Gray powder-coated finish. Ships fully assembled!
- **CASTERS** – 2 bolted-on non-marking thermo-plastic soft rubber casters; 2 swivel 5" x 1 1/4" casters with total lock brakes
- **DRAWERS** – 2 padlock-ready steel drawers: 15 3/4" W x 6 3/4" H x 20" D

Mobile Work Tables - Medium-Duty		Dimensions (In.)			Caster		
Model No.	Deck Type	L	W	H	Type	Size (In.)	Weight Capacity (lbs.)
RMWB24485SRTPG	Hardwood	24	48	36	Thermoplastic	5 x 1-1/4	800

COLOR
Gray



RMWB24485SRTP





Heavy-Duty Work Benches

ADJUSTABLE & FIXED WORK HEIGHTS

800.253.2467
akro-mils.com

CARTS & WORK
CENTERS

FEATURES

- 11-gauge steel work surface extends 1½" on front and sides to accommodate a vise or clamps (hardwood extends 2")
- Wraparound steel backstop keeps items from falling behind work bench
- Adjustable work height telescoping C-channel legs provide a range of work heights from 30" to 40" (1½" increments)
- 12-gauge welded steel shelves
- 13½" deep middle shelf is sloped for easy access to bins or containers
- Anchor pads on each leg secure bench in a fixed position
- Durable powder-coated finish

PRODUCT HIGHLIGHTS

- DURABLE** – Heavy-duty steel frame work bench. Gray powder-coated finish.
- VARIETY** – Bench sizes: 30" x 60" and 30" x 72". Fixed or adjustable work heights. Steel, kiln-dried premium hardwood, butcher block or composition work surface. Work surface thickness: wood 2¼"; butcher block 1¾"; composition 1¾"



How to Order Your Work Bench

STEP 1

PICK A SIZE

Standard work table sizes:
30" x 60" • 30" x 72"

STEP 2

PICK FRAME COLOR (G)

Standard color:
Gray

STEP 3

PICK HEIGHT STYLE (F, A)

Fixed Height:
34" high

Adjustable Height:
30" - 40" high

STEP 4

PICK SHELF OPTIONS (1, 2, 3, 4)

- Option 1:**
Both shelves FORWARD, toward the front of the bench
- Option 2:**
Both shelves BACK, toward the back of the bench
- Option 3:**
Middle shelf FORWARD, bottom shelf BACK
- Option 4:**
Middle shelf BACK, bottom shelf FORWARD

STEP 4

PICK WORK SURFACE (S, P, B, C)

- Steel (S):**
11-gauge steel
- Hardwood (P):**
Premium kiln-dried hardwood 2¼" thick
- Butcher Block (B):**
1¾"
- Composition (C):**
1¾"

Call your Akro-Mils distributor with your model number today to order

model #	step 1	step 2	step 3	step 4	step 5
H-D Work Bench	Size	Frame Color	Height Style	Shelf Options	Work Surface
RHWB	3060 3072	G (Gray)	F (Fixed) A (Adjustable)	1 (Both shelves forward) 2 (Both shelves back) 3 (Middle fwd, Bottom back) 4 (Middle back, Bottom fwd)	S (Steel) P (Hardwood) B (Butcher Block) C (Composition)
RHWB	3060	G	F	3	B =



**Ships fully
assembled &
ready to use!**

MADE
IN THE
USA