

Circular DIN Receptacles


A typical standard receptacle is shown to the right, and typical receptacles with front metal shield are shown below. Mating face layouts and pc board hole patterns are shown on page 4.

Materials


Housings — 94V-0 rated nylon, black

Contacts and Shield — Brass, tin plated


Standard Receptacle

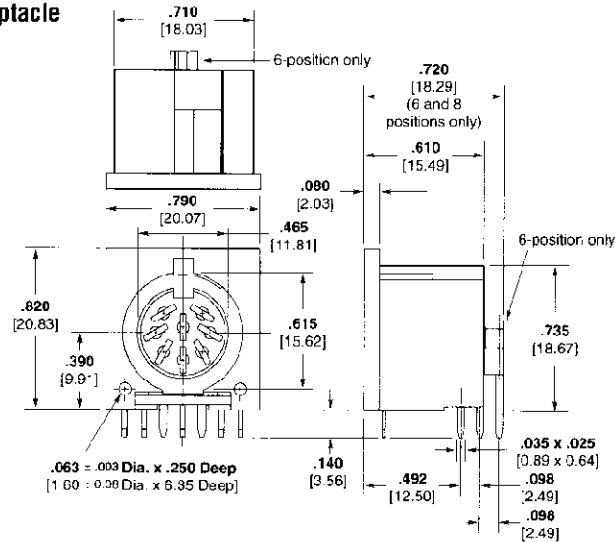


Standard Receptacle with Front Metal Shield

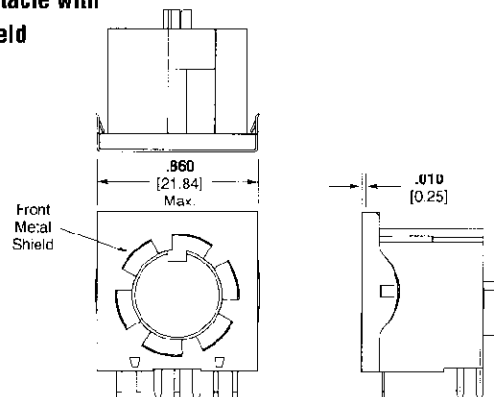


Receptacle with Front Metal Shield (2 Mounting Holes)

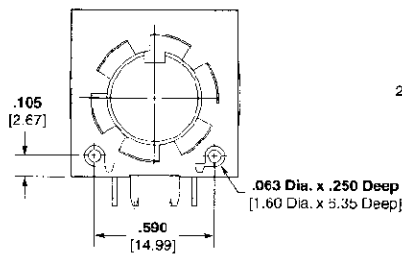

Receptacle with Front Metal Shield (4 Mounting Holes)

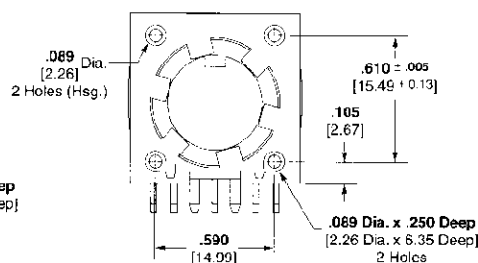

Receptacle with Front Metal Shield (with Front Grounding Fingers)

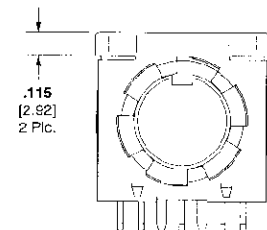

No. of Positions	Receptacle Part Numbers					
	Standard	Standard Shielded	Standard with 4 Mounting Holes	Shielded with 2 Mounting Holes	Shielded with 4 Mounting Holes	Shielded with Grounding Fingers
4	211508-1	—	—	212032-1	—	—
5	211450-1	212044-1	212476-1	520842-1	520904-1	750477-1
6	211509-1	212045-1	786290-1	—	—	786676-1
7	211510-1	212046-1	786165-1	—	—	—
8	211511-1	212047-1	—	212034-1	—	787013-1

Notes: 1. For applications requiring a 3-position connector, use a 5-position connector (contact positions 4 and 5 not used).
2. For receptacles with alternate mating face layouts or pc board hole patterns, consult AMP Incorporated.