




1711342-2 Product Details

 Share

 Print

 Email

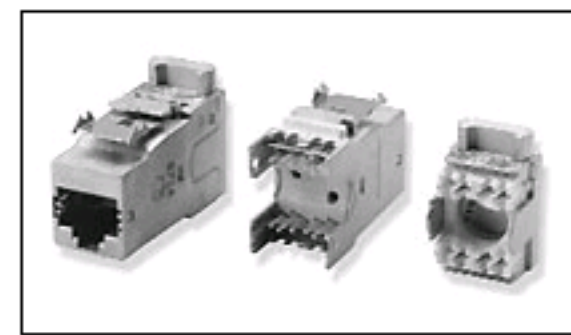

1711342-2

TE Internal Number: 1711342-2

 Active

Cable Mounted Jacks

 Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Connector - Modular
- Region = Asia, Latin America, North America
- Jack Type = RJ45
- Performance Category = Cat 6A
- Shielded

[View all Features](#)

 [Add to My Part List](#)

 [Request Sample](#)

 [Find Similar Products](#)

 [Buy Product](#)

Quick Links

- [▶ Pricing & Availability](#)
- [▶ Search for Tooling](#)
- [▶ Product Feature Selector](#)
- [▶ Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [AMP-TWIST-6S SL Jack, W/O dust cover, rear cable exit \(PDF, English\)](#)

Catalog Pages/Data Sheets:

- [XG Category 6A F/UTP Cabling System Products - Perf... \(PDF, English\)](#)
- [Enterprise Networks Guia Rapida de Productos \(PDF, Spanish\)](#)

Product Specifications:

- [AMP-TWIST Series Jacks for Class EA Systems \(PDF, English\)](#)

Application Specifications:

- None Available

Instruction Sheets:

- [AMP-TWIST-6S SL Jack; PN 1711160-\[\] and 1711342-\[\] \(PDF, English\)](#)

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Connector - Modular
- Jack Type = RJ45
- [Performance Category](#) = Cat 6A
- Termination Style = SL Termination Tool
- Series = AMP-TWIST
- System = AMP-TWIST
- Wiring Pattern = Universal
- [Keyed](#) = No

Electrical Characteristics:

- Shielded = Yes

Dimensions:

- Conductor Outer Diameter (mm [in]) = 1.60 [0.0629]
- Cable Diameter (Max.) (mm [in]) = 9.00 [0.354]

Body Features:

- NETCONNECT Select System = Yes
- Mount Type = Panel Mount
- Wire Range (Solid) (mm [AWG]) = 22-24
- Wire Range (Stranded) (mm² [AWG]) = 24-26
- 110 Block Material = Polycarbonate

Contact Features:

- Contact Base Material = Beryllium Copper
- Contact Plating, Mating Area, Material = Gold
- Contact Plating, Mating Area, Thickness (µm [µin]) = 1.27 [50]

Housing Features:

- Housing Color = Gray
- Housing Material = Zamak 5

Configuration Features:

- Dust Cover = Without
- Number of Positions = 8

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Features:

- Packaging Method = Tray
- Packaging Quantity = 12

Product Availability:

- Region = Asia, Latin America, North America

Other:

- Brand = TE Connectivity
- Comment = Rear Exit, optimized for F/UTP cables

Corporate Information

[About TE](#)

[Investors](#)

[News Room](#)

[Supplier Portal](#)

[Careers](#)

[Terms & Conditions](#)

[Privacy Policy](#)

Quick Links

[Distributor Inventory](#)

[Product Cross Reference](#)

[Documents & Drawings](#)

[Product Compliance Support Center](#)

[Site Map](#)

Customer Support

[Email or Chat With Us](#)

[Find a Phone Number](#)

[Knowledge Base](#)

[Manage Your Account](#)

Keep Me Informed

