


324487 Product Details

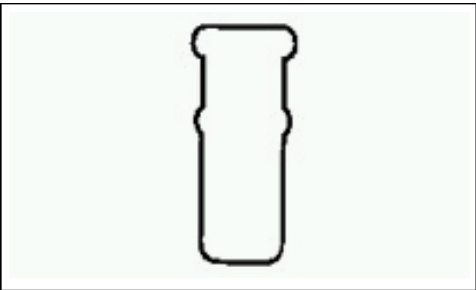

324487

 [Active](#)

Splices - Closed Barrel

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ?

Wire Caps for Unstripped Wire
- ?

Not Sealed
- ?

Body Style = PIDG
- ?

Insulated
- ?

Insulation Support

[View all Features](#) | [Find Similar Products](#)

 **Live Product Chat** US Only
8:30am - 5pm ET, Mon - Fri

Quick Links

[Check Pricing & Availability](#)

[Search for Tooling](#)

[Product Feature Selector](#)

[Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ?

[SPARE WIRE CAP,YELLOW](#) (PDF, English)

Catalog Pages/Data Sheets:

- ?

None Available

Product Specifications:

- ?

None Available

Application Specifications:

- ?

[Pre-Insulated Diamond Grip \(PIDG\) Terminals, Splices...](#) (PDF, English)

Instruction Sheets:

- ?

None Available

CAD Files:

- ?

None Available

Additional Information:

- ?

[Product Line Information](#)

Related Products:

- ?

[Tooling](#)

[List all Documents](#)

Product Features

(Please use the Product Drawing for all design activity)

Product Type Features:

- ?

[Product Type](#) = Wire Caps for Unstripped Wire
- ?

[Sealed](#) = No
- ?

[Body Style](#) = PIDG
- ?

[Insulation](#) = Yes
- ?

[Insulation Support](#) = Insulation Support
- ?

[Insulation Diameter \(mm \[in\]\)](#) = 3.81 -5.59
[.150 -.220]
- ?

[Material](#) = Copper
- ?

[Finish](#) = Tin
- ?

Color = Yellow

Industry Standards:

- ?

Government/Industry Qualification = No
- ?

[RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ?

[Lead Free Solder Processes](#) = Not relevant for lead free process
- ?

RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- ?

[Packaging Method](#) = Loose Piece

Other:

- ?

Brand = AMP