




+ CONNECTORS

RJ45 CONNECTORS

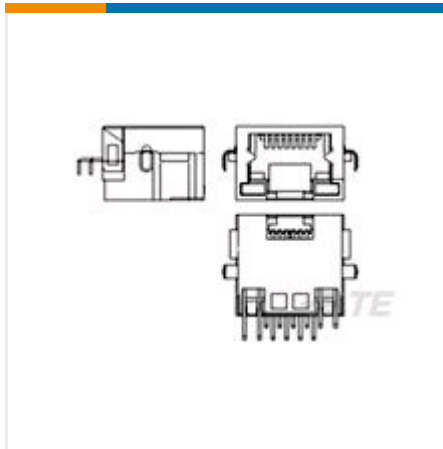

✓ Active

TE CONNECTIVITY (TE)

RJ45 w/ LED, Tab Up, Offset, DIP, H=9.45

Modular Jacks & Plugs | A-RJ45 , H9

2041411-1

TE Internal Number: 2041411-1

EU RoHS Compliant

EU ELV Compliant

Port Configuration Single

Shielded Yes

Port Matrix Configuration 1 x 1

Connector Style Jack

Inverted Jack Face Yes

↓ **PRODUCT DRAWING**
English

↓ **3D PDF**

DOCUMENTATION

Product Drawings

MODULAR JACK ASSEMBLY RJ45 WITH LED, 8P8C, TAB UP SHIELDED, OFFSET, DIP TYPE

PDF

English

CAD Files

3D PDF

PDF

3D

Customer View Model

2D_DXF.ZIP

English

Customer View Model

3D_IGS.ZIP

English

Customer View Model

3D_STP.ZIP

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Modular Jack & Plug Interface Type RJ45

Shielded Yes

Connector Style Jack

LED With

Performance Category Cat 3

Profile Offset - Overhangs PCB, Very Low

PCB Mounting Orientation Side Entry (Right Angle)

Connector & Contact Terminates To Printed Circuit Board

Product Type Connector

Grounding Options PCB Ground

Panel Stops Without

Connector Type Connector Assembly

Configuration Features

Port Configuration Single

Port Matrix Configuration 1 x 1

Number of Positions 8

Keyed No

Number of PCB Ground Tabs 2

Preloaded Yes

Body Features

Inverted Jack Face Yes

LED Color (Bottom Right) Green

Shield Material Brass

LED Color (Bottom Left) Green/Yellow

Shield Plating Material Nickel

Color Black

Contact Features

Solder Tail Contact Plating Material Gold Flash over Nickel

Contact Base Material Phosphor Bronze

Number of Contacts Loaded 8

Contact Mating Area Plating Thickness (µin) 6

Contact Mating Area Plating Material Gold

Termination Features

Termination Method to PC Board Through Hole - Solder

Mechanical Attachment

Panel Mount Feature Without
PCB Mounting Style Through Hole

Housing Features

Housing Material PA 9T GF30
Housing Color Black

Dimensions

Height 9.45 mm [.372 in]
PCB Tail Length 2.2 mm [.087 in]

Industry Standards

UL Flammability Rating UL 94V-0

Packaging Features

Packaging Quantity 150
Packaging Method Tape & Reel

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance

PDF
