






Back

| Selected Cable: 17000A | | | | |
|------------------------|---|---|---|---|
| End View | Plug | Cord | Connector | End View |
| |  |  |  |  |
| 5-15P | 290B | SVT | 386 | C13 |

| | |
|-----------------------------------|--------------------------------|
| Part Number | 17000A |
| Category | 3 conductor plastic detachable |
| Shielding | unshielded |
| Jacket Color | Black, |
| Length Feet | 3' |
| Length Meters | 0.91 |
| Temperature Rating | 60 C°C |
| Packaging Units Per Carton | B-25, S25 |
| Color Coding | North America |
| AWG Stranding | 18 (41x34) |
| Nominal OD Inch | 0.246 |
| Nominal OD millimeter | 6.25 |
| Rating | 1250 Watts 10A-125V |

Cord View

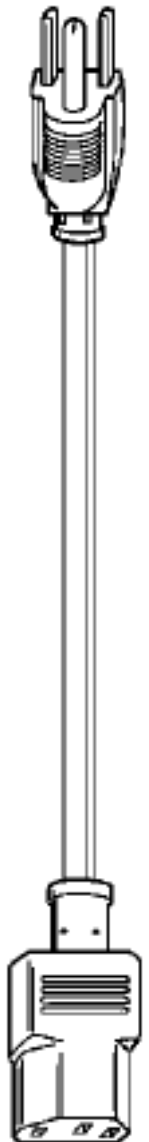

Approvals



Qty:

Back

Volex Power Cord Products Division, 5350 Lakeview Parkway S. Drive #D Indianapolis, IN 46268
800-246-CORD. info@volexpowercords.com

Proposition 65 warning for California residents: This product contains chemicals, including lead, known to the State of California to cause (cancer, and) birth defects or other reproductive harm. Wash hands after handling.

