

NARROW CARRIAGE PRINTER CROSS-REFERENCE

These wide carriage labels will not fit narrow carriage (80-column) printers. Identical labels on narrow carriage liners are listed below.


WIDE CARRIAGE MODELS		NARROW CARRIAGE MODELS	
Reference	Specifications On Page	Reference	Specifications On Page
DAT-1-637	155	DAT-49-637	155
DAT-2-637	156	DAT-72-637	156
DAT-8-292	167	DAT-63-292	166
DAT-9-292	167	DAT-75-292	167
DAT-10-637	156	DAT-73-637	156
DAT-12-502	157	DAT-64-502	157
DAT-14-292	167	DAT-65-292	166
DAT-23-637	156	DAT-74-637	156
DAT-30-292	166	DAT-66-292	166
DAT-31-502	154	DAT-67-502	154
DAT-32-632	154	DAT-68-632	154
DAT-41-292	166	DAT-69-292	166
DAT-42-292	166	DAT-70-292	166
DAT-55-642	166	DAT-71-642	166




Print your own wire markers in-house as you need them. (Product shown: DAT-5-502)

Labels Index by Size

MULTIPLE ACROSS RADIUS CORNERS

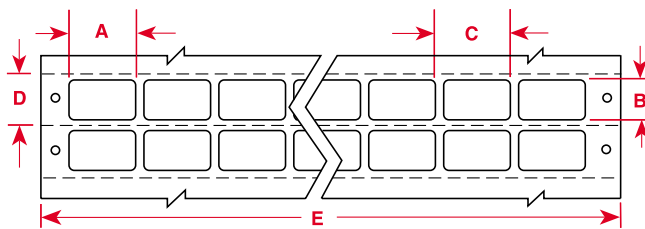

BUTT CUT SQUARE CORNERS

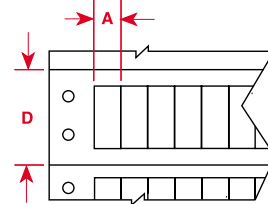

DAT-137-502-10

Dot Matrix Technology
7.62 x 19.05 mm Rating Plate
Package Quantity, 10,000
Material B-502, White Vinyl Cloth

REFERENCE EXPLANATION:

Most BRADY part numbers for computer printable labels follow the same four-part format:



The first code indicates the technology, the second part is a number indicating the die size used (where applicable), the third part indicates the BRADY material used (where applicable), and the final code indicates package quantity.

Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Vertical Repeat D mm	Web Width E mm
7.62 mm Label Width - Square Corners									
DAT-137-502-1,-10	1,000/10,000	Vinyl Cloth	White	16	7.62	19.05	7.62	25.40	147.32
DAT-138-632-1,-10	1,000/10,000	Polyvinylfluoride	White	16	7.62	19.05	7.62	25.40	147.32
DAT-140-502-1,-10	1,000/10,000	Vinyl Cloth	White	16	7.62	23.80	7.62	25.40	147.32
DAT-141-632-1,-10	1,000/10,000	Polyvinylfluoride	White	16	7.62	23.80	7.62	25.40	147.32
9.53 mm Label Width									
DAT-113-164-1,-10	1,000/10,000	Polyester	Silver	16	9.53	9.53	12.70	12.70	226.06
DAT-114-673-1,-10	1,000/10,000	Polyester	White	16	9.53	9.53	12.70	12.70	226.06
DAT-115-652-1,-10	1,000/10,000	Polyimide	Amber	16	9.53	9.53	12.70	12.70	226.06
DAT-116-658-1,-10	1,000/10,000	Polyimide	Amber	16	9.53	9.53	12.70	12.70	226.06
DAT-117-607-1,-10	1,000/10,000	Tamper-Resistant Vinyl	White	16	9.53	9.53	12.70	12.70	226.06
DAT-118-619-1,-10	1,000/10,000	Polyester	White	16	9.53	9.53	12.70	12.70	226.06
DAT-119-502-1,-10	1,000/10,000	Vinyl Cloth	White	16	9.53	9.53	12.70	12.70	226.06

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

Labels Index by Size

CONTINUED

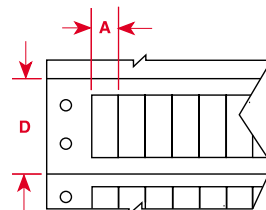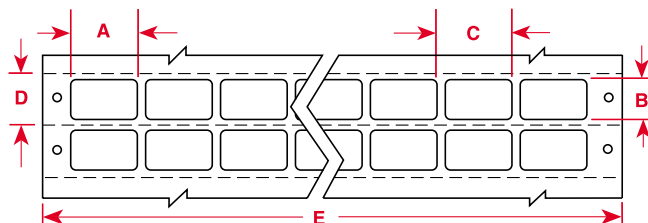

Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Vertical Repeat D mm	Web Width E mm
10.16 mm Label Width									
DAT-179-619-1,-10	1,000/10,000	Polyester	White	16	1016	5.08	12.70	6.35	226.06
DAT-179-652-1	1,000	Polyimide	Amber	16	1016	5.08	12.70	6.35	226.06
DAT-178-619-1	1,000	Polyester	White	16	1016	12.70	12.70	16.94	226.06
11.10 mm Label Width									
DAT-61-502-1,-10	1,000/10,000	Vinyl Cloth	White	12	1110	65.07	15.24	76.20	203.20
DAT-62-502-1,-10	1,000/10,000	Vinyl Cloth	White	12	1110	92.08	15.24	101.60	203.20
12.70 mm Label Width									
DAT-67-499-1,-10	1,000/10,000	Nylon Cloth	White	12	12.70	19.05	15.24	25.40	205.74
DAT-67-502-1,-10	1,000/10,000	Vinyl Cloth	White	12	12.70	19.05	15.24	25.40	205.74
DAT-68-632-1,-10	1,000/10,000	Polyvinylfluoride	White	12	12.70	19.05	15.24	25.40	205.74
DAT-31-502*-1,-10	1,000/10,000	Vinyl Cloth	White	14	12.70	19.05	15.24	25.40	236.22
DAT-32-632*-1,-10	1,000/10,000	Polyvinylfluoride	White	14	12.70	19.05	15.24	25.40	236.22
DAT-21-110-1,-10	1,000/10,000	Saturated Paper	White	12	12.70	36.50	15.24	38.10	205.74
DAT-24-499-1,-10	1,000/10,000	Nylon Cloth	White	12	12.70	36.50	15.24	38.10	205.74
DAT-24-502-1,-10	1,000/10,000	Vinyl Cloth	White	12	12.70	36.50	15.24	38.10	205.74
12.70 mm Label Width - Square Corners									
DAT-43-502-1,-10	1,000/10,000	Vinyl Cloth	White	16	12.70	1110	12.70	12.70	228.60
DAT-44-607-1,-10	1,000/10,000	Tamper-Resistant Vinyl	White	16	12.70	1110	12.70	12.70	228.60
DAT-45-619-1,-10	1,000/10,000	Polyester	White	16	12.70	1110	12.70	12.70	228.60
DAT-46-693-1,-10	1,000/10,000	Polyester	Silver	16	12.70	1110	12.70	12.70	228.60
DAT-46-969-1,-10	1,000/10,000	Polyester	Silver	16	12.70	1110	12.70	12.70	228.60
DAT-98-673-1,-10	1,000/10,000	Polyester	Silver	16	12.70	1110	12.70	12.70	228.60
DAT-171-652-1,-10	1,000/10,000	Polyimide	Amber	16	12.70	1110	12.70	12.70	228.60
DAT-143-502-1,-10	1,000/10,000	Vinyl Cloth	White	16	12.70	23.80	12.70	25.40	228.60
DAT-144-632-1,-10	1,000/10,000	Polyvinylfluoride	White	16	12.70	23.80	12.70	25.40	228.60
15.00 mm Label Width									
DAT-G7-502-1,-10	1,000/10,000	Vinyl Cloth	Yellow	11	15.00	9.00	17.78	12.70	219.40
16.51 mm Label Width									
DAT-15-129-1,-10	1,000/10,000	Paper	White	10	16.51	5.08	20.32	6.35	224.80
DAT-15-502-10-RF**	10,000	Vinyl Cloth	White	10	16.51	5.08	20.32	6.35	224.80
DAT-16-607-1,-10	1,000/10,000	Tamper-Resistant Vinyl	White	10	16.51	5.08	20.32	6.35	224.80
DAT-17-619-1,-10	1,000/10,000	Polyester	White	10	16.51	5.08	20.32	6.35	224.80
DAT-56-637-1,-10	1,000/10,000	Tedlar®	White	10	16.51	5.08	20.32	6.35	224.80
DAT-58-652-1,-10	1,000/10,000	Polyimide	Amber	10	16.51	5.08	20.32	6.35	224.80
DAT-88-693-1,-10	1,000/10,000	Polyester	Silver	10	16.51	5.08	20.32	6.35	224.80
DAT-88-969-1,-10	1,000/10,000	Polyester	Silver	10	16.51	5.08	20.32	6.35	224.80
DAT-109-658-1,-10	1,000/10,000	Polyimide	Amber	10	16.51	5.08	20.32	6.35	224.80
DAT-111-164-1,-10	1,000/10,000	Polyester	Silver	10	16.51	5.08	20.32	6.35	224.80
DAT-G5-619-1,-10	1,000/10,000	Polyester	White	10	16.51	5.08	20.32	8.47	224.80

Tedlar® is a registered trademark of DuPont.



* Size does not fit narrow carriage (80-column) printers. See p.153 for identical narrow carriage labels.

**RF : These parts are supplied on a 76.20 mm are for those applications requiring a roll form (RF) feed mechanism into the printer.

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

Labels Index by Size

CONTINUED

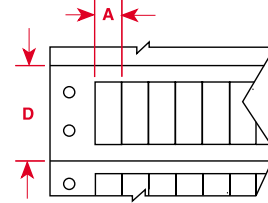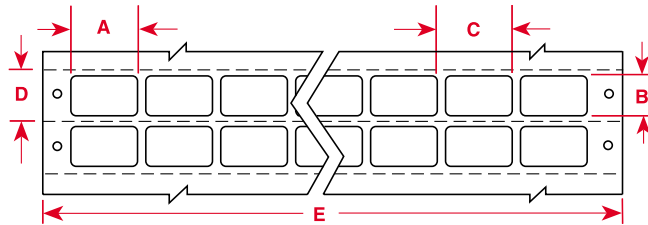

Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Vertical Repeat D mm	Web Width E mm
19.00 mm Label Width									
DAT-G3-502-1,-10	1000/10,000	Vinyl Cloth	White	9	19.00	11.00	22.86	16.90	227.28
19.05 mm Label Width									
DAT-25-129-1,-10	1000/10,000	Vinyl Cloth	White	9	19.05	6.35	22.86	8.46	228.60
DAT-25-502-1,-10	1000/10,000	Vinyl Cloth	White	9	19.05	6.35	22.86	8.46	228.60
DAT-25-502-10-RF**	10,000	Vinyl Cloth	White	9	19.05	6.35	22.86	8.46	228.60
DAT-26-607-1,-10	1000/10,000	Tamper-Resistant Vinyl	White	9	19.05	6.35	22.86	8.46	228.60
DAT-27-619-1,-10	1000/10,000	Polyester	White	9	19.05	6.35	22.86	8.46	228.60
DAT-89-969-1,-10	1000/10,000	Polyester	Silver	9	19.05	6.35	22.86	8.46	228.60
DAT-96-652-1,-10	1000/10,000	Polyimide	Amber	9	19.05	6.35	22.86	8.46	228.60
DAT-110-658-1,-10	1000/10,000	Polyimide	Amber	9	19.05	6.35	22.86	8.46	228.60
DAT-112-164-1,-10	1000/10,000	Polyester	Silver	9	19.05	6.35	22.86	8.46	228.60
DAT-124-502-1,-10	1000/10,000	Vinyl Cloth	White	9	19.05	6.35	22.86	9.53	228.60
DAT-125-607-1,-10	1000/10,000	Tamper-Resistant Vinyl	White	9	19.05	6.35	22.86	9.53	228.60
DAT-126-619-1,-10	1000/10,000	Polyester	White	9	19.05	6.35	22.86	9.53	228.60
DAT-127-969-1,-10	1000/10,000	Polyester	Silver	9	19.05	6.35	22.86	9.53	228.60
DAT-128-652-1,-10	1000/10,000	Polyimide	Amber	9	19.05	6.35	22.86	9.53	228.60
DAT-129-658-1,-10	1000/10,000	Polyimide	Amber	9	19.05	6.35	22.86	9.53	228.60
DAT-130-164-1,-10	1000/10,000	Polyester	Silver	9	19.05	6.35	22.86	9.53	228.60
DAT-161-637-1,-10	1000/10,000	Polyvinylfluoride	White	9	19.05	6.35	22.86	8.46	228.60
20.00 mm Label Width									
DAT-G2-502-1,-10	1000/10,000	Vinyl Cloth	White	9	20.00	8.00	22.86	12.70	228.60
20.32 mm Label Width									
DAT-5-499-1,-10	1000/10,000	Nylon Cloth	White	6	20.32	36.50	22.86	38.10	160.02
DAT-5-502-1,-10	1000/10,000	Vinyl Cloth	White	6	20.32	36.50	22.86	38.10	160.02
DAT-6-632-1,-10	1000/10,000	Polyvinylfluoride	White	6	20.32	36.50	22.86	38.10	160.02
DAT-G1-502-1,-10	1000/10,000	Vinyl Cloth	White	6	20.32	36.50	23.00	38.10	160.00
DAT-146-502-1,-10	1000/10,000	Vinyl Cloth	White	6	20.32	36.50	23.00	32.10	160.00
DAT-147-632-1,-10	1000/10,000	Polyvinylfluoride	White	10	20.32	23.80	20.32	25.40	228.60
22.86 mm Label Width									
DAT-1-637*-1,-10	1000/10,000	Polyvinylfluoride	White	10	22.86	6.35	25.40	8.46	226.06
DAT-49-637-1,-10	1000/10,000	Polyvinylfluoride	White	8	22.86	6.35	25.40	8.46	226.06
DAT-50-652-1,-10	1000/10,000	Polyimide	Amber	8	22.86	6.35	25.40	8.46	226.06
DAT-60-619-1,-10	1000/10,000	Polyester	White	8	22.86	6.35	25.40	8.46	226.06
DAT-120-164-1,-10	1000/10,000	Polyester	Silver	8	22.86	6.35	25.40	8.46	226.06
DAT-94-652-1,-10	1000/10,000	Polyimide	Amber	8	22.86	6.35	25.40	8.46	226.06
DAT-95-619-1,-10	1000/10,000	Polyester	White	8	22.86	6.35	25.40	8.46	226.06
DAT-132-637-1,-10	1000/10,000	Polyvinylfluoride	White	8	22.86	6.35	25.40	9.53	226.06
DAT-133-652-1,-10	1000/10,000	Polyimide	Amber	8	22.86	6.35	25.40	9.53	226.06
DAT-134-619-1,-10	1000/10,000	Polyester	White	8	22.86	6.35	25.40	9.53	226.06
DAT-135-164-1,-10	1000/10,000	Polyester	Silver	8	22.86	6.35	25.40	9.53	226.06

Tedlar® is a registered trademark of DuPont.

* Size does not fit narrow carriage (80-column) printers. See p. 153 for identical narrow carriage labels.


**RF : These parts are supplied on a 76.20 mm are for those applications requiring a roll form (RF) feed mechanism into the printer.

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

DOT MATRIX LABELS INDEX BY SIZE

Labels Index by Size

CONTINUED

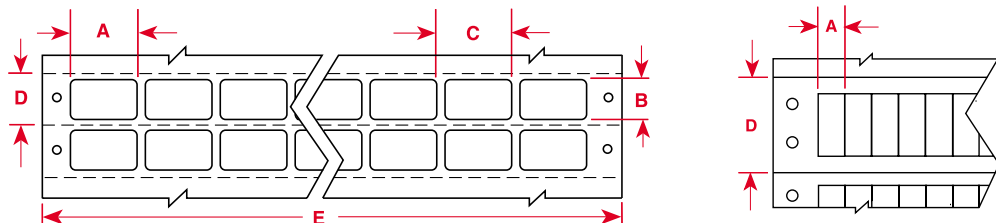

Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Vertical Repeat D mm	Web Width E mm
25.40 mm Label Width									
DAT-181-619-1	1000/10,000	Polyester	White	7	25.40	6.35	27.94	8.46	218.44
DAT-181-652-1	1000	Polyimide	Amber	7	25.40	6.35	27.94	8.46	218.44
DAT-11-499-1,-10	1000/10,000	Nylon Cloth	White	7	25.40	9.53	27.90	12.70	218.44
DAT-11-502-1,-10	1000/10,000	Vinyl Cloth	White	7	25.40	9.53	27.90	12.70	218.44
DAT-11-502-10-RF**	10,000	Vinyl Cloth	White	7	25.40	9.53	27.90	12.70	218.44
DAT-51-619-1,-10	1000/10,000	Polyester	White	7	25.40	9.53	27.90	12.70	218.44
DAT-18-129-1,-10	1000/10,000	Paper	White	7	25.40	12.70	27.94	16.94	218.44
DAT-18-499-1,-10	1000/10,000	Nylon Cloth	White	7	25.40	12.70	27.94	16.94	218.44
DAT-18-502-1,-10	1000/10,000	Vinyl Cloth	White	7	25.40	12.70	27.94	16.94	218.44
DAT-18-502-1,-10-RF**	1000/10,000	Vinyl Cloth	White	7	25.40	12.70	27.94	16.94	218.44
DAT-19-607-1,-10	1000/10,000	Tamper-Resistant Vinyl	White	7	25.40	12.70	27.94	16.94	218.44
DAT-20-619-1,-10	1000/10,000	Polyester	White	7	25.40	12.70	27.94	16.94	218.44
DAT-47-693-1,-10	1000/10,000	Metallised Polyester	Silver	7	25.40	12.70	27.94	16.94	218.44
DAT-47-969-1,-10	1000/10,000	Metallised Polyester	Silver	7	25.40	12.70	27.94	16.94	218.44
DAT-57-637-1,-10	1000/10,000	Polyvinylfluoride	White	7	25.40	12.70	27.94	16.94	218.44
DAT-59-652-1,-10	1000/10,000	Polyimide	Amber	7	25.40	12.70	27.94	16.94	218.44
DAT-97-673-1,-10	1000/10,000	Polyester	White	7	25.40	12.70	27.94	16.94	218.44
DAT-99-637-1,-10	1000/10,000	Polyvinylfluoride	Yellow	7	25.40	12.70	27.94	16.94	218.44
DAT-163-621-1,-10	1000/10,000	Polyester	Clear	7	25.40	12.70	27.94	16.90	218.44
DAT-83-502-1,-10	1000/10,000	Vinyl Cloth	White	7	25.40	19.05	27.90	25.40	218.44
DAT-84-632-1,-10	1000/10,000	Polyvinylfluoride	White	7	25.40	19.05	27.90	25.40	218.44
25.40 mm Label Width - Square Corners									
DAT-149-502-1,-10	1000/10,000	Vinyl Cloth	White	8	25.40	23.80	25.40	25.40	228.60
DAT-150-632-1,-10	1000/10,000	Polyvinylfluoride	White	8	25.40	23.80	25.40	25.40	228.60
28.58 mm Label Width									
DAT-160-502-1,-10	1000/10,000	Vinyl Cloth	White	4	28.58	13.46	40.64	15.88	185.42
31.75 mm Label Width									
DAT-72-637-1,-10	1000/10,000	Polyvinylfluoride	Yellow	5	31.75	9.53	35.56	12.70	201.93
DAT-73-637-1,-10	1000/10,000	Polyvinylfluoride	White	5	31.75	9.53	35.56	12.70	201.93
DAT-74-637-1,-10	1000/10,000	Polyvinylfluoride	Grey	5	31.75	9.53	35.56	12.70	201.93
DAT-2-637*-1,-10	1000/10,000	Polyvinylfluoride	Yellow	7	31.75	9.53	35.56	12.70	273.05
DAT-10-637*-1,-10	1000/10,000	Polyvinylfluoride	White	7	31.75	9.53	35.56	12.70	273.05
DAT-23-637*-1,-10	1000/10,000	Polyvinylfluoride	Grey	7	31.75	9.53	35.56	12.70	273.05
DAT-182-502-1	1000	Vinyl Cloth	White	5	31.75	9.53	35.56	12.70	200.66
38.10 mm Label Width									
BCDAT-8-619-1,-5	1000/5,000	Polyester	White	4	38.10	6.35	40.64	9.53	185.42
BCDAT-8-652-1,-5	1000/5,000	Polyimide	Amber	4	38.10	6.35	40.64	9.53	185.42
DAT-G4-502-1,-10	1000/10,000	Vinyl Cloth	White	5	38.00	11.00	40.64	16.90	225.96



* Size does not fit narrow carriage (80-column) printers. See p. 153 for identical narrow carriage labels.

**RF : These parts are supplied on a 76.20 mm are for those applications requiring a roll form (RF) feed mechanism into the printer.

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

Labels Index by Size

CONTINUED

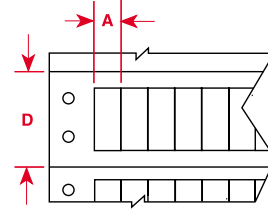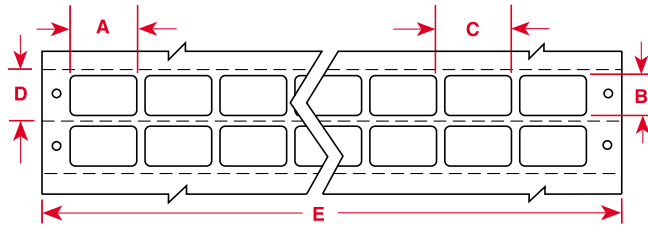


Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Vertical Repeat D mm	Web Width E mm
40.64 mm Label Width									
DAT-170-969-1,-10	1000/10,000	Polyester	Silver	4	40.64	9.53	43.18	12.70	195.58
50.80 mm Label Width									
BCDAT-9-619-1,-5	1000/5,000	Polyester	White	3	50.80	6.35	53.34	9.53	182.88
BCDAT-9-652-1,-5	1000/5,000	Polyimide	Amber	3	50.80	6.35	53.34	9.53	182.88
BCDAT-10-619-1,-10	1000/10,000	Polyester	White	3	50.80	9.53	53.34	12.70	182.88
DAT-64-502-1,-10	1000/10,000	Vinyl Cloth	White	3	50.80	9.53	53.34	12.70	182.88
DAT-12-502*-1,-10	1000/10,000	Vinyl Cloth	White	4	50.80	9.53	53.34	12.70	236.22
BCDAT-1-609-1,-5	1000/5,000	Litho Paper	White	3	50.80	22.86	53.34	25.40	182.88
BCDAT-1-619-1,-5	1000/5,000	Polyester	White	3	50.80	22.86	53.34	25.40	182.88
DAT-77-969-1,-5	1000/5,000	Metallised Polyester	Silver	3	50.80	22.86	53.34	25.40	182.88
BCDAT-3-609-1,-5	1000/5,000	Litho Paper	White	3	50.80	36.50	53.34	38.10	182.88
BCDAT-3-619-1,-5	1000/5,000	Polyester	White	3	50.80	36.50	53.34	38.10	182.88
DAT-79-969-1,-5	1000/5,000	Metallised Polyester	Silver	3	50.80	36.50	53.34	38.10	182.88
76.20 mm Label Width									
BCDAT-11-619-1,-10	1000/10,000	Polyester	White	2	76.20	9.53	78.74	12.70	180.34
DAT-13-502-1,-10	1000/10,000	Vinyl Cloth	White	2	76.20	9.53	78.74	12.70	180.34
BCDAT-2-619-1,-5	1000/5,000	Polyester	White	2	76.20	22.86	78.74	25.40	180.34
DAT-78-969-1,-5	1000/5,000	Metallised Polyester	Silver	2	76.20	22.86	78.74	25.40	180.34
BCDAT-4-609-1,-5	1000/5,000	Litho Paper	White	2	76.20	36.50	78.74	38.10	180.34
BCDAT-4-619-1,-5	1000/5,000	Polyester	White	2	76.20	36.50	78.74	38.10	180.34
DAT-80-969-1,-5	1000/5,000	Metallised Polyester	Silver	2	76.20	36.50	78.74	38.10	180.34
BCDAT-6-609-1,-5	1000/5,000	Litho Paper	White	2	76.20	48.26	78.74	50.80	180.34
BCDAT-6-619-1,-5	1000/5,000	Polyester	White	2	76.20	48.26	78.74	50.80	180.34
DAT-82-969-1,-5	1000/5,000	Metallised Polyester	Silver	2	76.20	48.26	78.74	50.80	180.34
99.06 mm Label Width									
BCDAT-5-609-1,-5	1000/5,000	Litho Paper	White	2	99.06	36.50	101.60	38.10	226.06
DAT-81-969-1,-5	1000/5,000	Metallised Polyester	Silver	2	99.06	36.50	101.60	38.10	226.06
106.60 mm Label Width									
DAT-180-609-1	1000	Litho Paper	White	2	101.60	50.80	104.14	55.12	231.14

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

Labels Index by Size

CONTINUED


► BUTT-CUT WITH PERFORATIONS Square Corners

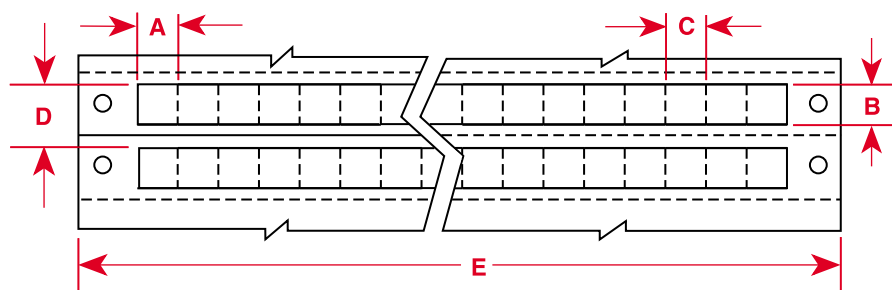

Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Vertical Repeat D mm	Web Width E mm
7.62 mm Label Width									
DAT-106-652-1,-10	1,000/10,000	Polyimide	Amber	16	7.62	7.62	7.62	12.70	147.32
DAT-107-658-1,-10	1,000/10,000	Polyimide	Amber	16	7.62	7.62	7.62	12.70	147.32
DAT-108-619-1,-10	1,000/10,000	Polyester	White	16	7.62	7.62	7.62	12.70	147.32
20.32 mm Label Width									
DAT-101-652-1,-10	1,000/10,000	Polyimide	Amber	10	20.32	5.08	20.32	8.46	228.60
DAT-102-619-1,-10	1,000/10,000	Polyester	White	10	20.32	5.08	20.32	8.46	228.60

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

► BUTT-CUT WITH PERFORATIONS Rounded Corners

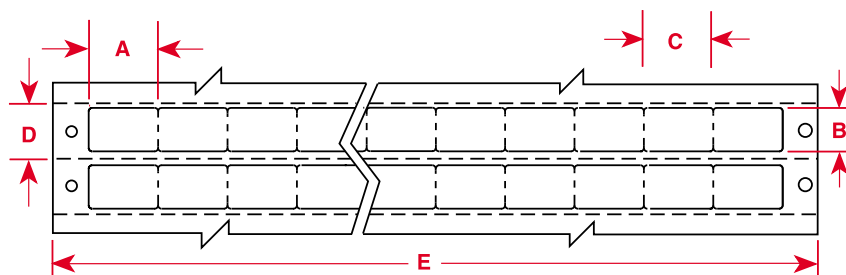


Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Vertical Repeat D mm	Web Width E mm
6.35 mm Label Width									
DAT-172-652-1,-10	1,000/10,000	Polyimide	Amber	20	6.35	6.35	6.35	12.70	152.40
DAT-173-619-1,-10	1,000/10,000	Polyester	White	20	6.35	6.35	6.35	12.70	152.40
20.32 mm Label Width									
DAT-103-652-1,-10	1,000/10,000	Polyimide	Amber	10	20.32	12.70	20.32	15.88	228.60
DAT-104-619-1,-10	1,000/10,000	Polyester	White	10	20.32	12.70	20.32	15.88	228.60
DAT-105-110-1,-10	1,000/10,000	Paper	White	10	20.32	12.70	20.32	15.88	228.60

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

Labels Index by Size

CONTINUED


► SLIT LINER for easy removal

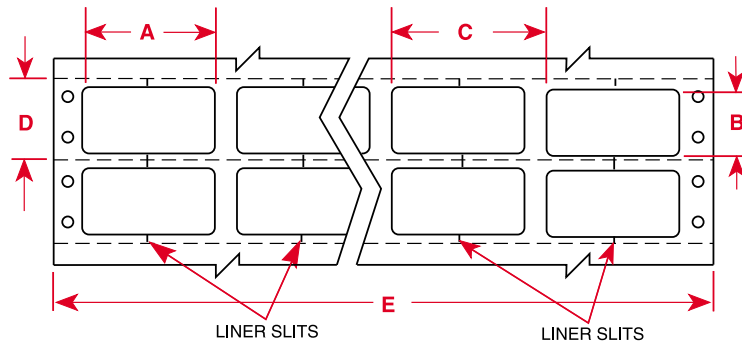

Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Vertical Repeat D mm	Web Width E mm
38.10 mm Label Width									
BCDAT-12-619-1,-10	1,000/10,000	Polyester	White	4	38.10	19.05	43.18	25.40	193.04
DAT-3-637-1,-10	1,000/10,000	Polyvinylfluoride	White	4	38.10	19.05	43.18	25.40	193.04
DAT-4-637-1,-10	1,000/10,000	Polyvinylfluoride	Yellow	4	38.10	19.05	43.18	25.40	193.04
DAT-48-693-1,-10	1,000/10,000	Metallised Polyester	Silver	4	38.10	19.05	43.18	25.40	193.04
DAT-48-969-1,-10	1,000/10,000	Metallised Polyester	Silver	4	38.10	19.05	43.18	25.40	193.04

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

► CENTRE PERFORATION (VERTICAL)

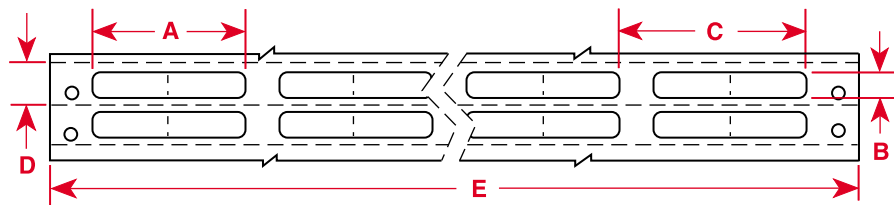


Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Vertical Repeat D mm	Web Width E mm
38.10 mm Label Width									
DAT-28-121-1,-10	1,000/10,000	Paper	White	4	38.10	6.35	45.72	8.46	200.66
DAT-29-499-1,-10	1,000/10,000	Nylon Cloth	White	4	38.10	6.35	45.72	8.46	200.66
DAT-29-502-1,-10	1,000/10,000	Vinyl Cloth	White	4	38.10	6.35	45.72	8.46	200.66

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

Labels Index by Size

CONTINUED


► CENTRE PERFORATIONS (HORIZONTAL)

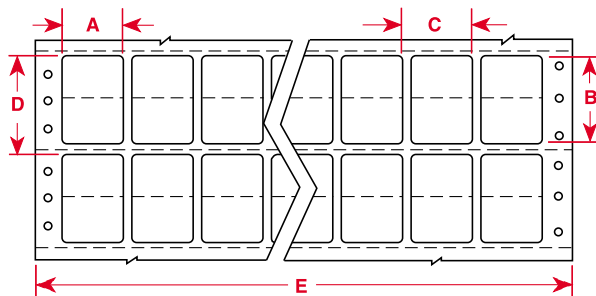

Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Vertical Repeat D mm	Web Width E mm
25.40 mm Label Width									
DAT-86-502-1,-10	1000/10,000	Vinyl Cloth	White	7	25.40	36.50	27.94	38.10	218.44
DAT-87-632-1,-10	1000/10,000	Polyvinylfluoride	White	7	25.40	36.50	27.94	38.10	218.44

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

► TAMPER-RESISTANT SLITS

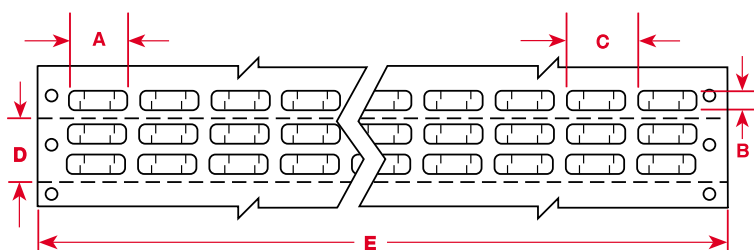

Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Vertical Repeat D mm	Web Width E mm
16.51 mm Label Width									
DAT-90-619-1,-10	1000/10,000	Polyester	White	10	16.51	5.08	20.32	6.35	224.80
DAT-91-652-1,-10	1000/10,000	Polyimide	Amber	10	16.51	5.08	20.32	6.35	224.80
19.05 mm Label Width									
DAT-92-619-1,-10	1000/10,000	Polyester	White	9	19.05	6.35	22.86	8.46	228.60
DAT-93-652-1,-10	1000/10,000	Polyimide	Amber	9	19.05	6.35	22.86	8.46	228.60


Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

Labels Index by Size

CONTINUED

HORIZONTAL SLIT


Wire marker with matching terminal block marker

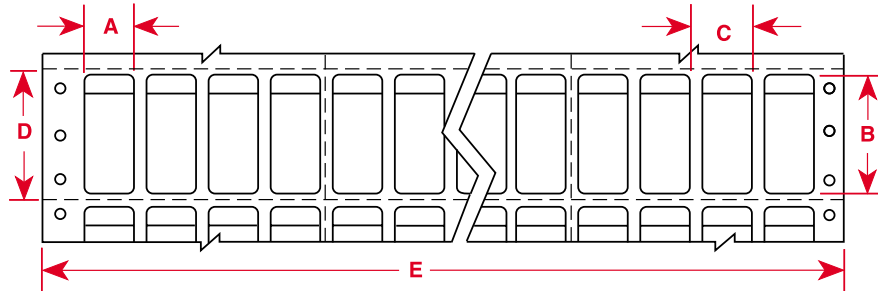

Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Vertical Repeat D mm	Web Width E mm
12.70 mm Label Width									
DAT-76-502-1-10	1,000/10,000	Vinyl Cloth	White	12	12.70	36.50	15.24	38.10	205.74

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

1.6 mm BLACK BORDER

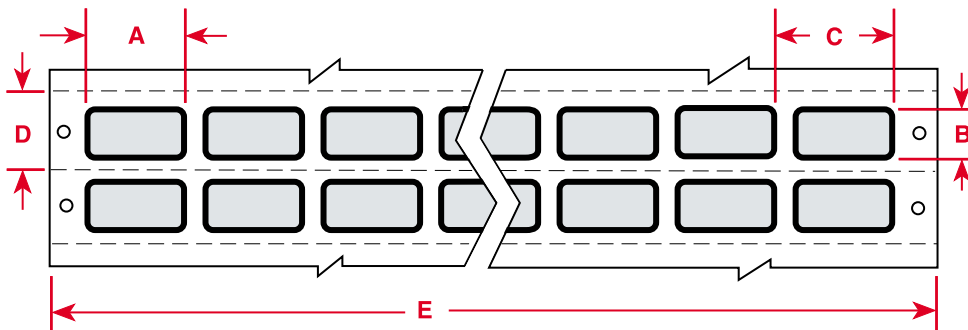


Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Vertical Repeat D mm	Web Width E mm
25.40 mm Label Width									
DAT-164-969-BK-1-10	1,000/10,000	Polyester	Silver	7	25.40	12.70	27.94	17.02	218.44
41.40 mm Label Width									
DAT-183-969-BK-1	1,000	Polyester	Silver	4	41.40	19.05	43.94	25.40	198.63
50.80 mm Label Width									
DAT-184-969-BK-1	1,000	Polyester	Silver	3	50.80	25.40	53.34	38.10	182.88

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

Labels Index by Size

CONTINUED


► STATIC AWARENESS LABELS for EPROM marking

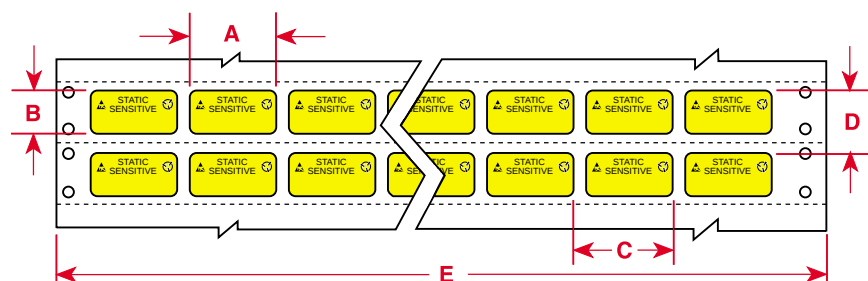

Reference	Pieces Per Package	Material	Print Colour	Printable Area mm	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Vertical Repeat D mm	Web Width E mm
25.40 mm Label Width									
SLDAT-1-502-1,-10	1,000/10,000	Vinyl Cloth	Black on Yellow	2540 x 792	2540	12.70	2794	1702	218.44
SLDAT-1-619-1,-10	1,000/10,000	Polyester	Black on Yellow/White	2540 x 792	2540	12.70	2794	1702	218.44

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

► PERMASHIELD™ MARKERS

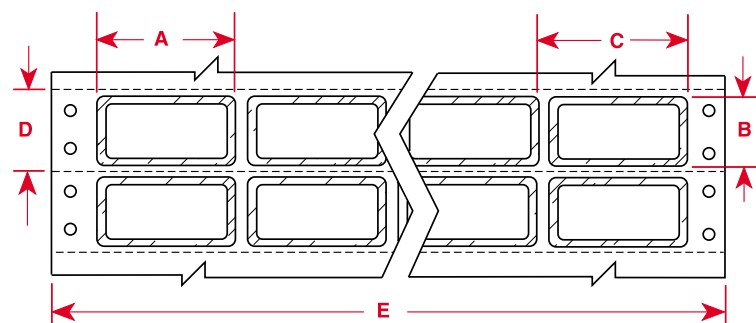


Clear polyester (B-966) overlamine extends 3.18 mm outside of label on each side.

Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Vertical Repeat D mm	Web Width E mm
25.40 mm Label Width									
PSL-1-609-1,-5	1,000/5,000	Paper	White	6	2540	12.70	35.56	25.40	234.95
PSL-1-619-1,-5	1,000/5,000	Polyester	White	6	2540	12.70	35.56	25.40	234.95
PSL-1-969-1,-5	1,000/5,000	Metallised Polyester	Silver	6	2540	12.70	35.56	25.40	234.95
38.10 mm Label Width									
PSL-2-609-1,-5	1,000/5,000	Paper	White	4	3810	19.05	48.26	38.10	214.63
PSL-2-619-1,-5	1,000/5,000	Polyester	White	4	3810	19.05	48.26	38.10	214.63
PSL-2-969-1,-5	1,000/5,000	Metallised Polyester	Silver	4	3810	19.05	48.26	38.10	214.63
50.80 mm Label Width									
PSL-3-609-1,-5	1,000/5,000	Paper	White	3	5080	25.40	60.96	38.10	204.47
PSL-3-619-1,-5	1,000/5,000	Polyester	White	3	5080	25.40	60.96	38.10	204.47
PSL-3-969-1,-5	1,000/5,000	Metallised Polyester	Silver	3	5080	25.40	60.96	38.10	204.47

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

Terminal Block Markers by Size


ONE-ACROSS

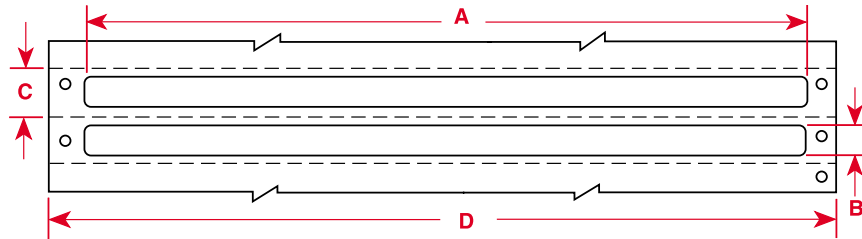

Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Vertical Repeat C mm	Web Width D mm
152.40 mm Label Width								
BCDAT-7-609-1,-2.5	1,000/2,500	Litho Paper	White	1	152.40	100.00	101.60	177.80
203.20 mm Label Width								
DAT-165-502-1,-2.5	1,000/2,500	Vinyl Cloth	White	1	203.20	714	12.70	228.60
DAT-166-502-1,-2.5	1,000/2,500	Vinyl Cloth	White	1	203.20	792	12.70	228.60
DAT-167-502-1,-2.5	1,000/2,500	Vinyl Cloth	White	1	203.20	9.53	12.70	228.60

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

CONTINUOUS STRIP/ONE-ACROSS

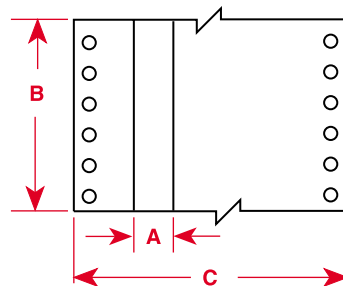


Reference	Meters Per Package	Material	Colour	Strips Per Row	Label Width A mm	Label Height B mm	Web Width C mm
714 mm Label Width							
DAT-156-502-2	50.80 m	Vinyl Cloth	White	1	714	Continuous	88.90
7.92 mm Label Width							
DAT-157-502-2	50.80 m	Vinyl Cloth	White	1	7.92	Continuous	88.90
9.53 mm Label Width							
DAT-158-502-2	50.80 m	Vinyl Cloth	White	1	9.53	Continuous	88.90

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

Terminal Block Markers by Size

CONTINUED


► CONTINUOUS STRIP/MULTIPLE ACROSS

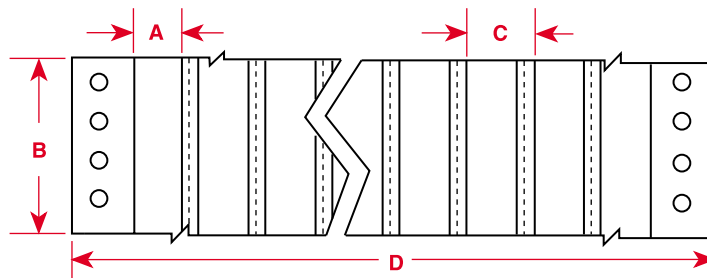

Reference	Meters Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Web Width D mm
7.92 mm Label Width								
DAT-153-502-2,-7	50.80/177.80m	Vinyl Cloth	White	10	7.92	Continuous	12.70	127.00
9.53 mm Label Width								
DAT-100-502-2,-7	50.80/177.80m	Vinyl Cloth	White	8	9.53	Continuous	12.70	127.00

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

► CONTINUOUS STRIP/PERFORATED

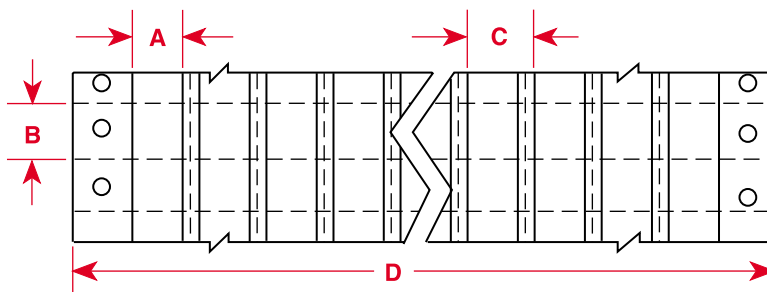


Reference	Meters Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Web Width D mm
7.14 mm Label Width								
DAT-152-502-2,-7	50.80/177.80m	Vinyl Cloth	White	10	7.14	6.35	10.16	127.00
7.92 mm Label Width								
DAT-154-502-2,-7	50.80/177.80m	Vinyl Cloth	White	10	7.92	9.53	10.16	127.00
DAT-155-502-2,-7	50.80/177.80m	Vinyl Cloth	White	10	7.92	12.70	12.70	127.00
9.53 mm Label Width								
DAT-168-619-2	50.80m	Polyester	White	1	9.53	5.08	NA	88.90

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

Terminal Block Markers by Size

CONTINUED


► BUTT-CUT TRANSLUCENT

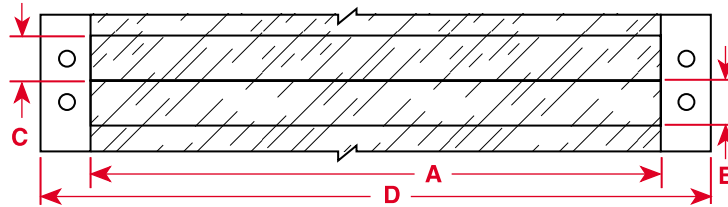

Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Vertical Repeat C mm	Web Width D mm
190.50 mm Label Width								
DAT-169-621-1,-2.5	1,000/2,500	Polyester	Clear	1	190.50	12.70	12.70	218.95

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

► PREPRINTED/PERFORATED

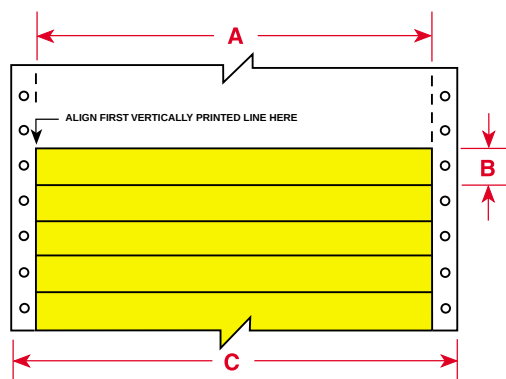


Reference	Pieces Per Package	Material	Colour	Strips Per Row	Strip Width A mm	Strip Height B mm	Web Width C mm
200.66 mm Label Width							
DAT-177-124-BL**	150	Paper	Blue	1	200.66	12.07	225.43
DAT-177-124-BR**	150	Paper	Brown	1	200.66	12.07	225.43
DAT-177-124-GR**	150	Paper	Green	1	200.66	12.07	225.43
DAT-177-124-GY**	150	Paper	Grey	1	200.66	12.07	225.43
DAT-177-124-OR**	150	Paper	Orange	1	200.66	12.07	225.43
DAT-177-124-PL**	150	Paper	Purple	1	200.66	12.07	225.43
DAT-177-124-RD**	150	Paper	Red	1	200.66	12.07	225.43
DAT-177-124-WT**	150	Paper	White	1	200.66	12.07	225.43
DAT-177-124-YL**	150	Paper	Yellow	1	200.66	12.07	225.43

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

****Also available in:** OR=orange, GN=green, GY=grey, PL=purple, BL=blue, BR=brown, YL=yellow, RD=red.
To order a colour, add a dash "-" after the reference, then add the colour suffix.

Self-Laminating Wire and Cable Markers by Size

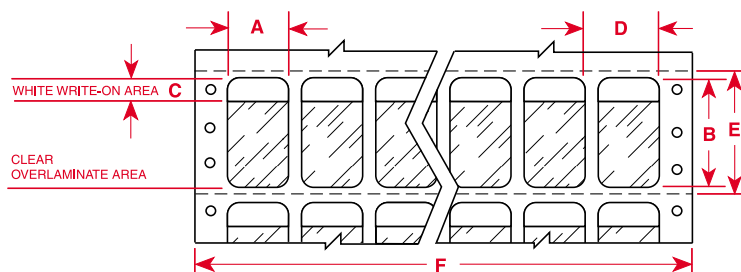

Reference	Pieces Per Package	Material	Labels Per Row	Label Width A mm	Label Height B mm	Write-On Height C mm	Horizontal Repeat D mm	Vertical Repeat E mm	Web Width F mm	Max Cable Diameter mm
12.70 mm Label Width										
DAT-30-292*-1,-10	1,000/10,000	Vinyl	14	12.70	19.05	9.53	15.24	25.40	236.22	3
DAT-66-292-1,-10	1,000/10,000	Vinyl	12	12.70	19.05	9.53	15.24	25.40	205.74	3
DAT-71-642-1,-10	1,000/10,000	Polyvinylfluoride	12	12.70	19.05	9.53	15.24	25.40	205.74	3
DAT-55-642*-1,-10	1,000/10,000	Polyvinylfluoride	14	12.70	19.05	9.53	15.24	25.40	236.22	3
19.05 mm Label Width										
DAT-36-292-1,-10	1,000/10,000	Vinyl	9	19.05	44.45	12.70	22.86	50.80	228.60	10
20.32 mm Label Width										
DAT-7-292-1,-10	1,000/10,000	Vinyl	6	20.32	36.50	12.70	22.86	38.10	160.00	7
DAT-52-642-1,-10	1,000/10,000	Polyvinylfluoride	6	20.32	36.50	12.70	22.86	38.10	160.00	7
25.40 mm Label Width										
DAT-185-292-1,-2.5	1,000/2,500	Vinyl	7	25.40	63.50	19.05	27.94	76.20	218.44	14
DAT-187-292-1,-2.5	1,000/2,500	Vinyl	7	25.40	101.60	25.40	27.94	114.30	218.44	24
DAT-41-292*-1,-2.5	1,000/2,500	Vinyl	8	25.40	150.80	38.10	27.94	152.40	241.30	35
DAT-69-292-1,-2.5	1,000/2,500	Vinyl	7	25.40	150.80	38.10	27.94	152.40	213.36	35
DAT-69-292-OR**	2,500	Vinyl	7	25.40	150.80	38.10	27.94	152.40	213.36	35
DAT-69-292-GR**	2,500	Vinyl	7	25.40	150.80	38.10	27.94	152.40	213.36	35
DAT-69-292-PL**	2,500	Vinyl	7	25.40	150.80	38.10	27.94	152.40	213.36	35
DAT-69-292-BL**	2,500	Vinyl	7	25.40	150.80	38.10	27.94	152.40	213.36	35
DAT-69-292-BR**	2,500	Vinyl	7	25.40	150.80	38.10	27.94	152.40	213.36	35
DAT-69-292-YL**	2,500	Vinyl	7	25.40	150.80	38.10	27.94	152.40	213.36	35
DAT-69-292-RD**	2,500	Vinyl	7	25.40	150.80	38.10	27.94	152.40	213.36	35
DAT-69-292-GY**	2,500	Vinyl	7	25.40	150.80	38.10	27.94	152.40	213.36	35
DAT-42-292*-1,-2.5	1,000/2,500	Vinyl	8	25.40	188.90	38.10	27.94	190.50	241.30	48
DAT-70-292-1,-2.5	1,000/2,500	Vinyl	7	25.40	188.90	38.10	27.94	190.50	213.36	48
38.10 mm Label Width										
DAT-186-292-1,-2.5	1,000/2,500	Vinyl	4	38.10	63.50	19.05	40.64	76.20	185.42	14
DAT-188-292-1,-2.5	1,000/2,500	Vinyl	4	38.10	101.60	25.40	40.64	114.30	185.42	24
48.26 mm Label Width										
DAT-8-292*-1,-2.5	1,000/2,500	Vinyl	4	48.26	80.95	19.05	50.80	88.90	241.30	19
DAT-63-292-1,-2.5	1,000/2,500	Vinyl	3	48.26	80.95	19.05	50.80	88.90	190.50	19


*Size does not fit narrow carriage (80-column) printers. See p.153 for identical narrow carriage labels.

**OR=orange, GR=green, GY=grey, PL=purple, BL=blue, BR=brown, YL=yellow, RD=red.

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

Self-Laminating Wire and Cable Markers by Size

CONTINUED

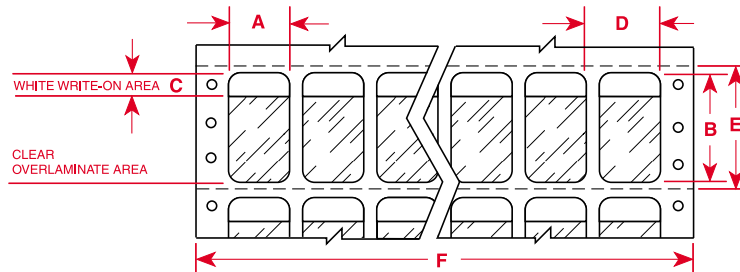

Reference	Pieces Per Package	Material	Labels Per Row	Label Width A mm	Label Height B mm	Write-On Height C mm	Horizontal Repeat D mm	Vertical Repeat E mm	Web Width F mm	Max Cable Diameter mm
50.80 mm Label Width										
DAT-9-292*-1,-2.5	1000/2,500	Vinyl	6	50.80	150.80	38.10	53.34	152.40	342.90	35
DAT-75-292-1,-2.5	1000/2,500	Vinyl	3	50.80	150.80	38.10	53.34	152.40	177.80	35
DAT-75-292-OR**	2,500	Vinyl	3	50.80	150.80	38.10	53.34	152.40	177.80	35
DAT-75-292-GR**	2,500	Vinyl	3	50.80	150.80	38.10	53.34	152.40	177.80	35
DAT-75-292-PL**	2,500	Vinyl	3	50.80	150.80	38.10	53.34	152.40	177.80	35
DAT-75-292-BL**	2,500	Vinyl	3	50.80	150.80	38.10	53.34	152.40	177.80	35
DAT-75-292-BR**	2,500	Vinyl	3	50.80	150.80	38.10	53.34	152.40	177.80	35
DAT-75-292-YL**	2,500	Vinyl	3	50.80	150.80	38.10	53.34	152.40	177.80	35
DAT-75-292-RD**	2,500	Vinyl	3	50.80	150.80	38.10	53.34	152.40	177.80	35
DAT-75-292-GY**	2,500	Vinyl	3	50.80	150.80	38.10	53.34	152.40	177.80	35
DAT-14-292*-1,-2.5	1000/2,500	Vinyl	4	50.80	188.90	38.10	55.88	190.50	238.76	48
DAT-65-292-1,-2.5	1000/2,500	Vinyl	3	50.80	188.90	38.10	53.34	190.50	182.88	48
DAT-159-292-1,-2.5	1000/2,500	Vinyl	3	50.80	214.30	38.10	53.34	215.90	182.88	56
DAT-159-292-OR**	2,500	Vinyl	3	50.80	214.30	38.10	53.34	215.90	182.88	56
DAT-159-292-GR**	2,500	Vinyl	3	50.80	214.30	38.10	53.34	215.90	182.88	56
DAT-159-292-PL**	2,500	Vinyl	3	50.80	214.30	38.10	53.34	215.90	182.88	56
DAT-159-292-BL**	2,500	Vinyl	3	50.80	214.30	38.10	53.34	215.90	182.88	56
DAT-159-292-BR**	2,500	Vinyl	3	50.80	214.30	38.10	53.34	215.90	182.88	56
DAT-159-292-YL**	2,500	Vinyl	3	50.80	214.30	38.10	53.34	215.90	182.88	56
DAT-159-292-RD**	2,500	Vinyl	3	50.80	214.30	38.10	53.34	215.90	182.88	56
DAT-159-292-GY**	2,500	Vinyl	3	50.80	214.30	38.10	53.34	215.90	182.88	56

*Wide Web. Will not fit narrow carriage (80-column printers). See p. 153 for identical narrow carriage labels.


**OR=orange, GR=green, GY=grey, PL=purple, BL=blue, BR=brown, YL=yellow, RD=red.

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

Self-Laminating Wire and Cable Markers by Size

CONTINUED

BUTT-CUT

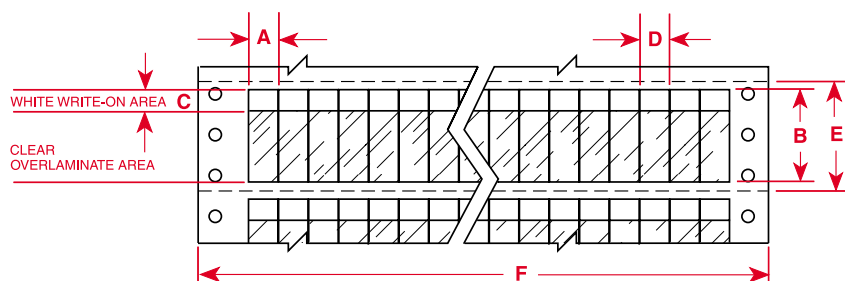

Reference	Pieces Per Package	Material	Labels Per Row	Label Width A mm	Label Height B mm	Write-On Height C mm	Horizontal Repeat D mm	Vertical Repeat E mm	Web Width F mm	Max Cable Diameter mm
7.62 mm Label Width										
DAT-139-292-1,-10	1,000/10,000	Vinyl	16	7.62	19.05	9.53	7.62	25.40	147.32	3
DAT-142-292-1,-10	1,000/10,000	Vinyl	16	7.62	23.80	9.53	7.62	25.40	147.32	4
12.70 mm Label Width										
DAT-145-292-1,-10	1,000/10,000	Vinyl	16	12.70	23.80	9.53	12.70	25.40	228.60	4
DAT-33-292-1,-10	1,000/10,000	Vinyl	16	12.70	36.50	12.70	12.70	38.10	228.60	7
DAT-53-642-1,-10	1,000/10,000	Polyvinylfluoride	16	12.70	36.50	12.70	12.70	38.10	228.60	7
SLSH-0515	1,664	Vinyl	16	12.70	36.50	12.70	12.70	38.10	228.60	7
20.32 mm Label Width										
DAT-148-292-1,-10	1,000/10,000	Vinyl	10	20.32	23.80	9.53	20.32	25.40	228.60	4
25.40 mm Label Width										
DAT-85-292-1,-10	1,000/10,000	Vinyl	8	25.40	19.05	9.53	25.40	25.40	228.60	3
DAT-85-292-OR**	2,500	Vinyl	8	25.40	19.05	9.53	25.40	25.40	228.60	3
DAT-85-292-GR**	2,500	Vinyl	8	25.40	19.05	9.53	25.40	25.40	228.60	3
DAT-85-292-PL**	2,500	Vinyl	8	25.40	19.05	9.53	25.40	25.40	228.60	3
DAT-85-292-BL**	2,500	Vinyl	8	25.40	19.05	9.53	25.40	25.40	228.60	3
DAT-85-292-BR**	2,500	Vinyl	8	25.40	19.05	9.53	25.40	25.40	228.60	3
DAT-85-292-YL**	2,500	Vinyl	8	25.40	19.05	9.53	25.40	25.40	228.60	3
DAT-85-292-RD**	2,500	Vinyl	8	25.40	19.05	9.53	25.40	25.40	228.60	3
DAT-85-292-GY**	2,500	Vinyl	8	25.40	19.05	9.53	25.40	25.40	228.60	3
DAT-151-292-1,-10	1,000/10,000	Vinyl	8	25.40	23.80	9.53	25.40	25.40	228.60	4
DAT-34-292-1,-10	1,000/10,000	Vinyl	8	25.40	36.50	12.70	25.40	38.10	228.60	7
DAT-34-292-OR**	2,500	Vinyl	8	25.40	36.50	12.70	25.40	38.10	228.60	7
DAT-34-292-GR**	2,500	Vinyl	8	25.40	36.50	12.70	25.40	38.10	228.60	7
DAT-34-292-PL**	2,500	Vinyl	8	25.40	36.50	12.70	25.40	38.10	228.60	7
DAT-34-292-BL**	2,500	Vinyl	8	25.40	36.50	12.70	25.40	38.10	228.60	7
DAT-34-292-BR**	2,500	Vinyl	8	25.40	36.50	12.70	25.40	38.10	228.60	7
DAT-34-292-YL**	2,500	Vinyl	8	25.40	36.50	12.70	25.40	38.10	228.60	7
DAT-34-292-RD**	2,500	Vinyl	8	25.40	36.50	12.70	25.40	38.10	228.60	7
DAT-34-292-GY**	2,500	Vinyl	8	25.40	36.50	12.70	25.40	38.10	228.60	7
DAT-54-642-1,-10	1,000/10,000	Polyvinylfluoride	8	25.40	36.50	12.70	25.40	38.10	228.60	7
SLSH-1015	832	Vinyl	8	25.40	36.50	12.70	25.40	38.10	228.60	7
DAT-37-292-1,-10	1,000/10,000	Vinyl	8	25.40	57.15	19.05	25.40	63.50	228.60	12
DAT-37-292-OR**	2,500	Vinyl	8	25.40	57.15	19.05	25.40	63.50	228.60	12
DAT-37-292-GR**	2,500	Vinyl	8	25.40	57.15	19.05	25.40	63.50	228.60	12
DAT-37-292-PL**	2,500	Vinyl	8	25.40	57.15	19.05	25.40	63.50	228.60	12
DAT-37-292-BL**	2,500	Vinyl	8	25.40	57.15	19.05	25.40	63.50	228.60	12
DAT-37-292-BR**	2,500	Vinyl	8	25.40	57.15	19.05	25.40	63.50	228.60	12
DAT-37-292-YL**	2,500	Vinyl	8	25.40	57.15	19.05	25.40	63.50	228.60	12
DAT-37-292-RD**	2,500	Vinyl	8	25.40	57.15	19.05	25.40	63.50	228.60	12
DAT-37-292-GY**	2,500	Vinyl	8	25.40	57.15	19.05	25.40	63.50	228.60	12
SLSH-10225	608	Vinyl	8	25.40	57.15	19.05	25.40	63.50	228.60	12


**OR=orange, GR=green, GY=grey, PL=purple, BL=blue, BR=brown, YL=yellow, RD=red.

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

Self-Laminating Wire and Cable Markers by Size

CONTINUED

BUTT-CUT CONTINUED

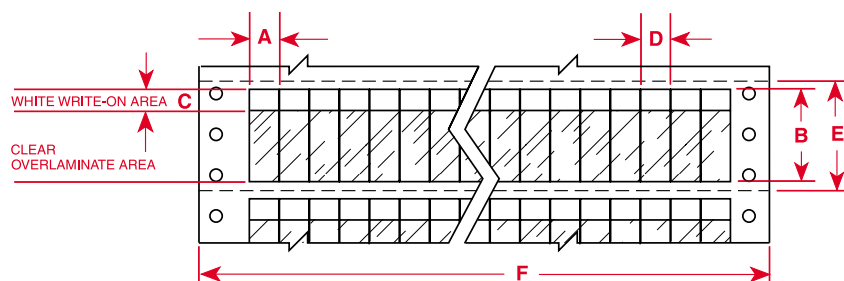

Reference	Pieces Per Package	Material	Labels Per Row	Label Width A mm	Label Height B mm	Write-On Height C mm	Horizontal Repeat D mm	Vertical Repeat E mm	Web Width F mm	Max Cable Diameter mm
25.40 mm Label Width										
DAT-39-292-1,-2.5	1000/2,500	Vinyl	8	25.40	95.25	25.40	25.40	101.60	228.60	22
DAT-39-292-OR**	2,500	Vinyl	8	25.40	95.25	25.40	25.40	101.60	228.60	22
DAT-39-292-GR**	2,500	Vinyl	8	25.40	95.25	25.40	25.40	101.60	228.60	22
DAT-39-292-PL**	2,500	Vinyl	8	25.40	95.25	25.40	25.40	101.60	228.60	22
DAT-39-292-BL**	2,500	Vinyl	8	25.40	95.25	25.40	25.40	101.60	228.60	22
DAT-39-292-BR**	2,500	Vinyl	8	25.40	95.25	25.40	25.40	101.60	228.60	22
DAT-39-292-YL**	2,500	Vinyl	8	25.40	95.25	25.40	25.40	101.60	228.60	22
DAT-39-292-RD**	2,500	Vinyl	8	25.40	95.25	25.40	25.40	101.60	228.60	22
DAT-39-292-GY**	2,500	Vinyl	8	25.40	95.25	25.40	25.40	101.60	228.60	22
SLSH-10375	408	Vinyl	8	25.40	95.25	25.40	25.40	101.60	228.60	22
50.80 mm Label Width										
DAT-35-292-1,-10	1000/10,000	Vinyl	4	50.80	36.50	12.70	50.80	38.10	228.60	7
SLSH-2015	416	Vinyl	4	50.80	36.50	12.70	50.80	38.10	228.60	7
DAT-38-292-1,-2.5	1000/2,500	Vinyl	4	50.80	57.15	19.05	50.80	63.50	228.60	12
DAT-38-292-OR**	2,500	Vinyl	4	50.80	57.15	19.05	50.80	63.50	228.60	12
DAT-38-292-GR**	2,500	Vinyl	4	50.80	57.15	19.05	50.80	63.50	228.60	12
DAT-38-292-PL**	2,500	Vinyl	4	50.80	57.15	19.05	50.80	63.50	228.60	12
DAT-38-292-BL**	2,500	Vinyl	4	50.80	57.15	19.05	50.80	63.50	228.60	12
DAT-38-292-BR**	2,500	Vinyl	4	50.80	57.15	19.05	50.80	63.50	228.60	12
DAT-38-292-YL**	2,500	Vinyl	4	50.80	57.15	19.05	50.80	63.50	228.60	12
DAT-38-292-RD**	2,500	Vinyl	4	50.80	57.15	19.05	50.80	63.50	228.60	12
DAT-38-292-GY**	2,500	Vinyl	4	50.80	57.15	19.05	50.80	63.50	228.60	12
SLSH-20225	304	Vinyl	4	50.80	57.15	19.05	50.80	63.50	228.60	12
DAT-40-292-1,-2.5	1000/2,500	Vinyl	4	50.80	95.25	25.40	50.80	101.60	228.60	22
DAT-40-292-OR**	2,500	Vinyl	4	50.80	95.25	25.40	50.80	101.60	228.60	22
DAT-40-292-GR**	2,500	Vinyl	4	50.80	95.25	25.40	50.80	101.60	228.60	22
DAT-40-292-PL**	2,500	Vinyl	4	50.80	95.25	25.40	50.80	101.60	228.60	22
DAT-40-292-BL**	2,500	Vinyl	4	50.80	95.25	25.40	50.80	101.60	228.60	22
DAT-40-292-BR**	2,500	Vinyl	4	50.80	95.25	25.40	50.80	101.60	228.60	22
DAT-40-292-YL**	2,500	Vinyl	4	50.80	95.25	25.40	50.80	101.60	228.60	22
DAT-40-292-RD**	2,500	Vinyl	4	50.80	95.25	25.40	50.80	101.60	228.60	22
DAT-40-292-GY**	2,500	Vinyl	4	50.80	95.25	25.40	50.80	101.60	228.60	22
SLSH-20375	204	Vinyl	4	50.80	95.25	25.40	50.80	101.60	228.60	22


**OR=orange, GR=green, GY=grey, PL=purple, BL=blue, BR=brown, YL=yellow, RD=red.

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

Self-Laminating Wire and Cable Markers by Size

CONTINUED

CABLE MARKERS

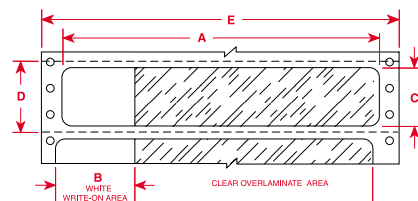


Reference	Pieces Per Package	Material	Labels Per Row	Label Width A mm	Write-On Height B mm	Label Height C mm	Vertical Repeat D mm	Web Width E mm	Max. Cable Diameter mm
215.90 mm Label Width									
DAT-162-292-1-2.5	1000/2,500	Vinyl	1	50.80	215.90	38.10	63.50	241.30	56

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

Cable Markers by Size

BRADYWRAP™ Continuous strip/cut-to-length

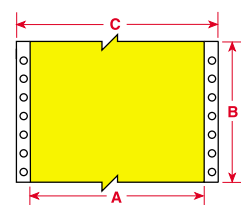


Reference	Roll Length m	Material	Colour	Label Width A mm	Label Height B mm	Web Width C mm	Maximum Characters Across		
							5 CPI	10 CPI	17 CPI
25.40 mm Label Width									
RCM-637-10-WT	30.5	Tedlar®	White	25.40	Continuous	91.44	4	9	15
RCM-637-10-YL	30.5	Tedlar®	Yellow	25.40	Continuous	91.44	4	9	15
38.10 mm Label Width									
RCM-637-15-WT	30.5	Tedlar®	White	38.10	Continuous	91.44	7	14	23
RCM-637-15-YL	30.5	Tedlar®	Yellow	38.10	Continuous	91.44	7	14	23
50.80 mm Label Width									
RCM-330-2.0-WT	30.5	Polyolefin	White	50.80	Continuous	91.44	9	19	32
RCM-330-2.0-YL	30.5	Polyolefin	Yellow	50.80	Continuous	91.44	9	19	32
RCM-637-2.0-WT	30.5	Tedlar®	White	50.80	Continuous	91.44	9	19	32
RCM-637-2.0-YL	30.5	Tedlar®	Yellow	50.80	Continuous	91.44	9	19	32

Tedlar® is a registered trademark of DuPont.

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

CLOTH TAGS Cable and wire harness markers

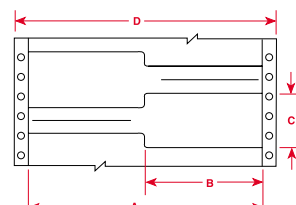


Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Width of Write-On Area B mm	Label Height C mm	Web Width D mm
114.30 mm Label Width (5715 mm tab area)								
CT-1	1,800	Self-Extinguishing Cloth	White	2	114.30	5715	25.40	139.70

Note: Labels are sorted in order by width, height, 3 digit material number (within reference).

BRADYTAG™ Labels by Size


► COMPUTER-PRINTABLE TAGS

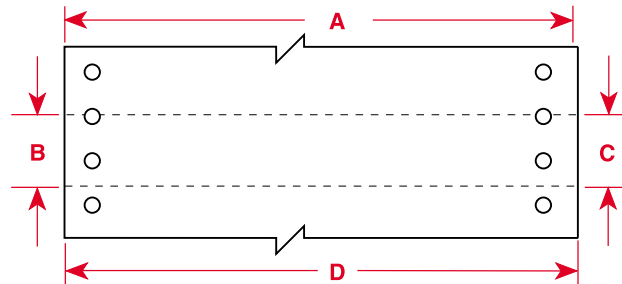

Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Vertical Repeat C mm	Web Width D mm
76.20 mm Label Width								
BT-0530	500	Matt Polyester	White	1	76.20	12.70	12.70	76.20
BT-1030	500	Matt Polyester	White	1	76.20	25.40	25.40	76.20
BT-109W-3060-1	100	Polyethylene	White	1	76.20	152.40	152.40	101.60
95.25 mm Label Width								
BT-109W-2037	100	Polyethylene	White	1	95.25	50.80	50.80	120.65
120.65 mm Label Width								
BT-109W-2547	100	Polyethylene	White	1	120.65	63.50	63.50	146.05

Note: Labels are sorted in order by width, height, 3 digit material number (within Reference).

► NOMEX® CABLE AND HARNESS MARKING

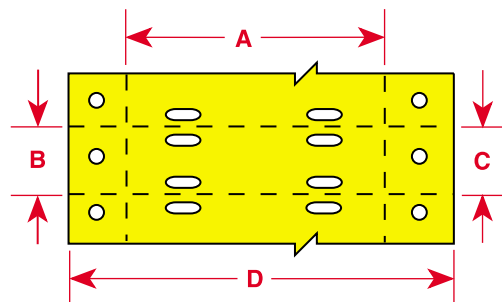

Reference	Pieces Per Package	Material	Colour	Labels Per Row	Holes Per Tag	Label Width A mm	Label Height B mm	Vertical Repeat C mm	Web Width D mm
50.80 mm Label Width									
BT-508W-2050	2,500	Nomex®	White	1	4	50.80	12.70	12.70	76.20
BT-508Y-2050	2,500	Nomex®	Yellow	1	4	50.80	12.70	12.70	76.20
BT-508W-2075	2,500	Nomex®	White	1	6	50.80	19.05	19.05	76.20
BT-508Y-2075	2,500	Nomex®	Yellow	1	6	50.80	19.05	19.05	76.20

Nomex® is a registered trademark of DuPont.

Note: Labels are sorted in order by width, height, 3 digit material number (within Reference).