

Wire Marker Cards

PRE-PRINTED
WIRE MARKERS




PART NUMBER EXPLANATION:


Most Brady part numbers in this section follow the same two-part format:

The first code indicates the Brady product being referenced, the second code indicates the marker legend.

Numbers

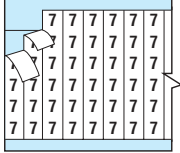


Higher Numbers

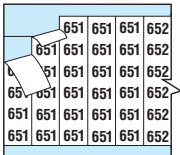

Mounted in groups of five identical groups per card.


LEGEND		B-500	B-702	B-605	B-184	B-12	Markers per Card	
		Vinyl Cloth	Vinyl Film	Over-Laminated	Aluminum Foil	Acetate Cloth	1.500" (38.10 mm)	0.750" (19.05 mm)
	0	WM-0	TWM-0	OLWM-0	AF-0	HH-0	36	72
	1	WM-1	TWM-1	OLWM-1	AF-1	HH-1	36	72
	2	WM-2	TWM-2	OLWM-2	AF-2	HH-2	36	72
	and so on thru	and so on thru	and so on thru	and so on thru	and so on thru	and so on thru		
	25	WM-25	TWM-25	OLWM-25	AF-25	HH-25	36	72
	26	WM-26	TWM-26	OLWM-26	AF-26		36	72
	and so on thru	and so on thru	and so on thru	and so on thru	and so on thru		36	72
		WM-99	TWM-99	OLWM-99	AF-50		25	50
	601 - 605	WM-601-605					25	50
	606 - 610	WM-606-610					25	50
	611 - 615	WM-611-615					25	50
	and so on thru	and so on thru						
	921 - 925	WM-921-925						

Consecutive Numbers

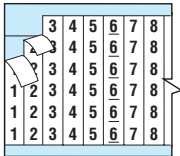

LEGEND		B-500	B-702	B-605	B-184	B-12	Quantity Each		Markers per Card	
		Vinyl Cloth	Vinyl Film	Over-Laminated	Aluminum Foil	Acetate Cloth	1.500" (38.10 mm)	0.750" (19.05 mm)	1.500" (38.10 mm)	0.750" (19.05 mm)
	1-33	WM-1-33	TWM-1-33	OLWM-1-33	AF-1-33	HH-1-33	1	2	33	66
	34-66	WM-34-66	TWM-34-66	OLWM-34-66	AF-34-66	HH-34-66	1	2	33	66
	67-99	WM-67-99	TWM-67-99	OLWM-67-99	AF-67-99	HH-67-99	1	2	33	66
	100-124	WM-100-124	TWM-100-124	OLWM-100-124	AF-100-124		1	2	25	50
	125-149	WM-125-149	TWM-125-149	OLWM-125-149	AF-125-149		1	2	25	50
	and so on thru	and so on thru	and so on thru	and so on thru	and so on thru					
		WM-1775-1799	TWM-375-399	OLWM-250-274	AF-250-274		1	2	25	50

 Consecutive Numbers Repeated




LEGEND		B-500	B-702	B-605	B-184	Sequences per Card		Markers per Card	
		Vinyl Cloth	Vinyl Film	Over-Laminated	Aluminum Foil	1.500" (38.10 mm)	0.750" (19.05 mm)	1.500" (38.10 mm)	0.750" (19.05 mm)
	1-3	WM-1-3	TWM-1-3		AF-1-3	12	24	36	72
	1-4	WM-1-4			AF-1-4	9	18	36	72
	1-5	WM-1-5				7	14	35	70
	1-6	WM-1-6				6	12	36	72
	1-8	WM-1-8				4	8	32	64
	1-9	WM-1-9			AF-1-9	4	8	36	72
	0-9	WM-0-9	TWM-0-9			3	6	30	60
	0-10	WM-0-10				3	6	33	66
	1-10	WM-1-10	TWM-1-10	OLWM-1-10	AF-1-10	3	6	30	60
	1-12	WM-1-12	TWM-1-12	OLWM-1-12	AF-1-12	3	6	36	72
	1-16	WM-1-16	TWM-1-16	OLWM-1-16	AF-1-16	2	4	32	64
	1-18	WM-1-18	TWM-1-18	OLWM-1-18	AF-1-18	2	4	36	64
	19-36	WM-19-36	TWM-19-36			2	4	36	72

NUMBERS
WIRE MARKER CARDS


Wire Marker Cards

CONTINUED


Letters — Upper Case

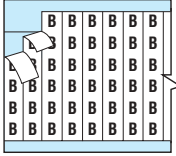


Lower Case

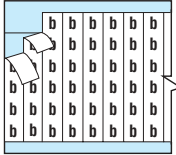


Consecutive Letters

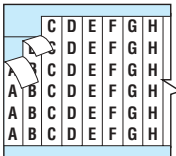

Consecutive Letters Repeated

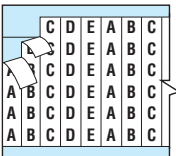

Terminal Markers

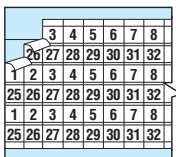

		B-500	B-702	B-605	B-184	B-12	Markers per Card	
		Vinyl Cloth	Vinyl Film	Over-Laminated	Aluminum Foil	Acetate Cloth	1.500" (38.10 mm)	0.750" (19.05 mm)
LEGEND	A	WM-A	TWM-A	OLWM-A	AF-A	HH-A	36	72
	B	WM-B	TWM-B	OLWM-B	AF-B	HH-B	36	72
	C	WM-C	TWM-C	OLWM-C	AF-C	HH-C	36	72
	and so on thru	and so on thru	and so on thru	and so on thru	and so on thru	and so on thru		
	Z	WM-Z	TWM-Z	OLWM-Z	AF-Z	HH-Z	36	72
	a	WM-A-SML					36	72
	b	WM-B-SML					36	72
	c	WM-C-SML					36	72
	and so on thru	and so on thru						
	z	WM-Z-SML					36	72
	A-Z	WM-A-Z	TWM-A-Z	OLWM-A-Z	AF-A-Z		26	52
	A-Z plus A-J	WM-A-Z, AJ					36	72
a-z	WM-A-Z-SML	TWM-A-Z-SML				26	52	

		B-500	B-702	Sequences Per Card		Markers per Card	
		Vinyl Cloth	Vinyl Film	1.500" (38.10 mm)	0.750" (19.05 mm)	1.500" (38.10 mm)	0.750" (19.05 mm)
LEGEND	A - E	WM-A-E	TWM-A-E	7	14	35	70
	F - J	WM-F-J	TWM-F-J	7	14	35	70
	K - O	WM-K-O	TWM-K-O	7	14	35	70
	P - T	WM-P-T	TWM-P-T	7	14	35	70
	U - Z	WM-U-Z	TWM-U-Z	7	14	35	70

Vinyl Cloth (B-500)			Markers per Card	
	Part Number		0.312" x 0.187" (8.00 mm x 5.00 mm)	
LEGEND	1 - 48	WM-1-48-TM	144	
	49 - 96	WM-49-96-TM	144	
	A - Z*	WM-A-Z-TM	144	

*Terminal Markers have no "I" or "O"


PRE-PRINTED WIRE MARKERS

WIRE MARKER CARDS LETTERS / TERMINAL MARKERS

Wire Marker Cards

CONTINUED

Letters and Numbers

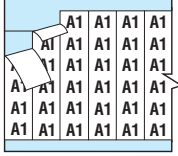

	B-500 Vinyl Cloth	B-702 Vinyl Film	B-605 Over- Laminated	B-184 Aluminum Foil	Markers per Card	
					1.500" (38.10 mm)	0.750" (19.05 mm)
A1	WM-A1	TWM-A1	OLWM-A1	AF-A1	36	72
A2	WM-A2	TWM-A2	OLWM-A2	AF-A2	36	72
A3	WM-A3				36	72
A4	WM-A4				36	72
A5	WM-A5				36	72
B1	WM-B1		OLWM-B1		36	72
B2	WM-B2		OLWM-B2		36	72
B3	WM-B3				36	72
B4	WM-B4				36	72
B5	WM-B5				36	72
C1	WM-C1		OLWM-C1		36	72
C2	WM-C2		OLWM-C2		36	72
C3	WM-C3				36	72
C4	WM-C4				36	72
C5	WM-C5				36	72
D1	WM-D1				36	72
D2	WM-D2				36	72
E1	WM-E1				36	72
E2	WM-E2				36	72
E3	WM-E3				36	72
E4	WM-E4				36	72
E5	WM-E5				36	72
F1	WM-F1	TWM-F1	OLWM-F1	AF-F1	36	72
F2	WM-F2	TWM-F2	OLWM-F2	AF-F2	36	72
F3	WM-F3				36	72
F4	WM-F4				36	72
G1	WM-G1				36	72
G2	WM-G2				36	72
G3	WM-G3				36	72
H1	WM-H1	TWM-H1	OLWM-H1	AF-H1	36	72
H2	WM-H2	TWM-H2	OLWM-H2	AF-H2	36	72
H3	WM-H3		OLWM-H3	AF-H3	36	72
H4	WM-H4		OLWM-H4	AF-H4	36	72
H5	WM-H5				36	72
J1	WM-J1				36	72
J2	WM-J2				36	72
J3	WM-J3				36	72
K1	WM-K1				36	72
K2	WM-K2				36	72
K3	WM-K3				36	72
L1	WM-L1	TWM-L1		AF-L1	36	72
L2	WM-L2	TWM-L2		AF-L2	36	72
L3	WM-L3	TWM-L3		AF-L3	36	72
L4	WM-L4				36	72
L5	WM-L5				36	72
M1	WM-M1	TWM-M1			33	66
M2	WM-M2	TWM-M2			33	66
M3	WM-M3				33	66
P1	WM-P1			AF-P1	36	72
P2	WM-P2			AF-P2	36	72
P3	WM-P3				36	72
P4	WM-P4				36	72
R1	WM-R1	TWM-R1			36	72
R2	WM-R2	TWM-R2			36	72
R3	WM-R3				36	72
R4	WM-R4				36	72
S1	WM-S1			AF-S1	36	72
S2	WM-S2			AF-S2	36	72
S3	WM-S3				36	72
S4	WM-S4				36	72
S5	WM-S5				36	72
T0				AF-T0	36	72
T1	WM-T1	TWM-T1	OLWM-T1	AF-T1	36	72
T2	WM-T2	TWM-T2	OLWM-T2	AF-T2	36	72
T3	WM-T3	TWM-T3	OLWM-T3	AF-T3	36	72
T4	WM-T4	TWM-T4	OLWM-T4	AF-T4	36	72
T5	WM-T5	TWM-T5		AF-T5	36	72
T6	WM-T6	TWM-T6		AF-T6	36	72
T7	WM-T7	TWM-T7			36	72
T8	WM-T8	TWM-T8			36	72
T9	WM-T9	TWM-T9			36	72
T10	WM-T10	TWM-T10			36	72
X1	WM-X1	TWM-X1	OLWM-X1	AF-X1	36	72
X2	WM-X2	TWM-X2	OLWM-X2	AF-X2	36	72
X3	WM-X3	TWM-X3	OLWM-X3	AF-X3	36	72
X4	WM-X4	TWM-X4	OLWM-X4	AF-X4	36	72
Y1	WM-Y1				36	72
Y2	WM-Y2				36	72
Y3	WM-Y3				36	72
Z1	WM-Z1				36	72
Z2	WM-Z2				36	72
Z3	WM-Z3				36	72

LEGEND


PRE-PRINTED
WIRE MARKERS

LETTERS & NUMBERS
WIRE MARKER CARDS

Wire Marker Cards

CONTINUED


Consecutive Paired Numbers

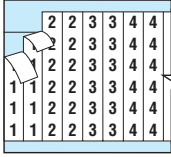

Vinyl Cloth (B-500)

LEGEND	Part Number	Pairs of Markers Per Card		Markers per Card	
		1.500" (38.10 mm)	0.750" (19.05 mm)	1.500" (38.10 mm)	0.750" (19.05 mm)
1-16	WM-1-16-DC	16	32	32	64
17-32	WM-17-32-DC	16	32	32	64
33-48	WM-33-48-DC	16	32	32	64
49-64	WM-49-64-DC	16	32	32	64
65-80	WM-65-80-DC	16	32	32	64
81-96	WM-81-96-DC	16	32	32	64


Consecutive Letters and Numbers Repeated

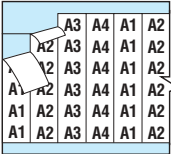

Vinyl Cloth (B-500)

LEGEND	Part Number	Sequences Per Card		Markers per Card	
		1.500" (38.10 mm)	0.750" (19.05 mm)	1.500" (38.10 mm)	0.750" (19.05 mm)
A1 - A4	WM-A1-A4	9	18	36	72
F1 - F4	WM-F1-F4	9	18	36	72
H1 - H4	WM-H1-H4	9	18	36	72
H1 - H9	WM-H1-H9	9	18	36	72
L1 - L4	WM-L1-L4	9	18	36	72
T1 - T4	WM-T1-T4	9	18	36	72
W1 - W4	WM-W1-W4	9	18	36	72
X1 - X4	WM-X1-X4	9	18	36	72

Suffix Numbers

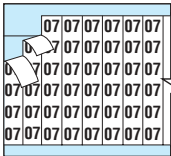

Vinyl Cloth (B-500)

LEGEND	Part Number	Markers per Card	
		1.500" (38.10 mm)	0.750" (19.05 mm)
00	WM-00-S	36	72
01	WM-01-S	36	72
and so on thru			
09	WM-09-S	36	72
00 - 09	WM-00-09-S	30	60

Note: Stock No. WM-00-09-S is a card of markers in 00 to 09 sequence with three sequences on a card.



PRE-PRINTED WIRE MARKERS

WIRE MARKER CARDS LETTERS & NUMBERS

Wire Marker Cards

CONTINUED

Solid Symbols — Miscellaneous

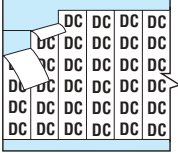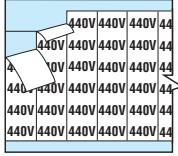

	B-500 Vinyl Cloth	B-702 Vinyl Film	B-605 Over- Laminated	Markers per Card	
				1.500" (38.10 mm)	0.750" (19.05 mm)
12V	WM-12V			25	50
24V	WM-24V			25	50
110V	WM-110V			20	40
115V	WM-115V			20	40
120V	WM-120V			20	40
220V	WM-220V			20	40
230V	WM-230V			20	40
240V	WM-240V			20	40
277V	WM-277V			20	40
440V	WM-440V			20	40
460V	WM-460V			20	40
480V	WM-480V			20	40
AC	WM-AC	TWM-AC		36	72
B +	WM-B-PLS			33	66
B -	WM-B-MNS			33	66
BAT	WM-BAT			25	50
COM	WM-COM			25	50
CT	WM-CT			36	72
DC	WM-DC	TWM-DC		36	72
GND	WM-GND	TWM-GND	OLWM-GND	25	50
GRD	WM-GRD			25	50
HOT	WM-HOT			25	50
IGN	WM-IGN			25	50
IN	WM-IN			36	72
LINE	WM-LIN			20	40
NEG	WM-NEG	TWM-NEG	OLWM-NEG	25	50
NEUT	WM-NEUT			20	40
OUT	WM-OUT			25	50
Phase C	WM-CPH			18	36
POS	WM-POS	TWM-POS	OLWM-POS	25	50
SEC	WM-SEC			25	50
SIG	WM-SIG			25	50
Spare	WM-SPR	TWM-SPR		20	40
TB	WM-TB			36	72
+	WM-PLS	TWM-PLS	OLWM-PLS	36	72
-	WM-MIN	TWM-MIN	OLWM-MIN	36	72
~	WM-CYS			36	72
⏏	WM-GRS			36	72
⚡	WM-HR-A			36	72
⚡	WM-IND-A			36	72
↻	WM-R-ROT	TWM-R-ROT	OLWM-R-ROT	36	72
↻	WM-L-ROT	TWM-L-ROT	OLWM-L-ROT	36	72

LEGEND


PRE-PRINTED
WIRE MARKERS

SOLID SYMBOLS
WIRE MARKER CARDS

Wire Marker Cards

CONTINUED


Solid Machine Tool Symbols

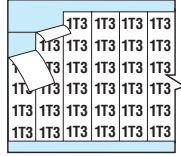

		B-500	B-702	Markers per Card	
		Vinyl Cloth	Vinyl Film	1.500" (38.10 mm)	0.750" (19.05 mm)
1L1		WM-1L1	TWM-1L1	25	50
1L2		WM-1L2	TWM-1L2	25	50
1L3		WM-1L3	TWM-1L3	25	50
2L1			TWM-2L1	25	50
2L2			TWM-2L2	25	50
2L3			TWM-2L3	25	50
3L1			TWM-3L1	25	50
3L2			TWM-3L2	25	50
3L3			TWM-3L3	25	50
4L1			TWM-4L1	25	50
4L2			TWM-4L2	25	50
4L3			TWM-4L3	25	50
5L1			TWM-5L1	25	50
5L2			TWM-5L2	25	50
5L3			TWM-5L3	25	50
6L1			TWM-6L1	25	50
6L2			TWM-6L2	25	50
6L3			TWM-6L3	25	50
1T1		WM-1T1	TWM-1T1	25	50
1T2		WM-1T2	TWM-1T2	25	50
1T3		WM-1T3	TWM-1T3	25	50
2T1		WM-2T1	TWM-2T1	25	50
2T2		WM-2T2	TWM-2T2	25	50
2T3		WM-2T3	TWM-2T3	25	50
3T1		WM-3T1	TWM-3T1	25	50
3T2		WM-3T2	TWM-3T2	25	50
3T3		WM-3T3	TWM-3T3	25	50
4T1		WM-4T1	TWM-4T1	25	50
4T2		WM-4T2	TWM-4T2	25	50
4T3		WM-4T3	TWM-4T3	25	50
5T1		WM-5T1	TWM-5T1	25	50
5T2		WM-5T2	TWM-5T2	25	50
5T3		WM-5T3	TWM-5T3	25	50
6T1		WM-6T1	TWM-6T1	25	50
6T2		WM-6T2	TWM-6T2	25	50
6T3		WM-6T3	TWM-6T3	25	50
7T1		WM-7T1	TWM-7T1	25	50
7T2		WM-7T2	TWM-7T2	25	50
7T3		WM-7T3	TWM-7T3	25	50
8T1			TWM-8T1	25	50
8T2			TWM-8T2	25	50
8T3			TWM-8T3	25	50
9T1			TWM-9T1	25	50
9T2			TWM-9T2	25	50
9T3			TWM-9T3	25	50
10T1			TWM-10T1	20	40
10T2			TWM-10T2	20	40
10T3			TWM-10T3	20	40
11T1			TWM-11T1	20	40
11T2			TWM-11T2	20	40
11T3			TWM-11T3	20	40

LEGEND

Consecutive Machine Tool Symbols Repeated

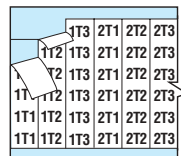

		B-500	B-702	Sequences Per Card		Markers per Card	
		Vinyl Cloth	Vinyl Film	1.500" (38.10 mm)	0.750" (19.05 mm)	1.500" (38.10 mm)	0.750" (19.05 mm)
1T1, 1T2, 1T3							
2T1, 2T2, 2T3							
3T1, 3T2, 3T3		WM-1T1-3T3		3	6	27	54
4T1, 4T2, 4T3							
5T1, 5T2, 5T3							
6T1, 6T2, 6T3		WM-4T1-6T3		3	6	27	54
7T1, 7T2, 7T3							
8T1, 8T2, 8T3							
9T1, 9T2, 9T3		WM-7T1-9T3	TWM-7T1-9T3	3	6	27	54
A1, A2, F1							
F2, S1, S2		WM-AFS		6	12	36	72

LEGEND


PRE-PRINTED WIRE MARKERS

WIRE MARKER CARDS MACHINE TOOL SYMBOLS

Wire Marker Cards

CONTINUED


Numbers on Colored Background

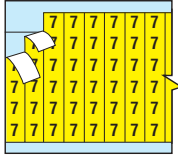

Vinyl Cloth (B-500)

LEGEND	BACKGROUND COLORS:					Markers per Card	
	Red	Yellow	Orange	Blue	Green	1.500" (38.10 mm)	0.750" (19.05 mm)
0	WM-0-RD	WM-0-YL	WM-0-OR	WM-0-BL	WM-0-GR	36	72
1	WM-1-RD	WM-1-YL	WM-1-OR	WM-1-BL	WM-1-GR	36	72
2	WM-2-RD	WM-2-YL	WM-2-OR	WM-2-BL	WM-2-GR	36	72
and so on thru	and so on thru	and so on thru	and so on thru	and so on thru	and so on thru		
9	WM-9-RD	WM-9-YL	WM-9-OR	WM-9-BL	WM-9-GR	36	72

Consecutive Numbers on Colored Background

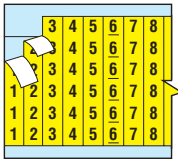


Vinyl Cloth (B-500)

LEGEND	BACKGROUND COLORS:								Quantity Each Number per Card		Markers per Card	
	Red	Yellow	Orange	Blue	Green	Brown	Black	1.500" (38.10 mm)	0.750" (19.05 mm)	1.500" (38.10 mm)	0.750" (19.05 mm)	
1-33	WM-1-33-RD	WM-1-33-YL	WM-1-33-OR	WM-1-33-BL	WM-1-33-GR	WM-1-33BR	WM-1-33-BK	1	2	33	66	
34-66	WM-34-66-RD	WM-34-66-YL	WM-34-66-OR	WM-34-66-BL	WM-34-66-GR	WM-34-66BR	WM-34-66-BK	1	2	33	66	
67-99	WM-67-99-RD	WM-67-99-YL	WM-67-99-OR	WM-67-99-BL	WM-67-99-GR	WM-67-99BR	WM-67-99-BK	1	2	33	66	
100-124	WM-100-124-RD	WM-100-124-YL	WM-100-124-OR	WM-100-124-BL	WM-100-124-GR	WM-100-124BR	WM-100-124-BK	1	2	25	50	

Note: White legend on red, green, brown and black backgrounds. All other colors have black legends.


Consecutive Letters On Colored Background

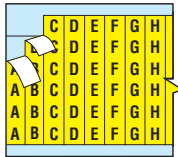

Vinyl Cloth (B-500)

LEGEND	Background Color	Part Number	Quantity Each Letter per Card		Markers per Card	
			1.500" (38.10 mm)	0.750" (19.05 mm)	1.500" (38.10 mm)	0.750" (19.05 mm)
A-Z	BLACK	WM-A-Z-BK	1	2	26	52
A-Z	BLUE	WM-A-Z-BL	1	2	26	52
A-Z	BROWN	WM-A-Z-BR	1	2	26	52
A-Z	GREEN	WM-A-Z-GR	1	2	26	52
A-Z	ORANGE	WM-A-Z-OR	1	2	26	52
A-Z	RED	WM-A-Z-RD	1	2	26	52
A-Z	YELLOW	WM-A-Z-YL	1	2	26	52

Solid NEMA Colors

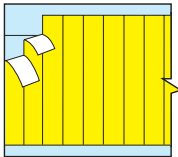

BACKGROUND COLOR	B-500 Vinyl Cloth	B-702 Vinyl Film	B-605 Over-Laminated	Markers per Card	
				1.500" (38.10 mm)	0.750" (19.05 mm)
BLACK	WM-COL-BK	TWM-COL-BK	OLWM-COL-BK	36	72
BROWN	WM-COL-BR	TWM-COL-BR		36	72
DARK BLUE	WM-COL-DB	TWM-COL-DB	OLWM-COL-DB	36	72
DARK GREEN	WM-COL-DG	TWM-COL-DG		36	72
GRAY	WM-COL-GY	TWM-COL-GY		36	72
LIGHT BLUE	WM-COL-LB	TWM-COL-LB	OLWM-COL-LB	36	72
LIGHT GREEN	WM-COL-LG	TWM-COL-LG	OLWM-COL-LG	36	72
MAROON	WM-COL-MR	TWM-COL-MR		36	72
OLIVE	WM-COL-OL	TWM-COL-OL		36	72
ORANGE	WM-COL-OR	TWM-COL-OR	OLWM-COL-OR	36	72
PINK	WM-COL-PK	TWM-COL-PK		36	72
PURPLE	WM-COL-PL	TWM-COL-PL		36	72
RED	WM-COL-RD	TWM-COL-RD	OLWM-COL-RD	36	72
TAN	WM-COL-TN	TWM-COL-TN		36	72
WHITE	WM-COL-WT	TWM-COL-WT	OLWM-COL-WT	36	72
YELLOW	WM-COL-YL	TWM-COL-YL	OLWM-COL-YL	36	72


PRE-PRINTED WIRE MARKERS

NUMBERS / LETTERS ON COLOR WIRE MARKER CARDS

Wire Marker Cards

CONTINUED


Self Laminating Letters — Upper Case

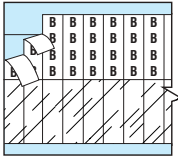

Vinyl Cloth (B-292)

LEGEND	Part Number	Markers per Card	
		1.500" (38.10 mm)	0.750" (19.05 mm)
A	SLF-A	36	72
B	SLF-B	36	72
C	SLF-C	36	72
and so on thru	and so on thru		
Z	SLF-Z	36	72

Self-Laminating Numbers

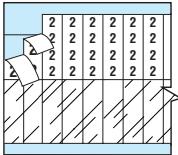


Vinyl Cloth (B-292)

LEGEND	Part Number	Markers per Card	
		1.500" (38.10 mm)	0.750" (19.05 mm)
0	SLF-0	36	72
1	SLF-1	36	72
2	SLF-2	36	72
and so on thru	and so on thru		
25	SLF-25	36	72
26	SLF-26	36	72
and so on thru	and so on thru	36*	72
	SLF-100	25	50

*36/card until "100", "100" is 25/card


Self-Laminating Consecutive Numbers

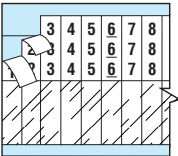

Vinyl Cloth (B-292)

LEGEND	Part Number	Quantity Each		Markers per Card	
		1.500" (38.10 mm)	0.750" (19.05 mm)	1.500" (38.10 mm)	0.750" (19.05 mm)
1-33	SLF-1-33	1	2	33	66
34-66	SLF-34-66	1	2	33	66
67-99	SLF-67-99	1	2	33	66

Self-Laminating Write-On Wire Markers

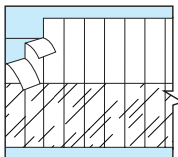

Vinyl Cloth (B-292)

Part Number	Write-on Area (Width x Height) Inch (mm)	Markers per Card
1.500" (38.10 mm) Long		
SLFW-250	0.250 x 0.750 (6.40 x 19.05)	36
SLFW-344	0.344 x 0.750 (8.70 x 19.05)	26
SLFW-500	0.500 x 0.750 (12.50 x 19.05)	18
SLFW-750	0.750 x 0.750 (19.05 x 19.05)	12
SLFW-100	1.000 x 0.750 (25.40 x 19.05)	9
SLFW-150	1.500 x 0.750 (38.10 x 19.05)	6
0.750" (19.05 mm) Long		
SLHW-188	0.187 x 0.375 (4.80 x 9.50)	96
SLHW-250	0.250 x 0.375 (6.40 x 9.50)	72
SLHW-344	0.344 x 0.375 (8.70 x 9.50)	52
SLHW-500	0.500 x 0.375 (12.50 x 9.50)	36
SLHW-750	0.750 x 0.375 (19.05 x 9.50)	24
SLHW-100	1.000 x 0.375 (25.40 x 9.50)	18
SLHW-150	1.500 x 0.375 (38.10 x 9.50)	12

PRE-PRINTED WIRE MARKERS

WIRE MARKER CARDS SELF-LAMINATING LETTERS & NUMBERS

Wire Marker Cards

CONTINUED

COMBINATION PACKS

Combination Packs



Each pack contains one card each of 25 numbers or 26 letters (A-Z) with all legends identical on each individual card.

	B-500 Vinyl Cloth	B-702 Vinyl Film	B-605 Over- Laminated
1 - 25	CPCWM-1-25	CPTWM-1-25	CPOLWM-1-25
26 - 50	CPCWM-26-50	CPTWM-26-50	CPOLWM-26-50
51 - 75	CPCWM-51-75	CPTWM-51-75	CPOLWM-51-75
76 - 100	CPCWM-76-100	CPTWM-76-100	CPOLWM-76-100
101 - 125	CPCWM-101-125	CPTWM-101-125	
126 - 150	CPCWM-126-150	CPTWM-126-150	
151 - 175	CPCWM-151-175	CPTWM-151-175	
176 - 200	CPCWM-176-200	CPTWM-176-200	
and so on thru	and so on thru	and so on thru	
301 - 325	CPCWM-301-325	CPTWM-301-325	
and so on thru	and so on thru		
576 - 600	CPCWM-576-600		
A - Z	CPCWM-A-Z	CPTWM-A-Z	CPOLWM-A-Z-CAP


Five Packs



Vinyl Cloth (B-500)

LEGEND	Part Number	Sequences per Card	
		1.500" (38.10 mm)	0.750" (19.05 mm)
0	WM-O-VP		
1	WM-1-VP		
2	WM-2-VP		
and so on thru	and so on thru		
9	WM-9-VP		
1 - 33	WM-1-33-VP	1	2
34 - 66	WM-34-66-VP	1	2
A - Z	WM-A-Z-VP	1	2


Solid Motor Numbers

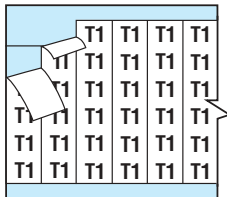

Acetate Cloth (B-12)

LEGEND	Part Number	Markers per Card	
		1.500" (38.10 mm)	0.750" (19.05 mm)
T1	HH-T1	36	72
T2	HH-T2	36	72
T3	HH-T3	36	72
and so on thru	and so on thru		
T6	HH-T6	36	72

Motor Hook-Up Diagrams

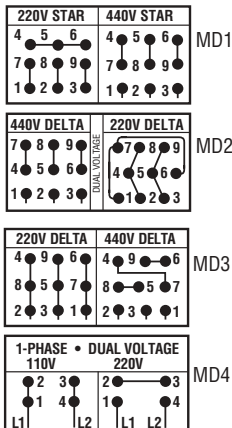

Acetate Cloth (B-12)

STYLE	Part Number	Label Size
		Inch (mm)
A	MD-1	1.500 x 0.750 (38.10 x 19.05)
B	MD-2	1.500 x 0.750 (38.10 x 19.05)
C	MD-3	1.500 x 0.750 (38.10 x 19.05)
D	MD-4	1.500 x 0.705 (38.10 x 19.05)

PRE-PRINTED
WIRE MARKERS

COMBO PACKS / MOTOR NUMBERS & DIAGRAMS

WIRE MARKER CARDS

Wire Marker Cards


CONTINUED

CABLE MARKERS



Standard 4" x 9" (101.6 mm x 228.6 mm) cards provide markers for cables, multi-wire circuits, even conductors and tubing in hydraulic systems. Markers may be slit for smaller diameter cable. Markers are 3.50" (89 mm) long; to order half markers, write 1.75" (44 mm) after stock number.


Solid Numbers

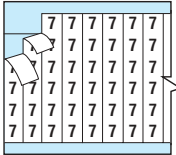

Vinyl (B-708)

	Part Number	Markers per Card	
LEGEND	0	CAB-0	18
	1	CAB-1	18
	2	CAB-2	18
	3	CAB-3	18
	4	CAB-4	18
	5	CAB-5	18
	6	CAB-6	18
	7	CAB-7	18
	8	CAB-8	18
	9	CAB-9	18

Consecutive Numbers or Letters

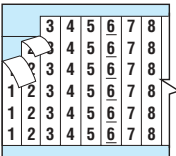


Vinyl (B-708)

	Part Number	Markers per Card	
LEGEND	01 - 09	CAB-01-09*	18
	1 - 9	CAB-1-9*	18
	1 - 18	CAB-1-18	18
	19 - 36	CAB-19-36	18
	37 - 54	CAB-37-54	18
	55 - 72	CAB-55-72	18
	73 - 90	CAB-73-90	18
	91 - 99	CAB-91-99	18
	A - I	CAB-A-I*	18
	J - R	CAB-J-R*	18
	S - Z	CAB-S-Z*	18

*Two sets of legends per card.

Solid Letters

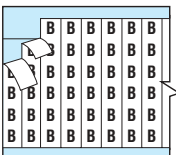

Vinyl (B-708)

	Part Number	Markers per Card	
LEGEND	A	CAB-A	18
	B	CAB-B	18
	C	CAB-C	18
	D	CAB-D	18
	E	CAB-E	18
	F	CAB-F	18
	N	CAB-N	18

PRE-PRINTED
WIRE MARKERS


WIRE MARKER CARDS CABLE MARKERS - NUMBERS & LETTERS

Wire Marker Cards


CONTINUED

MINIATURE WIRE MARKERS


Solid Numbers

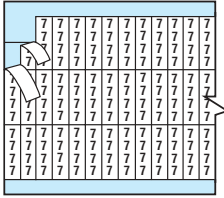


Solid Letters

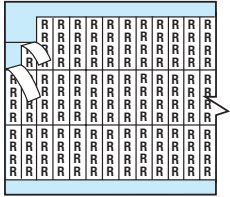

Solid Nema Colors

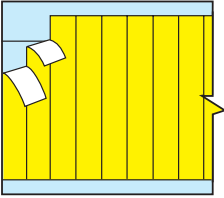

Consecutive Numbers

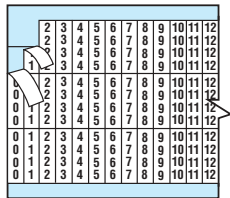

Vinyl Film (B-702)

	Part Number	Markers per Card 1.500" (38.10 mm)
0	TMM-0	150
1	TMM-1	150
2	TMM-2	150
3	TMM-3	150
and so on thru	and so on thru	
99	TMM-99	150
100	TMM-100	99
101	TMM-101	99
and so on thru	and so on thru	
125	TMM-125	99
A	TMM-A	150
B	TMM-B	150
C	TMM-C	150
and so on thru	and so on thru	
Z	TMM-Z	150

LEGEND

Vinyl Film (B-702)

	Part Number	Markers per Card 1.500" (38.10 mm)
BLACK	TMM-COL-BK	108
BROWN	TMM-COL-BR	108
DARK BLUE	TMM-COL-DB	108
DARK GREEN	TMM-COL-DG	108
GRAY	TMM-COL-GY	108
LIGHT BLUE	TMM-COL-LB	108
LIGHT GREEN	TMM-COL-LG	108
MAROON	TMM-COL-MR	108
OLIVE	TMM-COL-OL	108
ORANGE	TMM-COL-OR	108
PINK	TMM-COL-PK	108
PURPLE	TMM-COL-PL	108
RED	TMM-COL-RD	108
TAN	TMM-COL-TN	108
WHITE	TMM-COL-WT	108
YELLOW	TMM-COL-YL	108

BACKGROUND COLOR

Vinyl Film (B-702)

	Part Number	Quantity of Each Number per Card	Markers per Card 1.500" (38.10 mm)
0 - 49	TMM-0-49	3	150
50 - 99	TMM-50-99	3	150
100 - 132	TMM-100-132	3	99
133 - 165	TMM-133-165	3	99
166 - 198	TMM-166-198	3	99
199 - 231	TMM-199-231	3	99
232 - 264	TMM-232-264	3	99
265 - 297	TMM-265-297	3	99
298 - 330	TMM-298-330	3	99
331 - 363	TMM-331-363	3	99
364 - 396	TMM-364-396	3	99
397 - 429	TMM-397-429	3	99
430 - 462	TMM-430-462	3	99
463 - 495	TMM-463-495	3	99

LEGEND


PRE-PRINTED
WIRE MARKERS

MINIATURE WIRE MARKERS
WIRE MARKER CARDS

Wire Marker Cards

CONTINUED

MICRO MARKERS

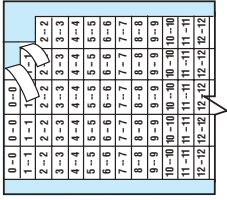

For identification of fine wire (#28 and smaller); resists continuous heat to 250°F (121°C). Only 2 mils thick. Two numbers on each marker, 250 markers on zip-strip dispenser card. Application tool included in each package of 25 cards. Marker size: 0.313" x 0.100" (7.95 mm x 2.54 mm).

Vinyl Film (B-702)

		Part Number	Markers per Card
LEGEND	NUMBERS		
	0	TMXM-0	250
	1	TMXM-1	250
	2	TMXM-2	250
	and so on thru	and so on thru	
17	TMXM-17	250	

		Part Number	Sequences on Each Card
LEGEND	CONSECUTIVE NUMBERS REPEATED		
	0 - 49	TMXM-0-49	5
	50 - 99	TMXM-50-99	5
	1 - 5	TMXM-1-5	50
	1 - 10	TMXM-1-10	25
1 - 25	TMXM-1-25	10	

WIRE MARKER CARD ACCESSORIES



Wire Marker Card Dispenser

- ▶ Holds cards in position... ready for fast application of markers.
- ▶ Allows both hands to be free for production line work, increasing productivity

Part No.	Description	Wt. Each
CH-2	Card Holder for 2.000" x 9.000" (50.80 mm x 228.60 mm) Cards	4 lbs (1.80 kg)
CH-SL	Card Holder Slitting Attachment	0.50 lb (0.20 kg)



Storenizer Work Center

- ▶ 36 individual compartments hold cards in view, within easy reach.
- ▶ Comes with a card holder and slitter to speed handling and application.
- ▶ Dimensions: width 13.500", depth 8.500", height 14.500".

Part No.	Description	Wt. Each
BLS-1	36 Compartment Wire Marker Unit, Card Holder and Slitter Attachment	11 lbs 2 oz (5.00 kg)

PRE-PRINTED WIRE MARKERS

WIRE MARKER CARDS MICRO MARKERS & CARD ACCESSORIES