


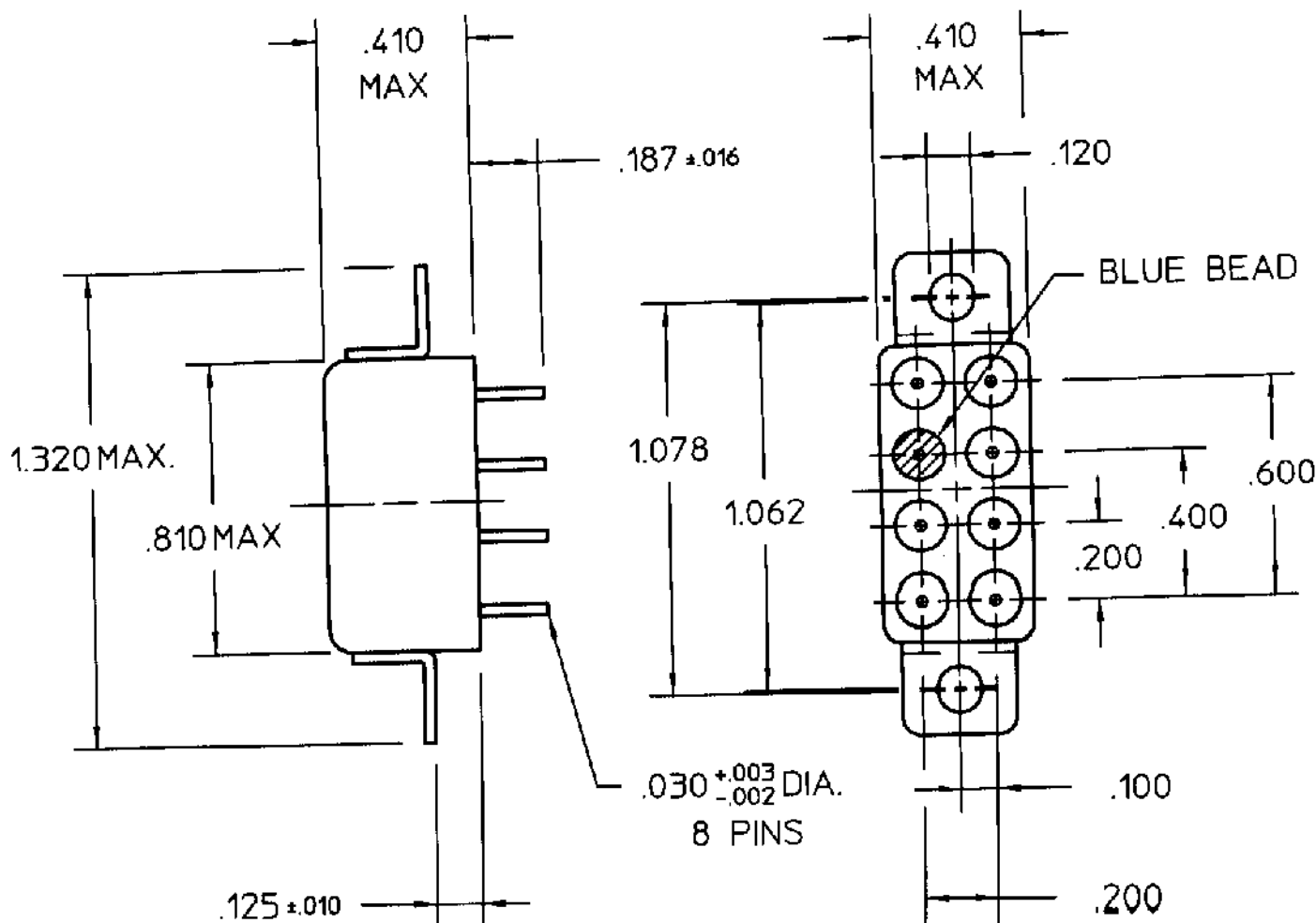

REV. 0

DCO 15768

COIL: @ 25°C

RESISTANCE 1620 OHMS ±10%

NOMINAL VOLTAGE 30.0 VDC

MUST OPERATE 14.3 VDC

1.4 VDC

MUST RELEASE

ENVIRONMENT:

VIBRATION 10 CPS TO 2500 CPS @ 20 g's

SHOCK 50 g's 11 MS. DURATION


TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 6 MS MAX.

RELEASE 5 MS MAX.

CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

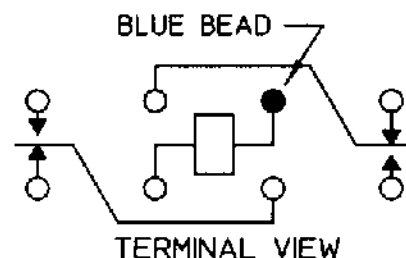

CONTACT RATING: LOW LEVEL TO 2A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 10/15/96 CK. GAH 8/9/99

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I. STD.

CUST. NO. REV.

HMS RELAY

HMS1230S005