

REV. B  
DCO 300860


TOLERANCES  $\pm .010$ " - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C	
RESISTANCE	320 OHMS $\pm 10\%$
NOMINAL VOLTAGE	28 VDC
MUST OPERATE	13.5 VDC MAX.
COIL TRANSIENT SUPPRESSION: 42 VDC MAX.	
MUST RELEASE	5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 Hz TO 3000 Hz @ 30 g's
SHOCK	200 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

NOTES:	OPERATE, RELEASE 10 MS MAX.
	CONTACT BOUNCE 1 MS MAX.
	CONTACT BREAK BOUNCE 0.1 MS MAX.

CUSTOMER DATA SHEET

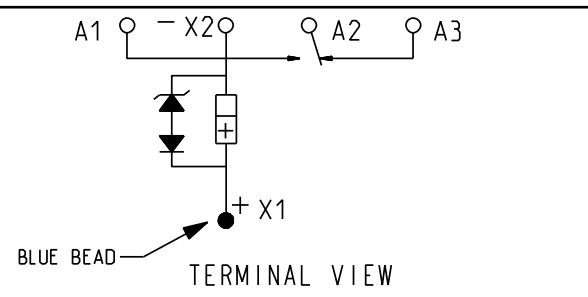

CONTACT RATING:	
25 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE	
50,000 OPERATIONS	

DR. B.D. 21MAY2008 CK. J.M.B. 5/21/08

**Tyco Electronics** ©COPYRIGHT 2005  
TYCO ELECTRONICS CORPORATION  
ALL INTERNATIONAL RIGHTS RESERVED

CUST.	QPL
CUST. NO.	M6106/19-015 REV. ----

TE NUMBER	2-1617748-1
-----------	-------------

CII PART NUMBER	FCA-125-15
-----------------	------------