



BALL KNOBS


BLACK

[proceed to red ball knobs >>](#)



Material- Phenolic
Insert- Brass
 † Insert- Steel, zinc plated



Molded Thread

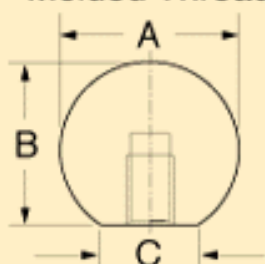

Threaded Insert

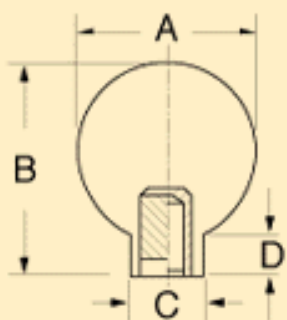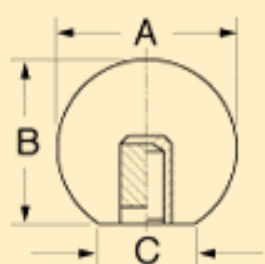

Threaded Insert w/Shank

Threaded Insert

Part No.	Insert	
	Thread	Depth
0035-X	3/8-16	1/2
0035CH *5	3/8-16	1/2
0035CL	5/16-18	1/2
0035CS *5	5/16-18	1/2

*w/shank 4"B"=1-1/2, "D"=5/16

3"B"=27/32, "D"=1/4, 5"B"=1-13/16, "D"=1/2

Molded Thread

Part No.	Thread	Depth
0035-D	1/2-13	7/8
0035-Q	1/4-20	5/8
0035AU *2	1/4-20	5/8

*w/shank

1"B"=1-1/2, "D"=5/16

2"B"=1-13/16, "D"=1/2

[← back](#)