


4,724" x 4,724" x 1,496"

120 x 120 x 38 mm

Series
125

ETRI®

AC Axial Fans

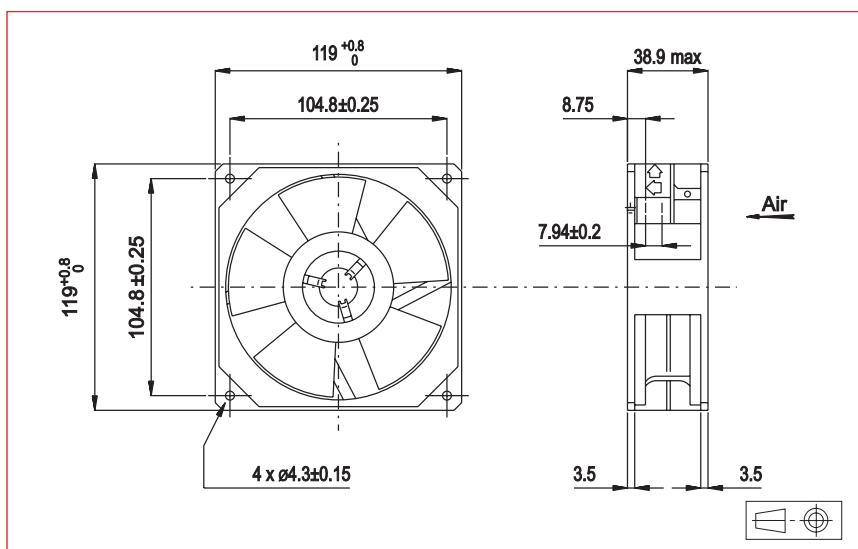

Approvals



AC Motor


Electrical protection: impedance protected
Housing material: zamak
Impeller material: plastic UL 94 VO
Weight: 725 g
Bearing system: ball bearings

Available with:

- Flying leads
- Speed sensor

Life expectancy

L-10 LIFE AT 40°C:
80 000 hours

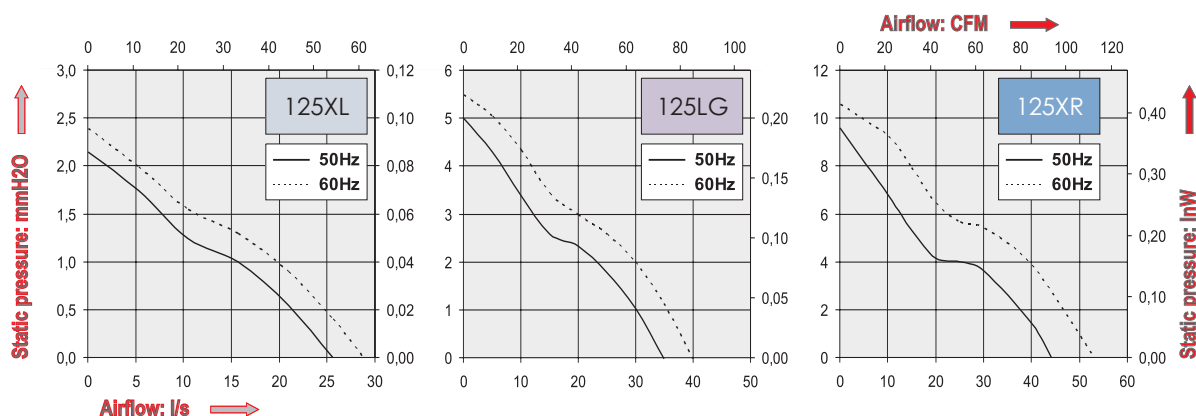

Part Number	Nominal voltage	Airflow	Noise level	Nominal speed	Frequency	Phases	Capacitor	Input Power	Nominal current	Starting current	Connection type		Operating temperature	
	V	l/s	dB(A)	RPM	Hz		µF	W	mA	mA	Leads	Terminals	Min.°C	Max.°C
125XL0182000	115	25	30	1600	50	1		12	135	145		X	-10	70
		27	32	1750	60	1		10	115	125		X	-10	70
125XL0181000	208-240	25	30	1600	50	1		12	75	90		X	-10	70
		27	32	1750	60	1		10	65	75		X	-10	70
125LG0182000	115	35	38	2200	50	1		16	200	260		X	-10	70
		40	40,5	2500	60	1		13	160	120		X	-10	70
125LG0181000	208-240	35	38	2200	50	1		18	110	140		X	-10	70
		40	40,5	2500	60	1		15	90	120		X	-10	70
125XR0182000	115	44	44	2800	50	1		16	200	310		X	-10	70
		53	48	3200	60	1		15	180	260		X	-10	70
125XR0181000	208-240	44	44	2500	50	1		18	125	170		X	-10	70
		53	48	3200	60	1		15	105	150		X	-10	70

Additional versions:

Dual voltage 115V - 230V - other weight: 560g - aluminium housing - salt spray protected - shock and vibration protected - marine specifications - wide temperature range - IP54: consult factory

Accessories:

Refer to Accessories leaflet