

TYPE HP-N





NYLOCLIP®

CABLE HANGER

NYLOCLIP® cable hangers are fabricated one-piece nylon, with no metal parts. Tough, resilient, lightweight and abrasion resistant, NYLOCLIP® cable hangers offer high tensile strength and are resistant to solvents, alkalis, oils grease and diluted acids.

Available in white or black UV/weather resistant material.

Meets Mil spec M-20693, ASTM STD D4066 Group 1 Class 1.

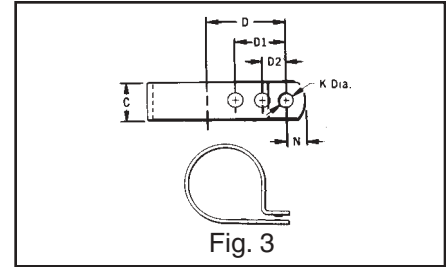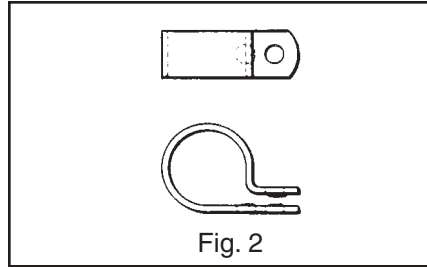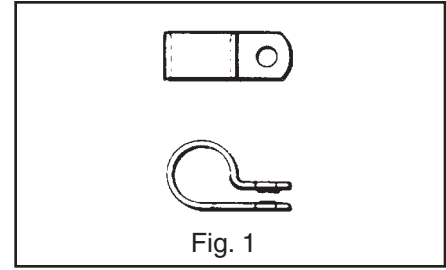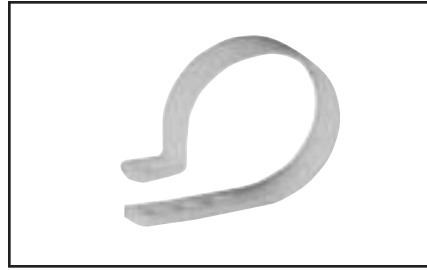

CATALOG NUMBER	FIG. NO.	C	D*	D1	D2	N	K DIA.	SCREW SIZE	WIRE BUNDLE DIAMETER			BULK CATALOG NUMBER
									HOLE 1	HOLE 2	HOLE 3	
HP-2N BOX	1	.38	.37	-	-	.19	.17	#8	.10	-	-	HP-2N
HP-3N BOX	1	.38	.40	-	-	.19	.17	#8	.18	-	-	HP-3N
HP-4N BOX	1	.38	.43	-	-	.19	.17	#8	.22	-	-	HP-4N
HP-5N BOX	1	.38	.46	-	-	.19	.17	#8	.29	-	-	HP-5N
HP-6N BOX	1	.38	.50	-	-	.19	.17	#8	.33	-	-	HP-6N
HP-7N BOX	1	.38	.52	-	-	.19	.17	#8	.42	-	-	HP-7N
HP-8N BOX	1	.38	.54	-	-	.19	.17	#8	.47	-	-	HP-8N
HP-9N BOX	1	.38	.57	-	-	.19	.17	#8	.53	-	-	HP-9N
HP-10N BOX	1	.38	.61	-	-	.19	.17	#8	.62	-	-	HP-10N
HP-11N BOX	1	.50	.65	-	-	.25	.20	#10	.66	-	-	HP-11N
HP-12N BOX	1	.50	.69	-	-	.25	.20	#10	.70	-	-	HP-12N
HP-13N BOX	1	.50	.72	-	-	.25	.20	#10	.82	-	-	HP-13N
HP-14N BOX	2	.50	.76	.31	-	.25	.20	#10	.84	.73	-	HP-14N
HP-16N BOX	2	.50	.82	.31	-	.25	.20	#10	.96	.88	-	HP-16N
HP-18N BOX	2	.50	.86	.31	-	.25	.20	#10	1.05	.95	-	HP-18N
HP-24N BOX	3	.50	.95	.62	.31	.25	.20	#10	1.47	1.38	1.23	HP-24N
HP-32N BOX	3	.50	1.25	.81	.38	.25	.20	#10	1.92	1.82	1.72	HP-32N

For weatherproof UNIRAP™ ties add suffix "-X" to catalog number (example: HP-24NX BOX or HP-24NX).

* D - Distance from hole 1 centerline of cable bundle.