

SMB3528



SMB3528LF*



Wirewound





PART NUMBER	TURNS	IMPEDANCE OHMS MIN				DCR OHMS MAX	CURRENT RATING A DC MAX
		10 MHz	100 MHz	150 MHz	220 MHz		
FERRITE CORE							
SMB3528-1	2.5	210	385	400	375	0.005	9.5
SMB3528-2	2.5	N/A	490	635	650	0.005	9.5

Custom designs are available to meet your specific requirements; please contact factory

***Add "LF" suffix for RoHS requirement. Example: SMB3528-LF**

Gowanda designates a component RoHS-compliant by adding "LF" (lead free) to the part number.

These LF components meet the $\leq .1\%$ lead requirement and they are compatible with 260°C soldering processes.

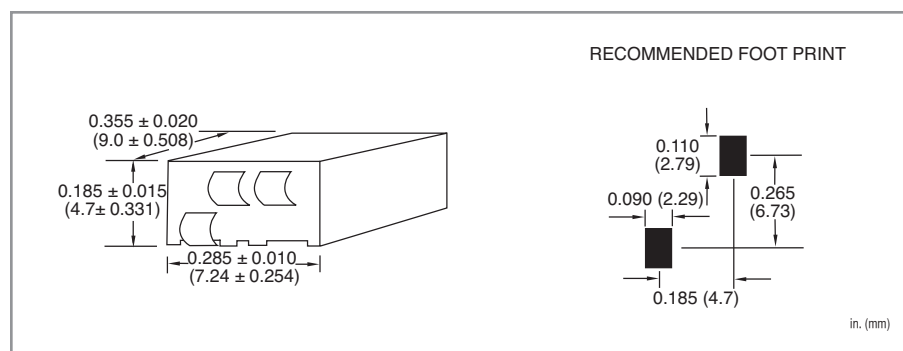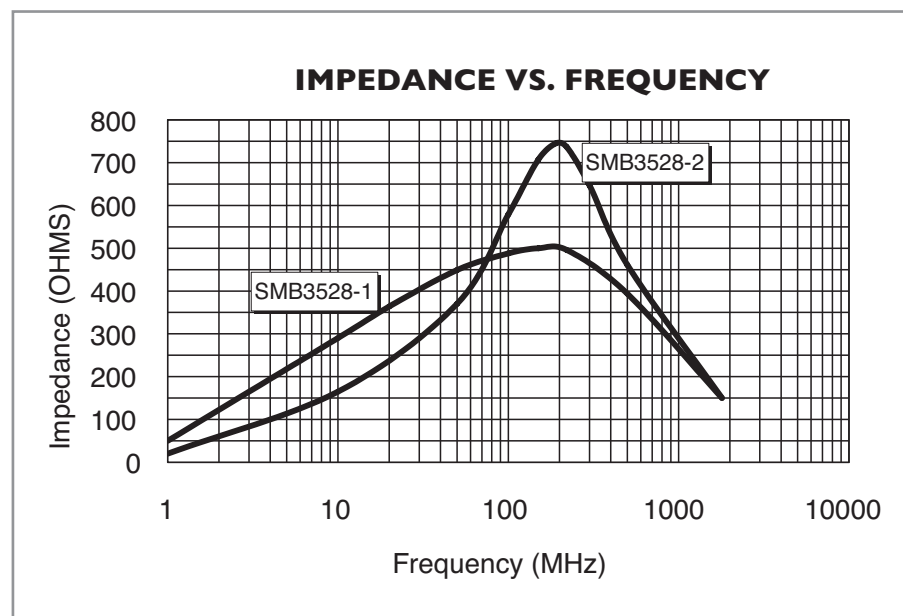

NOTES:

- Operating Temperature Range: -40°C to +125°C
- Current Rating is based on a 35°C temperature rise at an ambient temperature of 90°C

TAPE AND REEL SPECS:

Pcs./Reel maximum:	500
Pitch between parts:	12 mm
Tape width:	16 mm
Reel diameter:	13 in.