

## Twist-Lock® Devices

# 30 Ampere, 125/250 Volts and 3Ø 250 Volts AC

3 Pole, 4 Wire Grounding

## Insulgrip® Connector Bodies and Receptacles



30A 125/250V  
NEMA L14-30R  
UL/CSA  
2 (2) HP



30A 3Ø 250V AC  
NEMA L15-30R  
UL/CSA  
3 HP

## Connector Bodies

### Watertight Safety-Shroud®

Description	Cord Dia.	IP66 SUITABILITY	
		Catalog Numbers	
Black Valox® housing, white Valox® clamps.	.35"-1.15" (9-29)	HBL2713SW	HBL2723SW



HBL2713SW

### Insulgrip

Description	Cord Dia.	IP20 SUITABILITY	
		Catalog Numbers	
Black and white nylon.	.35"-1.15" (9-29)	HBL2713	HBL2723
Corrosion resistant, yellow nylon.	.35"-1.15" (9-29)	HBL27CM13	HBL27CM23
All black nylon.	.35"-1.15" (9-29)	HBL2713BK	-



HBL2713

Accessories on page B-53.

## Receptacles

### Watertight Safety-Shroud, Back Wired

Description	IP66 SUITABILITY	
		Catalog Numbers
Gray Valox® housing and flange.	HBL2710SW HBL2720SW	

Accessories on page B-54.

### Safety-Shroud Twist-Lock, Back Wired

Description	IP20 SUITABILITY	
		Catalog Numbers
Gray Valox® angle housing, one gang.	HBL2710AR HBL2720AR	
Gray Valox® surface mounting, one gang.	HBL2710SR HBL2720SR	
Gray Valox® semi-flush, two gang.	HBL2710SR2 HBL2720SR2	

Accessories on page B-54.



HBL2710SW

### Single Flush, Back and Side Wired

Description	IP20 SUITABILITY	
		Catalog Numbers
Black nylon face.	HBL2710 HBL2720	
Isolated ground, orange nylon face.	IG2710 IG2720	
Ring terminal connection.	HBL2710RT HBL2720RT	

Accessories on page B-52.




HBL2710AR


### Insulgrip Flanged Receptacles

Description	Catalog Numbers	
Nylon casing, back wired.	HBL2716	HBL2726


Accessories on page B-52.

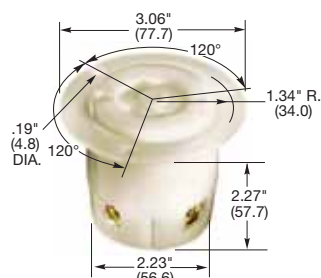

HBL2716

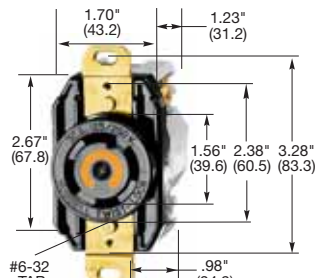

HBL2710

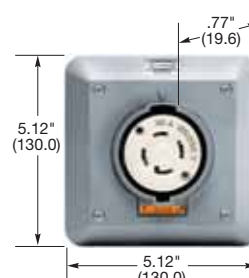

HBL2710SR2



HBL2710SR

Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.