

Temporary Power Distribution Systems

Cable Sets and Receptacles

Replacement Parts and Specifications

Cable Sets and Receptacles

Cable Sets and Receptacles

Description	Catalog Numbers
50A cord set - 50 ft. cable (input/output).	SCB50
50A pre-wired wall mounted receptacle.	SR50
60A cord set - 6 ft. cable (input/output).	SCC06
60A cord set - 50 ft. cable (input/output).	SCC50
60A, 3Ø 120/208V Pin & Sleeve wall mounted receptacle.	HBL560R9W
1 1/4" hub 15 deg. angle back box for 60A receptacle.	BB601W
1 1/2" hub 15 deg. 4-way angle back box for 60A receptacle.	FW60100


Note: Consult factory for alternate cable lengths.



HBL2310SW



GFM20

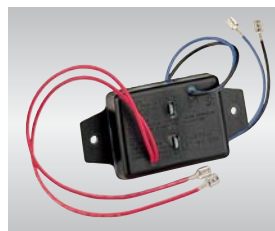

SSK

Replacement Parts

Description	Catalog Numbers
20A, 125V Safety-Shroud Twist-Lock® receptacle.	HBL2310SW
30A, 250V Safety-Shroud Twist-Lock receptacle.	HBL2620SW
20A, 125V straight blade receptacle.	HBL53R61
50A, 125/250V Twist-Lock receptacle.	CS6369
50A, 125/250V Twist-Lock inlet.	HBL6375S
60A, 3Ø 120/208V Pin & Sleeve reversed service receptacle (inlet).	HBL560B9R
60A, 3Ø 120/208V Pin & Sleeve receptacle (outlet).	HBL560R9W
GFCI module.	GFM20
50A Spider supervisory kit.	SSK
60A Spider supervisory kit.	SSK60
Spider circuit breaker cover.	SCBC
Spider leg kit.	SLK
50A receptacle cover plate.	HBL77CM74WO

Specifications

Spider® II

Listing/Certifications	UL 1640 cUL and CSA, UL 943
Operation	Indoor and outdoor wet and dry locations.
Enclosure Type	3R, rainproof, suitable for use in damp locations.
Code Compliance	NEC®, ANSI/NFPA 70



SCB50



SR50



SCBC



HBL77CM74WO