


**PAN-FLEX™  
.050" Flat Cable**

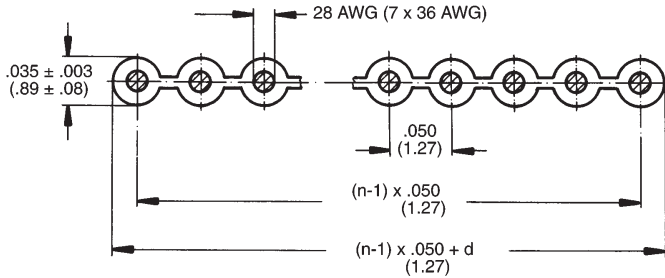

Conductors	Part Numbers	Per Reel
	Only 1st Conductor is Color-marked	
6	<b>050F28V6 CR*</b>	(100 FT)
10	<b>050F28V10 CR*</b>	
14	<b>050F28V14 CR*</b>	
16	<b>050F28V16 CR*</b>	
20	<b>050F28V20 CR*</b>	
26	<b>050F28V26 CR*</b>	
32	<b>050F28V32 CR*</b>	
34	<b>050F28V34 CR*</b>	
40	<b>050F28V40 CR*</b>	
50	<b>050F28V50 CR*</b>	
60	<b>050F28V60 CR*</b>	
64	<b>050F28V64 CR*</b>	

**\*CR = 100ft Rolls**  
**THR = 300ft Rolls**  
 (Available on 10, 14, 20, 26, 34 and 50 circuit sizes)

Conductor	CU Tinned
Insulation	PVC Gray
Conductor Resistance	$\leq 230 \Omega/\text{km}$
Insulation Resistance	$\geq 90 \times 10^6 \Omega/\text{km}$
Capacitance	56 pF/m
Voltage Rating	300 V <sup>eff</sup>
Temperature Rating	-20 °C/ + 105 °C