


**Series 050
Sockets**


**6 to 64 contact sockets
compatible with:
Din 41651,
MIL-C-83503**

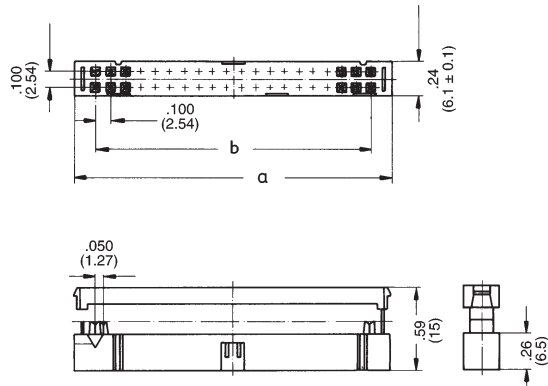

Without Strain Relief



With Strain Relief Bracket - Optional

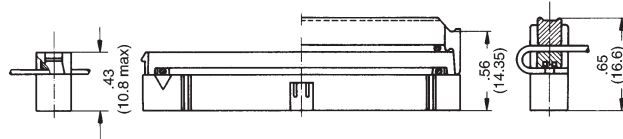

Dimensions

	6	10	14	16	20	26	34	40	50	60	64
a	.48" (12.2)	.68" (17.3)	.88" (22.4)	.98" (24.9)	1.18" (30.0)	1.48" (37.6)	1.88 (47.8)	"2.18" (55.4)	2.68" (68.1)	3.18" (80.8)	3.38" (85.9)
b	.200" (5.08)	.400" (10.16)	.600" (15.24)	.700" (17.78)	.900" (22.86)	1.200" (30.48)	1.600" (40.64)	1.900" (48.26)	2.400" (60.96)	2.900" (73.66)	3.100" (78.74)

Part numbers

No. of contacts 6, 10, 14, 16, 20, 26, 34, 40, 50, 60, 64

□□ = Number of Circuits

Sockets				
Termination Methods	Plating Thickness	Without Strain Relief		Strain Relief Bracket
		Without Center Polarization	With Center Polarization	
Insulation displacement connection	30μ" Au Plating	050-0 □□ - 435	050-0 □□ - 435A	050-000-0 □□ Must Order Separate
	15μ" Au Plating	050-0 □□ - 455	050-0 □□ - 455A	