

RIBBON CABLE



- 08-1410-100** 10-conductor
- 08-1414-100** 14-conductor
- 08-1416-100** 16-conductor
- 08-1420-100** 20-conductor
- 08-1425-100** 25-conductor
- 08-1426-100** 26-conductor
- 08-1434-100** 34-conductor
- 08-1440-100** 40-conductor
- 08-1450-100** 50-conductor



Grey jacket 28 AWG stranded .050" ribbon cable. Available in 100' spools only. Rated 300V 105 degrees C. UL and CSA listed.

RIBBON CABLE CUTTER



Precision ground.

84-404-1 Pkg.

.062" CONTACT CONNECTORS



5A @ 250V

 


Plug Receptacle

Plug	Receptacle	Package	Contacts
37-002-0	37-102-0	37-202-2	2
37-003-0	37-103-0	37-203-2	3
37-004-0	37-104-0	37-204-1	4
37-005-0	37-105-0	37-205-1	5
37-006-0	37-106-0	37-206-1	6
37-009-0			9
37-012-0	37-112-0	37-212-1	12

Package contains 1 or 2 plugs, receptacles and contacts

.062" CONTACTS




37-910-0

Female contacts 20-24 AWG

37-900-0

Male contacts 20-24 AWG

.093" CONTACT CONNECTORS

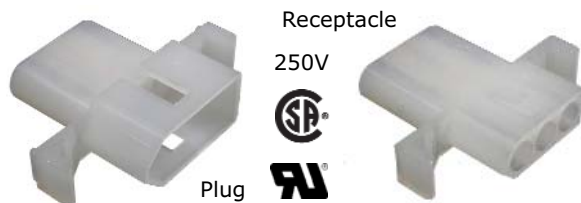

Receptacle

250V



Plug

Plug	Receptacle	Package	Cont.
37-302-0	37-402-0	37-502-2	2 12A
37-303-0	37-403-0	37-503-1	3 12A
37-304-0	37-404-0	37-504-1	4 9A
37-306-0	37-406-0	37-506-1	6 9A
37-309-0	37-409-0	37-509-1	9 9A
37-312-0	37-412-0	37-512-1	12 7.5A

Package contains 1 or 2 plugs, receptacles and contacts

.093" CONTACTS




37-940-0

Female contacts 18-22 AWG

37-930-0

Male contacts 18-22 AWG

.100" WIRE CONNECTORS

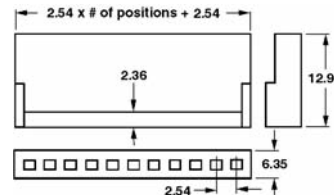

Pos	Bulk	Pkg.
2	37-602-0	-5
3	37-603-0	-5
4	37-604-0	-4
5	37-605-0	-3
6	37-606-0	-3
8	37-608-0	-2
9	37-609-0	-2

Each package includes contacts. -5 is 5 connectors + contacts.

CONTACTS



37-960-0

Bulk 22-28 AWG contacts

.100" PC HEADERS

Straight PC headers for 37-60X series. .64mm PC posts.



Display Packages

Pos	Bulk	Pkg.
2	37-6202-0	-6
3	37-6203-0	-5
4	37-6204-0	-5
5	37-6205-0	-4
6	37-6206-0	-3
8	37-6208-0	-2


Right angle PC headers for 37-60X series. .64mm PC posts.




Display Packages

Pos	Bulk	Pkg.
2	37-6302-0	-5
3	37-6303-0	-4
4	37-6304-0	-3
5	37-6305-0	-2
6	37-6306-0	-2
8	37-6308-0	-2

Drawings for 37-62xx & 37-63xx

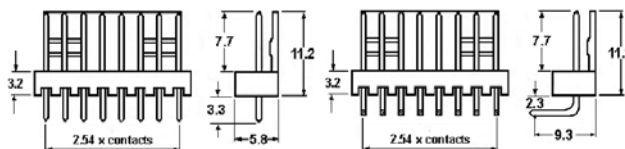

.156" WIRE CONNECTORS

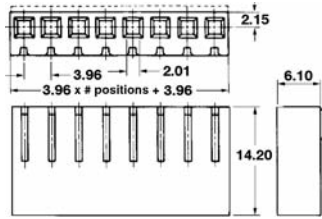

Package contains connectors and contacts.

Pos	Bulk	Pkg.
2	37-702-0	-5
4	37-704-0	-5
6	37-706-0	-3
8	37-708-0	-2

.156" WIRE CONTACTS



37-970-0 Bulk
18-22AWG wire

.156" PC HEADERS

Straight PC headers for 37-70X series. 1.14mm PC posts.




Pos	Bulk	Pkg.
8	37-7208-0	-2

Right Angle PC headers for 37-70X series. 1.14mm PC posts.



Pos	Bulk	Pkg.
2	37-7302-0	-5
4	37-7304-0	-5
6	37-7306-0	-3
10	37-7310-0	-2

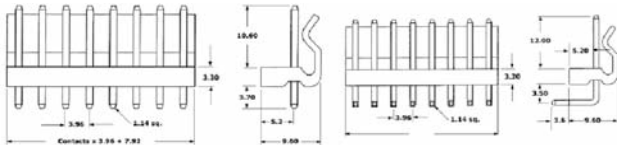

See the tool section starting on Page 85 for crimp tools and insertion/extraction tools for the crimp contacts shown on this page.


MODE ELECTRONICS LTD.
211 - 2999 UNDERHILL AVE.,
BURNABY, B.C., CANADA, V5A 3C2
Phone: 604-435-6633
Fax: 604-435-8890
Toll Free: 1-800-663-4992
Web Site: www.mode-elec.com

Visit our Web Site at
<http://www.mode-elec.com>

DUAL WIPE STANDARD I.C. SOCKETS




30% glass filled polyester UL94V-0 insulator. Contacts: phosphor bronze with 50 microinches hot tin dip.

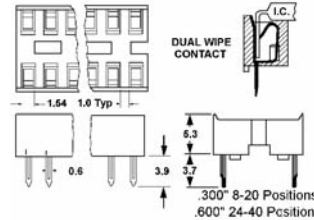

Pos.	Bulk	Pkg. #
8-pos.	39-008-0	-10
14-pos.	39-014-0	-6
16-pos.	39-016-0	-5
18-pos.	39-018-0	-4
20-pos.	39-020-0	-4
24-pos.	39-024-0	-3
28-pos.	39-028-0	-3
32-pos.	39-032-0	-3
40-pos.	39-040-0	-2

MACHINED CONTACT I.C. SOCKETS


94V-0 PBT insulator 15 micro inch gold plated contact area.

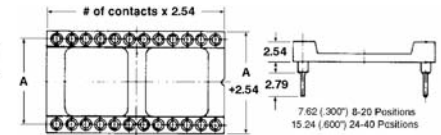

Pos.	Bulk	Pkg.
8-pos.	39-108-0	-3
14-pos.	39-114-0	-2
16-pos.	39-116-0	-2
40-pos.	39-140-0	-1

DIP RIBBON CONNECTORS


UL94V-0 40% glass fibre PBT, 10 micro inches gold plating.

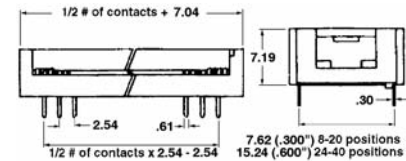

Pos.	Bulk
14-pos.	39-214-0
16-pos.	39-216-0
20-pos.	39-220-0

PLCC SOCKETS

94V-0 glass filled thermoplastic, tin plated contacts.

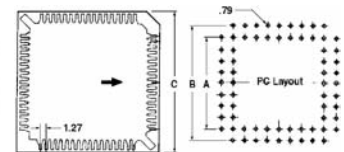

Pos	A	B	C
44	.500	.700	.898
68	.800	1.000	1.26
84	1.000	1.200	1.46

Pos.	Bulk	Pkg.
44-pos.	39-344-0	
68-pos.	39-368-0	-1
84-pos.	39-384-0	-1