



**24-100-0** Bulk  
**24-100-2** Pkg (2)

Metal body RCA plug. Maximum cable dia. 7.5mm



**24-180-0** Bulk  
**24-180-2** Pkg (2)

Chassis mount RCA jack.  
6.4mm mounting hole.



**24-104-0** Bulk  
**24-104-2** Pkg (2)

Metal plug with strain relief. Maximum cable dia. 4.5mm




**24-181-0** Bulk  
**24-181-2** Pkg (2)

Gold plated chassis RCA jack.  
6.4mm mounting hole.



**24-105-0** RG59/u Pkg  
**24-105-1** Pkg  
**24-106-0** RG6/u Pkg  
**24-106-1** Pkg

Use 84-156-1 tool for installation

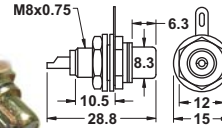


**24-183B-0** Black Bulk  
**24-183R-0** Red Bulk  
**24-183-2** Pkg (2)

Gold Plated Color coded isolated chassis RCA jack. 8mm mtg hole.



**24-101-0** Black  
**24-102-0** Red  
**24-109-4** Pkg (4)

 Colored plastic body RCA plugs. Max. cable dia. 4.5mm.




**24-191-0** Bulk  
**24-191-2** Pkg (2)

PC mount RCA jack



**24-111-0** Black  
**24-112-0** Red  
**24-113-4** Pkg (4)

Colored plastic with strain relief. Max. cable dia. 4.5mm

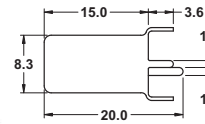


**24-192-0** Bulk  
**24-192-2** Pkg (2)

PC mount RCA jack



**24-114-0** Bulk  
**24-114-2** Pkg (2)

Black plastic right angle RCA plug. Max. cable dia. 5.1mm

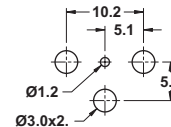

**24-195-0** Bulk  
**24-195-2** Pkg (2)

Right angle PC mount RCA jack



**24-116-0** Bulk  
**24-116-2** Pkg (2)

Crimp RCA plug for RG59/u



**24-120-0** Bulk  
**24-120-1** Pkg

Gold plated plug with spring strain relief. Cable dia 5.5mm



 
**24-121-0** Black  
**24-122-0** Red  
**24-123-2** Pkg (2)

Color coded gold plated plugs. Max. cable dia. 5.0mm



**24-124-0** Black  
**24-125-0** Red  
**24-126-2** Pkg (2)

Color coded gold plated plugs. Max cable dia. 6.0mm



**24-150-0** Bulk  
**24-150-2** Pkg (2)

Metal body RCA jack. Max. cable dia. 7.5mm

**Special Order Products**  
*If you have a requirement for items not shown in this Catalog, please contact Mode or your local Distributor and we would be pleased to find an economical source.*

**MODE ELECTRONICS LTD.**  
**211 - 2999 UNDERHILL AVE.,**  
**BURNABY, B.C., CANADA, V5A 3C2**  
**Phone: 604-435-6633**  
**Fax: 604-435-8890**  
**Toll Free: 1-800-663-4992**  
**Web Site: www.mode-elec.com**

Dimensions shown for plugs and jacks are lengths and diameters of the plug body (without S/R). Cable diameter dimension is maximum cable size.

## 2.5mm PLUGS



**24-200-0** Bulk  
**24-200-2** Pkg (2)

**Mono** plug 25mm long x 9mm dia. Cable dia. 6mm



**24-211-0** Bulk  
**24-211-2** Pkg (2)

**Mono** plug 19 x 8mm dia. Cable diameter 4mm



**24-221-0** Bulk  
**24-221-1** Pkg

**Stereo** plug 23mm x 8mm dia. Cable diameter 4mm



**24-223-0** Bulk  
**24-223-1** Pkg

**Stereo** plug 24mm x 10mm dia. Cable diameter 4mm

## 2.5mm JACKS



**24-271-0** Bulk  
**24-271-1** Pkg

Inline **stereo** jack Black color. 26mm L x 11mm dia. Cable dia. 5mm



**24-287-0** Bulk  
**24-287-2** Pkg (2)

**Mono** chassis jack. 8mm W x 9.6mm H x 8mm D. 4mm mtg. hole



**24-288-0** Bulk  
**24-288-2** Pkg (2)

**Stereo** chassis jack. 8mm W x 9.6mm H x 8mm D. 4mm mtg. hole

**MODE ELECTRONICS LTD.**  
211 - 2999 UNDERHILL AVE.,  
BURNABY, B.C., CANADA, V5A 3C2  
Phone: 604-435-6633  
Fax: 604-435-8890  
Toll Free: 1-800-663-4992  
Web Site: [www.mode-elec.com](http://www.mode-elec.com)

## 3.5mm PLUGS



**24-300-0** Bulk  
**24-300-2** Pkg (2)

Metal **mono** plug 25 x 9mm dia. Cable dia. 4.5mm



**24-301-0** Bulk  
**24-301-2** Pkg (2)

**Mono** plug 25 x 10mm diameter. Cable dia. 5mm



**24-303-0** Bulk  
**24-303-2** Pkg (2)

**Mono** plug 24 x 10mm dia. Cable dia. 4mm



**24-304-0** Bulk  
**24-304-2** Pkg (2)

Metal **mono** plug 26 x 9mm dia. Cable dia. 4.5mm



**24-310-0** Bulk  
**24-310-2** Pkg (2)

3.5mm **mono** right angle plug. Cable diameter 6.75mm



**24-319-0** Bulk  
**24-319-2** Pkg (2)

3.5mm **stereo** right angle plug. Cable diameter 6.75mm



**24-320-0** Bulk  
**24-320-2** Pkg (2)

Metal **stereo** plug. 25mm x 9mm dia. Cable dia. 6.5mm



**24-321-0** Bulk  
**24-321-2** Pkg (2)

Black plastic **stereo** plug. 25 x 10mm dia. Cable 6mm dia.



**24-322-0** Bulk  
**24-322-2** Pkg (2)

Metal **stereo** plug. 25 x 9mm dia. Cable dia. 4.5mm



**24-323-0** Bulk  
**24-323-2** Pkg (2)

Black plastic **stereo** plug. 52 x 10mm dia. Cable dia. 4mm

Visit our Web Site at  
<http://www.mode-elec.com>

**3.5mm JACKS**



**24-351-0** Bulk  
**24-351-2** Pkg (2)

Black mono jack. 35 x 9mm dia. Cable dia. 6mm



**24-353-0** Bulk  
**24-353-2** Pkg (2)

Metal mono jack. 34 x 10mm dia. Cable dia. 4.5mm



**24-354-0** Bulk  
**24-354-2** Pkg (2)

Black plastic mono jack. 34 x 11mm dia. Cable dia. 4.0mm



**24-371-0** Bulk  
**24-371-1** Pkg

Black plastic stereo jack. 34 x 11mm dia. Cable dia. 4.5mm



**24-372-0** Bulk  
**24-372-2** Pkg (2)

Metal stereo jack. 34 x 10mm dia. Cable dia. 6mm




**24-373-0** Bulk  
**24-373-2** Pkg (2)

Metal stereo jack. 34 x 10mm dia. Cable dia. 4.5mm




Closed circuit mono chassis jack. Mtg. hole 6mm dia.

**24-381-0** Bulk  
**24-381-4** Pkg (4)

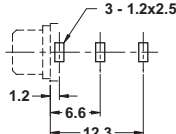

**24-383-0** Bulk  
**24-383-2** Pkg (2)

Mono chassis jack (PC mount also) Mounting hole 6mm diameter.

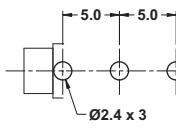

**24-386-0** Bulk  
**24-386-2** Pkg (2)

PC mount mono closed circuit jack.




Mono closed circuit chassis jack. 6mm mtg. hole

**24-387-0** Bulk  
**24-387-2** Pkg (2)




Stereo closed circuit chassis jack. 6mm mtg. hole

**24-388-0** Bulk  
**24-388-1** Pkg

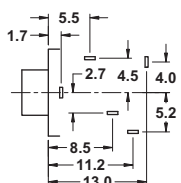

**24-391-0** Bulk  
**24-391-1** Pkg

Stereo PC mount jack with 2 normally closed switches. 6mm mtg.

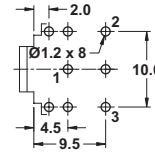

**24-392-0** Bulk  
**24-392-1** Pkg

Stereo PC mount jack.

**1/4" PLUGS**



**24-600-0** Bulk  
**24-600-1** Pkg

Metal mono plug. 33 x 12mm dia. Cable dia. 8mm



**24-601-0** Bulk  
**24-601-1** Pkg

Black plastic mono plug. 40 x 13mm dia. Cable dia. 8mm



**24-603-0** Bulk  
**24-603-1** Pkg

Mono plug with strain relief. 38 x 13mm dia. Cable dia. 6mm



**24-604-0** Bulk  
**24-604-1** Pkg

Metal mono plug with spring strain relief. 32 x 12mm dia. Cable dia. 6mm



**24-610-0** Bulk  
**24-610-1** Pkg

Metal right angle mono plug



**24-618-0** Bulk  
**24-618-1** Pkg

Metal right angle stereo plug



**24-620-0** Bulk  
**24-620-1** Pkg

Metal stereo plug. 33 x 12mm dia. Cable dia. 8mm



**24-621-0** Bulk  
**24-621-1** Pkg

Plastic stereo plug. 40 x 13mm dia. Cable dia. 7.5mm



**24-622-0** Bulk  
**24-622-1** Pkg

Metal stereo plug with spring strain relief. 32 x 12mm dia. Cable dia. 6mm



**24-623-0** Bulk  
**24-623-1** Pkg


Stereo plug with strain relief. 37 x 13mm dia. Cable dia. 6mm

## 1/4" JACKS



**24-650-0** Bulk  
**24-650-1** Pkg

Mono inline jack. 56 x 14mm dia. Cable dia. 6mm




**24-653-0** Bulk  
**24-653-1** Pkg

Metal mono inline jack. 56 x 13mm dia. Cable dia. 6mm



**24-670-0** Bulk  
**24-670-1** Pkg


Stereo inline jack. 56 x 14mm dia. Cable dia. 6.0mm



 
**24-673-0** Bulk  
**24-673-1** Pkg

Metal stereo inline jack. 57 x 13mm dia. Cable dia. 6mm


## 1/4" CHASSIS JACKS




Mono chassis jack. 9mm mounting hole




**24-680-0** Bulk  
**24-680-1** Pkg



 
Mono chassis jack with switch.  
9mm mounting hole




**24-681-0** Bulk  
**24-681-1** Pkg




Stereo chassis jack. 9mm mounting hole




**24-690-0** Bulk  
**24-690-1** Pkg



 
Stereo chassis jack with switch.  
9mm mounting hole



**24-691-0** Bulk  
**24-691-1** Pkg



Stereo chassis jack with 2 SPDT  
switches. 9mm mounting hole



**24-697-0** Bulk  
**24-697-1** Pkg

**MODE ELECTRONICS LTD.**  
211 - 2999 UNDERHILL AVE.,  
BURNABY, B.C., CANADA, V5A 3C2  
Phone: 604-435-6633  
Fax: 604-435-8890  
Toll Free: 1-800-663-4992  
Web Site: www.mode-elec.com

## DIN CONNECTORS

### INLINE DIN JACKS




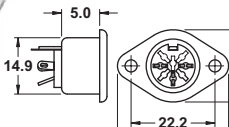
**25-130-0** 3-position  
**25-150-0** 5-position  
**25-160-0** 6-position  
**25-180-0** 8-position  
Use -1 for Display Package

### INLINE DIN PLUGS




**25-230-0** 3-position  
**25-240-0** 4-position  
**25-250-0** 5-position  
**25-260-0** 6-position  
**25-280-0** 8-position  
Use -1 for Display Package

### CHASSIS MOUNT DIN JACKS

**25-340-0** 4-position  
**25-350-0** 5-position  
**25-360-0** 6-position  
Use -1 for Display Package


### SHIELDED PC MOUNT DIN JACK

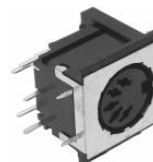

**25-358-0** 5-position  
**25-358-1** Pkg

### PC MOUNT DIN JACK

**25-359-0** 5-position  
**25-359-1** Pkg

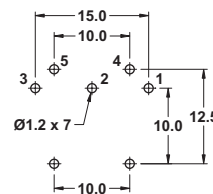


### METAL INLINE DIN PLUG



**25-450-0** 5-pos.  
**25-450-1** Pkg

### STANDARD 'DIN' PIN LAYOUTS

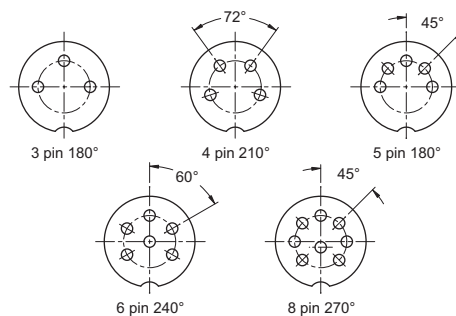

**Mini DIN Connectors on next page**

**MINI DIN CONNECTORS**

**INLINE JACKS**



- 26-140-0** 4-position
- 26-160-0** 6-position
- 26-180-0** 8-position
- Use -1 for Display Pkg.*

**INLINE PLUGS**



- 26-240-0** 4-position
- 26-250-0** 5-position
- 26-260-0** 6-position
- 26-280-0** 8-position
- Use -1 for Display Pkg.*

**MICROPHONE CONNECTORS**



- 25-513-0** 3-pos jack
- 25-513-1** Pkg
- 25-515-0** 5-pos jack
- 25-515-1** Pkg



- 25-523-0** 3-pos plug
- 25-523-1** Pkg
- 25-525-0** 5-pos plug
- 25-525-1** Pkg



- 25-533-0** 3-pos. jack
- 25-533-1** Pkg
- 25-545-0** 5-pos. plug
- 25-545-1** Pkg

**INLINE PLUGS**




- 25-722-0** 2-position
- 25-723-0** 3-position
- 25-724-0** 4-position
- 25-725-0** 5-position
- 25-726-0** 6-position
- 25-728-0** 8-position
- Use -1 for Display Package*


**CHASSIS JACKS**



- 25-732-0** 2-position
- 25-733-0** 3-position
- 25-734-0** 4-position
- 25-735-0** 5-position
- 25-736-0** 6-position
- 25-738-0** 8-position
- Use -1 for Display Package*

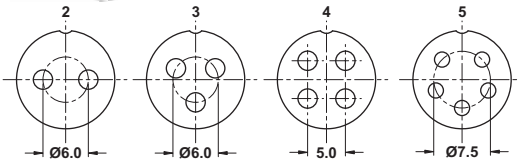

**Pin Layout**

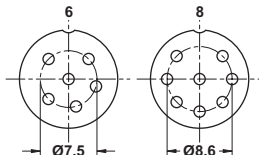

**MINIATURE CONNECTORS**

These are miniature versions of our 25-72X and 25-73X series (approx. 30% smaller).

**INLINE PLUGS**



- 25-722M=0** 2-position
- 25-723M=0** 3-position
- 25-724M=0** 4-position
- 25-725M=0** 5-position
- Use -1 for Display Pkg.*




**CHASSIS JACKS**





- 25-732M=0** 2-position
- 25-733M=0** 3-position
- 25-734M=0** 4-position
- 25-735M=0** 5-position
- Use -1 for Display Pkg.*

**Pin Layout**

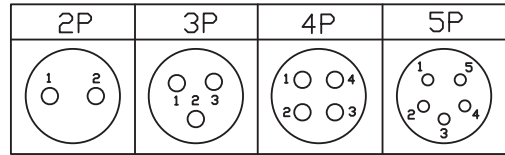

**PRECISION MINIATURE CONNECTOR**

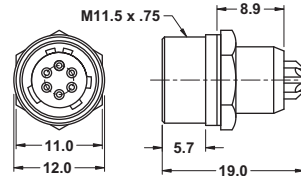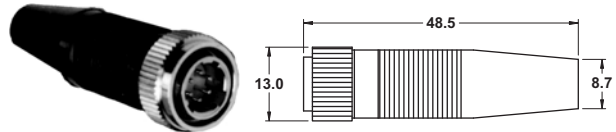

This miniature precision six contact connector features gold plated contacts, threaded locking ring and precision fit and finish.

- 25-746-0** 6-position plug
- 25-746-1** Display Package
- 25-756-0** 6-position jack
- 25-756-1** Display Package

**WATERPROOF (IP67) CONNECTORS**

**INLINE PLUGS**



**CHASSIS JACKS**



- 25-814-0** 4-position
- 25-815-0** 5-position
- 25-818-0** 8-position
- Use -1 for Display Pkg.*
- 25-834-0** 4-position
- 25-835-0** 5-position
- 25-838-0** 8-position
- Use -1 for Display Pkg.*