

UHF CONNECTORS

UHF SPECIFICATIONS

MATERIALS:

Body : Brass
 Contacts: Nickel plated brass
 Dielectric: Delrin

ELECTRICAL:

Nominal Impedance: Non constant
 Frequency Range: 0-500MHz
 Voltage Rating: 500VAC
 Withstanding Voltage: 1000V RMS
 Insulation Resistance: 5000MΩ min.




UHF CHASSIS JACK

21-238-0 Bulk
21-238-1 Package



UHF CHASSIS JACK

21-239-0 Bulk
21-239-1 Package

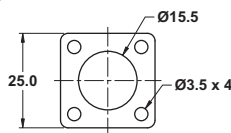

UHF STANDARD PLUG



For RG8/u - use reducing adapters below for RG58 or 59

21-259-0 Bulk
21-259-1 Package

UHF REDUCING ADAPTER



21-260-0 RG58/u
21-261-0 RG59/u
 Use -2 for Display Package

MALE UHF JOINER



21-266-0 Bulk
21-266-1 Package

UHF BULKHEAD MOUNT



50mm long with mtg. nuts
21-267-0 Bulk
21-267-1 Package

FEMALE UHF JOINER



21-268-0 Bulk
21-268-1 Package

UHF RIGHT ANGLE



21-269-0 Bulk
21-269-1 Package

BNC CONNECTORS

BNC SPECIFICATIONS

MATERIALS:


Body: Nickel plated brass
 Contacts: Gold plated brass or phosphor bronze
 Dielectric: Delrin

ELECTRICAL:

Nominal Impedance: 50Ω (75Ω)
 Frequency range: 0-4 GHz
 Voltage rating: 500VAC
 Withstanding voltage: 1500V RMS
 Insulation resistance: 5000MΩ min.

ISOLATED CHASSIS JACK


21-337-0 Bulk
21-337-1 Package

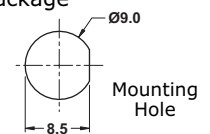

CHASSIS JACK



21-338-0 Bulk
21-338-1 Package

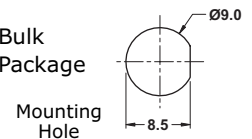

CRIMP PLUG



21-344-0 RG174/u 50Ω
21-346-0 RG6/u 50Ω
21-348-0 RG58/u 50Ω
21-349-0 RG59/u 75Ω
 Use -1 for Display Package

CRIMP JACK



21-350-0 Bulk
21-350-1 Package
 for RG58/u

BNC TERMINATORS



21-351-0 50Ω
21-352-0 75Ω
 Use -1 for Display Package

TWIST-ON PLUG



21-353-0 RG58/u
21-354-0 RG59/u
 Use -1 for Display Package

COMPRESSION CONNECTORS



Use 84-156-1 tool for installation

21-355-0 RG59/u
21-356-0 RG6/u
 Use -1 for Display Package

BNC Connectors continued on next page

STANDARD PLUG (Clamp Type)



21-358-0 RG58/u
21-359-0 RG59/u
Use -1 for Display Package

TRIPLE JACK



21-364-0 Bulk
21-364-1 Package

'T' CONNECTOR



21-365-0 Bulk
21-365-1 Package

FEMALE JOINER



21-368-0 Bulk
21-368-1 Package

MALE JOINER



21-366-0 Bulk
21-366-1 Package

RIGHT ANGLE ELBOW




21-369-0 Bulk
21-369-1 Package

PANEL MOUNT JACK



21-367-0 Bulk
21-367-1 Package

Mounting Hole

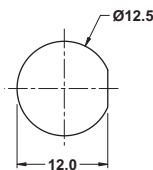

RUBBER CABLE BOOTS

These rubber boots for BNC crimp connectors provide a professional molded look to coaxial cables.



21-398-0 RG58/u
21-399-0 RG59/u
Use -6 for Display Package

N CONNECTORS

SPECIFICATIONS

MATERIALS:

Body: Nickel plated brass
Contacts: Gold plated brass or phosphor bronze
Dielectric: Delrin


ELECTRICAL:

Nominal Impedance: 50Ω
Frequency range: 0-4 GHz
Voltage rating: 500VAC
Withstanding voltage: 1500V RMS
Insulation resistance: 5000MΩ min.

CHASSIS JACK



21-439-0 Bulk
21-439-1 Package

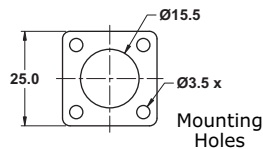

STANDARD PLUG (RG58/u)



21-458-0 Bulk
21-458-1 Package

CRIMP/SOLDER PLUG (RG58/u)



Centre-pin soldered

21-450-0 Bulk
21-450-1 Package

FEMALE JOINER



21-468-0 Bulk
21-468-1 Package

STANDARD PLUG (RG8/u)



21-457-0 Bulk
21-457-1 Package

RIGHT ANGLE ELBOW



21-469-0 Bulk
21-469-1 Package

MINI UHF CONNECTORS

MINI UHF SPECIFICATIONS

MATERIALS:

Body : Brass
 Contacts: Nickel plated brass
 Dielectric: Delrin

ELECTRICAL:

Nominal Impedance: Non constant
 Frequency Range: 0-2GHz
 Voltage Rating: 500VAC
 Withstanding Voltage: 1000V RMS
 Insulation Resistance: 5000MΩ min.

TNC CONNECTORS

TNC SPECIFICATIONS

MATERIALS:

Body: Nickel plated brass
 Contacts: Gold plated brass or phosphor bronze
 Dielectric: Delrin

ELECTRICAL:

Nominal Impedance: 50Ω
 Frequency range: 0-4 GHz
 Voltage rating: 500VAC
 Withstanding voltage: 1500V RMS
 Insulation resistance: 5000MΩ min.

CHASSIS JACK



21-538-0 Bulk Package
 21-538-1

CRIMP PLUG (RG58/u)



21-748-0 Bulk Package
 21-748-1

CRIMP PLUG RG58/u



21-548-0 Bulk Package
 21-548-1

STANDARD PLUG (RG58/u)



21-758-0 Bulk Package
 21-758-1

'T' CONNECTOR



21-564-0 Bulk Package
 21-564-1

FEMALE JOINER



21-768-0 Bulk Package
 21-768-1

RIGHT ANGLE ELBOW



21-569-0 Bulk Package
 21-569-1

RIGHT ANGLE ELBOW



21-769-0 Bulk Package
 21-769-1

SMA CONNECTORS

SMA SPECIFICATIONS

MATERIALS:

Body: Nickel plated brass
 Contacts: Gold plated brass or phosphor bronze
 Dielectric: Delrin

ELECTRICAL:

Nominal Impedance: 50Ω
 Frequency range: 0-12.4 GHz
 Voltage rating: 500VAC
 Withstanding voltage: 1500V RMS
 Insulation resistance: 5000MΩ min.

CRIMP PLUG FOR RG174/U



21-847-0 Bulk Package
 21-847-1

CRIMP PLUG FOR RG58/U



21-848-0 Bulk Package
 21-848-1

FEMALE JOINER



21-868-0 Bulk Package
 21-868-1