



Electrical Commercial and Industrial


[Products](#) | [Documentation & Literature](#) | [News & Tradeshow](#) | [Support](#)

[United States](#) > [All 3M Products](#) > [Energy](#) > [Electrical Commercial and Industrial](#) > [Products](#) > [Electrical Commercial & Industrial Products Catalog](#) > [Terminals, Kits and Tools](#) > [Terminals](#) > 3M™ Scotchlok™ Pin Nylon Insulated, 100/bottle, MNG18-47PX-A

[Find An Account Rep](#) [Where To Buy \(Find A Distributor\)](#) [Contact Us](#)

3M™ Scotchlok™ Pin Nylon Insulated, 100/bottle, MNG18-47PX-A

3M ID 80611464910 UPC# 00051128588451 Part Number MNG18-47PX-A Print Share

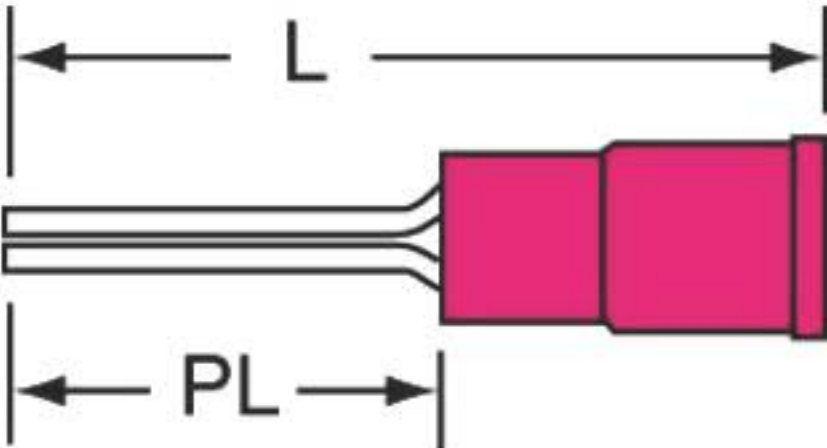

Pin Nylon Insulated, 100/bottle, MNG18-47PX-A



Need Help?

Questions? We can help
[Contact Us](#)

[Overview](#) [Documents](#)

Specifications

Barrel Style	Insulation Grip
Brand	Scotchlok
Conductor Sizes	22 - 18 AWG
Insulation Material	Nylon
Length	0.9 Inch
Maximum Insulation Outer Diameter	0.17 Inch
Packaging	100 per bottle
RoHS 2011/65/EU Compliant	Yes
RoHS EU Comments	RoHS 2011/65/EU compliant without exemption *Important RoHS information
Terminal Type	Pin
Trademark	Scotchlok

