

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0192000003**
Status: **Active**
Overview: Splices
Description: Avikrimp™ Seamless Butt Splice for 10-12 AWG Wire, Super Duty

Documents:

Drawing (PDF) [Product Specification PS-19902-013-001 \(PDF\)](#)
Product Specification PS-19902-011-001 (PDF) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E32244

General

Product Family Splices
 Series 19200
 Comments Yellow
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview Splices
 Product Name Avikrimp™
 UPC 756054241233

Physical

Barrel Type Closed
 Color - Resin Yellow
 Flammability 94V-2
 Insulation Nylon (PA)
 Material - Metal Copper
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Net Weight 4.064/g
 Packaging Type Bag
 Temperature Range - Operating 105°C
 Wire Insulation Diameter 5.84mm
 Wire Size AWG 10, 12

Electrical


Voltage - Maximum 600V

Material Info

Engineering Number CS-846

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-013-001
 Sales Drawing SD-19200-001

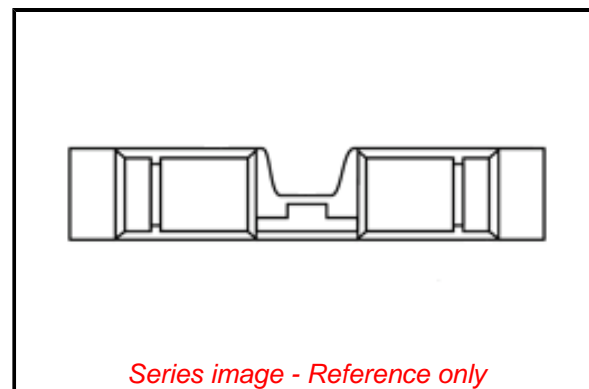

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19200 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION