

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0192160004](#)
Status: **Active**
Overview: [Splices](#)
Description: Multi-Lock Connector for 14-18 AWG Wire

Documents:

[3D Model](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)

Agency Certification

UL E32244

General

Product Family Splices
 Series [19216](#)
 Comments Width 13.97mm (.550")
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 MolexKits Yes
 Overview [Splices](#)
 Product Name Multi-Lock
 UPC 800753025943

Physical

Barrel Type Closed
 Color - Resin White
 Flammability 94V-0
 Insulation Polypropylene
 Material - Metal Copper
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Net Weight 1.334/g
 Packaging Type Bag
 Wire Insulation Diameter 3.30mm & 3.56mm
 Wire Size AWG 14, 16, 18
 Wire Size mm² 0.96-2.60

Electrical

Voltage - Maximum 600V

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number ML-1814

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-013-001
 Sales Drawing SD-19216-003

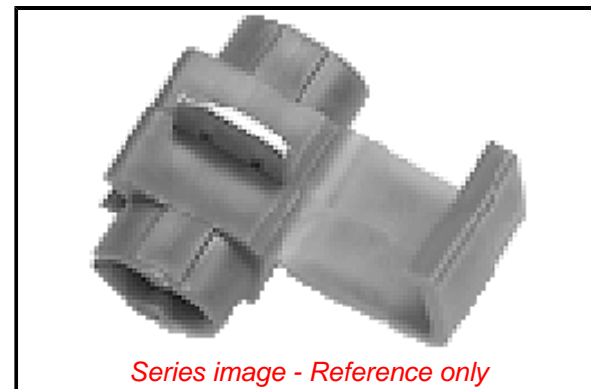

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[19216 Series](#)