

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0190730202
Status: Active
Overview: Solderless Terminals
Description: Avikrimp™ Ring Tongue Terminal for 10 to 12 AWG Wire, Stud Size 5/16" (M8), Expanded Flare, Length 31.95mm

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)


Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series 19073
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview Solderless Terminals
Product Name Avikrimp™
Type Ring
UPC 800753077409

Physical
Barrel Type Closed
Flammability 94V-2
Insulation Nylon (PA)
Material - Plating Mating Tin
Net Weight 2.544/g
Packaging Type Bag
Stud Size 5/16" (M8)
Wire Insulation Diameter 6.35mm max
Wire Size AWG 10, 12
Wire Size mm² 4.00-6.00

Material Info
Engineering Number C-830-56X

Reference - Drawing Numbers
Product Specification PS-19902-011-001
Sales Drawing CCD80105

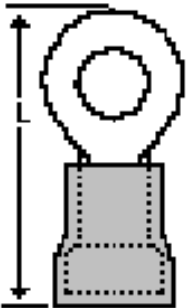

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
ED/30/2017 (7 July
2017)
Halogen-Free
Status
Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
19073 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION