



[Login](#) to manage account. New customer? [Start here](#)

shopping cart (0 items)
 wishlist (0 items)

Quick Find: [Home](#) [Featured](#) [Specials](#) [Help & Information](#) [Distributors](#) [Forums](#) [Manuals](#) [Product Change](#) [Contact Us](#) [My Account](#)

Categories

[Download Catalogue](#)

On Sale

Graphic TFT Touch


GX Series

- [Intelligent Display](#)
- [Economy Display](#)
- [Parallel Display](#)
- [DevDevil Board](#)
- [PC Bay Inserts](#)
- [Accessories](#)
- [Interface Module](#)
- [Miscellaneous](#)
- [Design Services](#)

Specials >>

MX231

Intelligent Display » Character LCDs » LCD0821

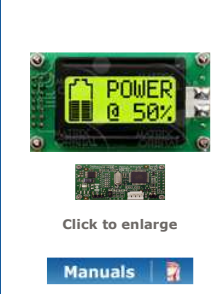

If your product is short on space but needs information at a glance then the LCD0821 will suit your needs. This product is used in military servers and luxury yachts. The 8 characters by 2 lines display maybe just right for your project.

Name	Quantity	Price (USD)			
LCD0821 Base Product	<input type="text"/> Qty 1+	25+	50+	100+	
	Unit Price				
	Saving %	0%	2%	5%	10%
LCD0821-E <i>Extended Temperature option, -20 °C to +70 °C.</i>	<input type="text"/> Qty 1+	25+	50+	100+	
	Unit Price				
	Saving %	0%	2%	4%	8%
LCD0821-V <i>Wide Voltage power, +9 to +15Vdc.</i>	<input type="text"/> Qty 1+	25+	50+	100+	
	Unit Price				
	Saving %	0%	2%	5%	9%
LCD0821-V-E <i>Wide Voltage power +9 to +15Vdc. Extended Temperature option, -20 °C to +70 °C.</i>	<input type="text"/> Qty 1+	25+	50+	100+	
	Unit Price				
	Saving %	0%	2%	4%	7%

Available Accessories

<p>Power</p> <ul style="list-style-type: none"> • PC12V (Power Cable 12V) \$4.99 USD 	<p>Communication</p> <ul style="list-style-type: none"> • CCS1FT (Serial 1ft Cable) \$5.49 USD • BBC (Breadboard Cable) \$4.95 USD • CCS4FT (Serial 4ft Cable) \$5.99 USD
--	---

Display Appearance

Character X Lines	Module Size	Character Size
8 x 2	Length Width Thickness 58.00 mm x 32.00 mm x 25.00 mm	Length Width 5.56 mm x 2.96 mm
Display Size	Background Color	Text Color
Length Width 38.00 mm x 16.00 mm	Yellow/Green	Black

Features

Keypad	One Wire	GPO	Advanced GPO
N/A	N/A	1	N/A

Interface

RS232	RS232TTL	Buffer	Other
1200 2400 9600 19200	1200 2400 9600 19200	128	I2C

Environmental Conditions

Standard Temp.	Extended Temp (-E)	Max Humidity
Min Max 0.00°C to 50.00°C	Min Max -20.00°C to 70.00°C	90.00 %

Power Requirements

Supply Current	Backlight Current	Inrush Current
5V	94 mA	N/A

Includes

We provide all our manuals on line at our Tech Support site at <http://www.matrixorbital.ca/manuals/> and questions may be posted on our forum site at <http://www.lcdforums.com/forums>

Your Account

[Login Problems? Click Here](#)

Your Email Address

Your Password

Shopping Cart >>

0 items

Best Sellers

- LCD2041-WB
- LCD0821
- LK202-25
- LCD2041-E
- LK162-12-E
- GLK19264-7T-1U-WB
- LCD2041-GW
- LK204-25-WB-E
- GLK12232-25-FGW-E
- GLK19264-7T-1U-FGW

Information

[Information Pages](#)
[Contact Us](#)
[Orbital](#)
[Design Service](#)

Tell A Friend


Tell someone you know about this product.



Your Recent History

Viewed Products Successful **You may also**





ISCCPC5V

Searches
gik240128-25-e

appreciate...
LK204-25-422-R-VPT-E

GTT480272A-USB

GTT480272A

GRY204 (Gray 20x4 VFD Filter)



[Home](#) | [Login](#) | [Specials](#) | [Shopping Cart](#) | [Checkout](#) | [Contact us](#) | [Terms](#) | [Privacy Notice](#) | [Shipping](#)

Copyright © 2012 MatrixOrbital Inc.

