

Cable gland - HC-B-GM0-M40-ET-AL - 1414647

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




EVO metal cable gland with bayonet locking; size M40, with filler plug

Product Description

Metal cable gland

Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 030999
GTIN	4055626030999
Weight per Piece (excluding packing)	140.000 g
Custom tariff number	85389099
Country of origin	Germany

Technical data

Dimensions

Ambient conditions

Degree of protection	IP66
	IP67
	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Ambient temperature (operation)	-30 °C ... 100 °C

General

Cable gland - HC-B-GM0-M40-ET-AL - 1414647


Technical data

General

Material	Die-cast aluminum, corrosion-resistant
Housing material	Die-cast aluminum, corrosion resistant
Cable gland material	Aluminum
Material, pressure screw	Brass
Shielded	No
Thread type on connection side	Bayonet B metal
Thread type on seal side	M40

Drawings

Dimensional drawing

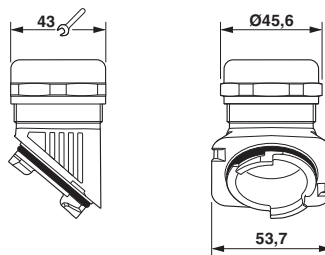

Dimensional drawing

Classifications

eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27261207
eCl@ss 8.0	27149109
eCl@ss 9.0	27144432

ETIM

ETIM 5.0	EC000441
ETIM 6.0	EC000441

UNSPSC

UNSPSC 13.2	39121311
-------------	----------

Approvals

Approvals

Cable gland - HC-B-GM0-M40-ET-AL - 1414647

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		7500651.22.01.00246
-----	---	---------------------
