

Sealing cap - PROT-M 8 MS-PA-CHAIN-EYE-DM3 - 1441105

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



M8 sealing cap made of plastic with fixing band, for free M8 sockets, with 3.0 mm fastening eye



Key Commercial Data

Packing unit	1 STK
Minimum order quantity	10 STK
GTIN	 4 046356 502863
GTIN	4046356502863
Weight per Piece (excluding packing)	1.000 g
Custom tariff number	39269097
Country of origin	Germany

Technical data

Ambient conditions

Ambient temperature (operation)	-25 °C ... 85 °C
Degree of protection	IP65
	IP67

Material

Flammability rating according to UL 94	V0
Material	PA 66 GF
Sealing material	NBR
Additional material specifications	PUR (Holding band)

Standards and Regulations

Sealing cap - PROT-M 8 MS-PA-CHAIN-EYE-DM3 - 1441105

Technical data

Standards and Regulations


Flammability rating according to UL 94	V0
--	----

Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Drawings

Dimensional drawing

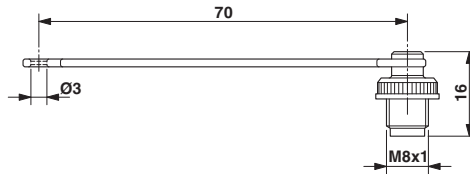

Dimensional drawing

Classifications

eCl@ss

eCl@ss 4.0	27250313
eCl@ss 4.1	27250313
eCl@ss 5.0	27143423
eCl@ss 5.1	27143423
eCl@ss 6.0	27143423
eCl@ss 7.0	27449001
eCl@ss 8.0	27379218
eCl@ss 9.0	27379218

ETIM

ETIM 3.0	EC000032
ETIM 4.0	EC002040
ETIM 5.0	EC002040
ETIM 6.0	EC002040

UNSPSC

UNSPSC 6.01	31251501
-------------	----------

Sealing cap - PROT-M 8 MS-PA-CHAIN-EYE-DM3 - 1441105

Classifications

UNSPSC

UNSPSC 7.0901	31251501
UNSPSC 11	31251501
UNSPSC 12.01	31251501
UNSPSC 13.2	31251501

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		B.01742
-----	---	---------
