


Search within category

GO

BUY NOW

DESIGN / INSTALL

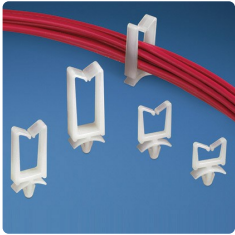

VWS3750-C

Vertical wire saddle, .37" x .50" (9.398mm x 12.7mm) bundle, natural, standard package.

Specs	Packaging Details	Documents	★ Add to Favorites	🛒 Add to BOM
Color	Natural			
Environment	Indoor			
Flammability Rating	UL94V-2			
Height (In.)	0.90			
Height (mm)	22.9			
Material	Nylon 6.6			
Max. Bundle Capacity (In.)	0.37 X 0.50			
Max. Bundle Capacity (mm)	9.3 X 12.7			
Max. Panel Thickness (In.)	0.04			
Max. Panel Thickness (mm)	1.0			
Mounting Method	Push Barb			
Panel Hole Diameter (In.)	0.19			
Panel Hole Diameter (mm)	4.7			
UL Recognized	E136577			
Width (In.)	0.56			
Width (mm)	14.2			
RoHS Compliancy Status	Compliant			
Min. Order Qty.	100			