

Search Results

- Evaluate
 - FAQ's
- Design a Solution
 - Part Drawings
 - PDFPush Mount A..
 - Specification Sheets
 - PDFPush Mounts..
- How to Buy
 - Bill of Material
 - Favorite Products List
 - Locate Distributor


Home > Products Overview > Search Results >

Current refinements (click  to remove) Search Tips

 Text Search: 'PUM-071-2S-C30'

Your search criteria matched only one product, shown below

PUM-071-2S-C30

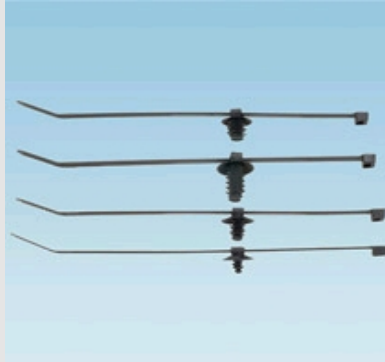

- Cable tie/mount assemblies significantly reduce installation time compared to loose parts
- Fewer parts throughout the manufacturing/assembly process
- Heat Stabilized Nylon 6.6 standard on cable ties and mounts

Part Number	PUM071-2S-C30
RoHS Compliancy Status	Compliant
Part Description	Fir Tree Push Mount Assembly
Product Type	Cable Tie Mounts- Through Panel Hole
Material	Heat Stabilized Nylon 6.6
Color	Black
CE Compliant	No
Environment	Indoor
Head Diameter (In.)	0.67
Head Diameter (mm)	17.0
Max. Bundle Diameter (In.)	1.88
Max. Bundle Diameter (mm)	48
Mounting Method	Fir Tree Hole Mount
Overall Height (In.)	0.67
Overall Height (mm)	16.9
Panel Hole Diameter Range (In.)	0.25 - 0.28
Panel Hole Diameter Range (mm)	6.3 - 7.1
Panel Thickness Range (In.)	0.03 - 0.28
Panel Thickness Range (mm)	0.8 - 7.0
Panel to Top of Mount (In.)	0.26
Panel to Top of Mount (mm)	6.6
Pricing Description	Fir Tree Push Mount Assembly, .25"-.28" (6.3mm-7.1mm) Panel Hole Dia Range, HSBL, 100/pkg
Sub Brand	Cable Tie and Mount
Type	Through Hole
Min. Order UOM	PC
Min. Order Qty.	100
BOM Qty. (# of Pkgs.)	<input type="text" value="0"/>
Add to Favorite Product List	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.